

AT-type timing pulley



Pitch AT5

Aluminium



For 25mm belts



- For use with AT5 belts
- Pitch 5mm
- Material:
Aluminium

Accessories

- AT5 belts
- GTC tension rollers

Info

- *Pilot bore given as indication, may vary between batches.
- Will require re-machining by customer
- We are unable to modify this product

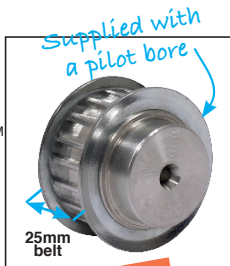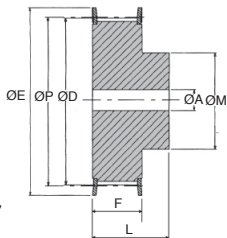

Economy range

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	ØP PDC	ØD external	ØE flange	ØM	F	L	Pilot bore not guaranteed	
								ØA*	Price each 1 to 5
12AT5-25/ECO	12	19,10	17,85	23	11	30	36	-	3,94 €
14AT5-25/ECO	14	22,29	21,05	25	13	30	36	-	4,36 €
15AT5-25/ECO	15	23,88	22,65	28	16	30	36	6	4,74 €
16AT5-25/ECO	16	25,47	24,20	32	18	30	36	6	5,24 €
18AT5-25/ECO	18	28,65	27,40	32	20	30	36	6	5,61 €
19AT5-25/ECO	19	30,25	29,00	36	22	30	36	6	6,23 €
20AT5-25/ECO	20	31,83	30,60	36	23	30	36	6	6,66 €
22AT5-25/ECO	22	35,02	33,85	38	24	30	36	6	7,63 €
24AT5-25/ECO	24	38,21	37,00	42	26	30	36	6	8,45 €
25AT5-25/ECO	25	39,80	38,60	44	26	30	36	6	9,03 €
26AT5-25/ECO	26	41,39	40,20	44	26	30	36	6	9,73 €
27AT5-25/ECO	27	42,98	41,80	48	30	30	36	8	9,91 €
28AT5-25/ECO	28	44,58	43,35	48	32	30	36	8	10,75 €
30AT5-25/ECO	30	47,76	46,55	51	34	36	36	8	11,54 €
32AT5-25/ECO	32	50,94	49,70	54	38	30	36	8	12,95 €
36AT5-25/ECO	36	57,31	56,05	64	38	30	36	8	15,20 €
40AT5-25/ECO	40	63,66	62,45	66,5	40	30	36	8	17,15 €
42AT5-25/ECO	42	66,86	65,60	70	40	30	36	8	18,61 €
44AT5-25/ECO	44	70,05	68,80	-	45	30	36	8	19,54 €
48AT5-25/ECO	48	76,42	75,15	-	50	30	36	8	22,06 €
60AT5-25/ECO	60	95,52	94,25	-	65	30	36	8	32,94 €

Dimensions in mm

Our other products



UTKswc
Utilitrak® 3 wheels carriage, Series V precision steel wheel



DBC
Panamech, Multi-Beam, Aluminium - with clamping jaw



CHAR5050_Z
Spring hinge, screwed



ERF
Quick fitting threaded cable terminal, Cable terminal with threaded ...



AT10-BAR
AT type tooth bar stock, AT10



RFK48C
Hypoid gearbox - Stainless steel, up to 350 Nm




VRM
Female swivelling lifting rings, Female swivelling



DER71
Stainless steel AC asynchronous motor 0.25 à 0.37kW, 0.25 to 0.37kW



 
VB
Small 6 lobe threaded handle - female, Duroplast - Stainless



SHTP
Drylin® Linear table, Economy range



 PP60
Worm and wheel gear reducer, from 17.80 to 34 Nm



INO
Internal gear, Machined plastic (delrin)

Complementary products



GTC
Belt tensioner, For standard applications



AT5courroie
AT type timing belt, AT5 Steel cored polyurethane



AT5-BAR
AT type tooth bar stock, AT5



AT5M AT10M
AT type timing belt per metre, AT5 Steel cored polyurethane