

AT-type timing pulley



Pitch AT5

Aluminium



For 25mm belts



- For use with AT5 belts
- Pitch 5mm
- Material:
Aluminium

Accessories

- AT5 belts
- GTC tension rollers

Info

- *Pilot bore given as indication, may vary between batches.
- Will require re-machining by customer
- We are unable to modify this product

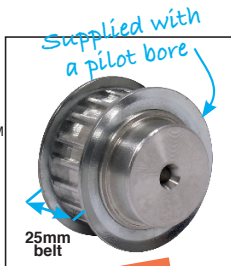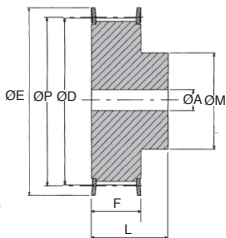

Economy range

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	ØP PDC	ØD external	ØE flange	ØM	F	L	Pilot bore not guaranteed	
								ØA*	Price each 1 to 5
12AT5-25/ECO	12	19,10	17,85	23	11	30	36	-	3,94 €
14AT5-25/ECO	14	22,29	21,05	25	13	30	36	-	4,36 €
15AT5-25/ECO	15	23,88	22,65	28	16	30	36	6	4,74 €
16AT5-25/ECO	16	25,47	24,20	32	18	30	36	6	5,24 €
18AT5-25/ECO	18	28,65	27,40	32	20	30	36	6	5,61 €
19AT5-25/ECO	19	30,25	29,00	36	22	30	36	6	6,23 €
20AT5-25/ECO	20	31,83	30,60	36	23	30	36	6	6,66 €
22AT5-25/ECO	22	35,02	33,85	38	24	30	36	6	7,63 €
24AT5-25/ECO	24	38,21	37,00	42	26	30	36	6	8,45 €
25AT5-25/ECO	25	39,80	38,60	44	26	30	36	6	9,03 €
26AT5-25/ECO	26	41,39	40,20	44	26	30	36	6	9,73 €
27AT5-25/ECO	27	42,98	41,80	48	30	30	36	8	9,91 €
28AT5-25/ECO	28	44,58	43,35	48	32	30	36	8	10,75 €
30AT5-25/ECO	30	47,76	46,55	51	34	36	36	8	11,54 €
32AT5-25/ECO	32	50,94	49,70	54	38	30	36	8	12,95 €
36AT5-25/ECO	36	57,31	56,05	64	38	30	36	8	15,20 €
40AT5-25/ECO	40	63,66	62,45	66,5	40	30	36	8	17,15 €
42AT5-25/ECO	42	66,86	65,60	70	40	30	36	8	18,61 €
44AT5-25/ECO	44	70,05	68,80	-	45	30	36	8	19,54 €
48AT5-25/ECO	48	76,42	75,15	-	50	30	36	8	22,06 €
60AT5-25/ECO	60	95,52	94,25	-	65	30	36	8	32,94 €

Dimensions in mm

Our other products




CHM40
Worm and wheel gear reducer, up to 57 Nm



BTC
End cap for square tube, Standard



PW_PWG3
Worm - precision range, Stainless steel

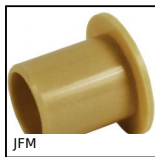

JFM
Flanged polymer bush, Universal polymer




OP2
Mechanical digital position indicator, 3 numbers



PF45
Worm and wheel gear reducer, up to 40 Nm



 PCS6ECO
Chain sprocket - steel, 6mm (DIN 04-1)



B
Steel bevel gear, 1:1



PR881
Idler sprocket for slat top chain, Range 881



VTHbr
Hexagonal headed screw VTH - DIN933, Brass



RFK38B
Hypoid gearbox - Stainless steel, up to 200 Nm



SVG
Adjustable latch clamp with strike plate, Stroke from 174mm to 190mm

Complementary products



GTC
Belt tensioner, For standard applications



AT5courroie
AT type timing belt, AT5 Steel cored polyurethane



AT5-BAR
AT type tooth bar stock, AT5



AT5M AT10M
AT type timing belt per metre, AT5 Steel cored polyurethane