

# AT type tooth bar stock



## AT5-BAR

## Aluminium




- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodic oxidation
- Finish : Supplied not-treated



### Info.

- We are unable to modify this product

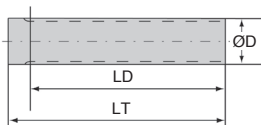

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Z Teeth	ØD External	Length of teeth L <sub>D</sub>	Total length L <sub>T</sub>	Price each
12AT5-BAR	12	17,85	140	140	9,45 €
13AT5-BAR	13	19,45	140	140	19,64 €
14AT5-BAR	14	21,05	140	140	11,13 €
15AT5-BAR	15	22,65	140	140	12,05 €
16AT5-BAR	16	24,20	140	140	13,57 €
18AT5-BAR	18	27,40	140	140	15,75 €
19AT5-BAR	19	29,00	140	140	17,04 €
20AT5-BAR	20	30,60	160	160	19,64 €
21AT5-BAR	21	32,30	160	160	20,47 €
22AT5-BAR	22	33,85	160	160	22,81 €
23AT5-BAR	23	35,45	160	160	23,01 €
24AT5-BAR	24	37,00	160	160	24,72 €
25AT5-BAR	25	38,55	160	160	26,57 €
26AT5-BAR	26	40,20	160	160	29,26 €
28AT5-BAR	28	43,25	160	160	32,42 €
30AT5-BAR	30	46,55	160	160	34,74 €
32AT5-BAR	32	49,70	160	160	40,31 €
34AT5-BAR	34	52,85	160	160	44,15 €
36AT5-BAR	36	56,05	160	160	46,84 €
38AT5-BAR	38	59,25	160	160	49,71 €
40AT5-BAR	40	62,45	160	160	53,92 €
42AT5-BAR	42	65,60	160	160	58,32 €
44AT5-BAR	44	68,80	160	160	68,68 €
46AT5-BAR	46	72,00	160	160	69,16 €
48AT5-BAR	48	75,15	160	160	77,36 €
52AT5-BAR	52	81,55	160	160	106,18 €
56AT5-BAR	56	87,90	160	160	109,65 €
60AT5-BAR	60	94,25	160	160	116,26 €
64AT5-BAR	64	100,65	160	160	155,16 €
72AT5-BAR	72	113,35	160	160	163,49 €

Dimensions in mm

## Our other products



PRF\_BR

Clamp for aluminium profile, Clamp for profile



TFR

Rigid manual tensioner, Fixed



SBF

Sealed flange bearing unit for Food Industry, cover



PR820

Idler sprocket for slat top chain, Rangs 820 and 815



GAL22

Conveyor wheel, Zinc plated steel



QN

Single row cylindrical roller bearing, Free outer ring



TCC

Rigging screw (hook/hook), Steel



WJUM16

Dyrilin® W bearing block, Slide



PSG08

Spur gear - precision range, Case hardened



PGR

Folding revolving handle for handwheel, AT5



BL15

Right angled gearbox, from 1.10 to 6 Nm



KSTM

Igal® pillow block bearing, Polymer

## Complementary products



AT10-BAR

AT type tooth bar stock, AT10



AT5-10ECO

AT type timing pulley, Economy range - AT5 aluminium



AT5-16ECO

AT type timing pulley, Economy range - AT5 aluminium



AT5-25ECO

AT type timing pulley, Economy range - AT5 aluminium