

# AT type tooth bar stock



## AT5-BAR

## Aluminium




- Bar stock to be cut to length by the customer

- The overall length is the same as the maximum length

- Material : Aluminium suitable for hard anodic oxidation

- Finish : Supplied not-treated

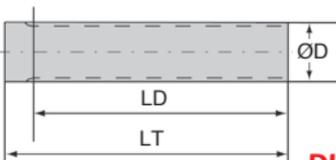

### Info.

- We are unable to modify this product

### Accessories

- AT5 belt (tome 4 p.82)

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Z Teeth	ØD External	Length of teeth L <sub>D</sub>	Total length L <sub>T</sub>	Price each
12AT5-BAR	12	17,85	140	140	10,51 €
13AT5-BAR	13	19,45	140	140	21,69 €
14AT5-BAR	14	21,05	140	140	12,30 €
15AT5-BAR	15	22,65	140	140	13,18 €
16AT5-BAR	16	24,20	140	140	14,79 €
18AT5-BAR	18	27,40	140	140	17,22 €
19AT5-BAR	19	29,00	140	140	18,68 €
20AT5-BAR	20	30,60	160	160	21,47 €
21AT5-BAR	21	32,30	160	160	22,25 €
22AT5-BAR	22	33,85	160	160	24,86 €
23AT5-BAR	23	35,45	160	160	25,00 €
24AT5-BAR	24	37,00	160	160	26,86 €
25AT5-BAR	25	38,55	160	160	28,78 €
26AT5-BAR	26	40,20	160	160	31,69 €
28AT5-BAR	28	43,25	160	160	34,92 €
30AT5-BAR	30	46,55	160	160	37,43 €
32AT5-BAR	32	49,70	160	160	43,52 €
34AT5-BAR	34	52,85	160	160	51,48 €
36AT5-BAR	36	56,05	160	160	50,31 €
38AT5-BAR	38	59,25	160	160	53,54 €
40AT5-BAR	40	62,45	160	160	57,90 €
42AT5-BAR	42	65,60	160	160	62,54 €
44AT5-BAR	44	68,80	160	160	73,62 €
46AT5-BAR	46	72,00	160	160	74,21 €
48AT5-BAR	48	75,15	160	160	82,86 €
52AT5-BAR	52	81,55	160	160	113,29 €
56AT5-BAR	56	87,90	160	160	117,02 €
60AT5-BAR	60	94,25	160	160	124,10 €
64AT5-BAR	64	100,65	160	160	165,59 €
72AT5-BAR	72	113,35	160	160	174,47 €

Dimensions in mm

- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodic oxidation
- Finish : Supplied not-treated




### Info.

- We are unable to modify this product

### Accessories

- AT10 belt (tome 4 p.83)

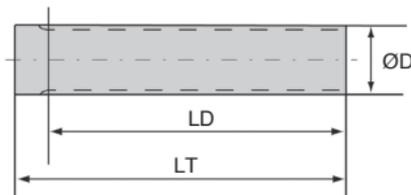

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Z Teeth	ØD External	Length of teeth L <sub>D</sub>	Total length L <sub>T</sub>	Price each
15AT10-BAR	15	45,90	160	160	33,38 €
16AT10-BAR	16	49,14	160	160	37,71 €
18AT10-BAR	18	55,45	160	160	45,35 €
19AT10-BAR	19	58,65	160	160	50,80 €
20AT10-BAR	20	61,80	160	160	55,03 €
21AT10-BAR	21	65,00	160	160	59,62 €
22AT10-BAR	22	68,20	160	160	70,54 €
23AT10-BAR	23	71,35	160	160	70,86 €
24AT10-BAR	24	74,55	160	160	79,43 €
25AT10-BAR	25	77,75	160	160	80,01 €
26AT10-BAR	26	80,90	160	160	89,05 €
28AT10-BAR	28	87,25	160	160	99,03 €
30AT10-BAR	30	93,65	160	160	119,97 €
32AT10-BAR	32	100,00	160	160	131,79 €
34AT10-BAR	34	106,40	160	160	144,10 €
36AT10-BAR	36	112,75	160	160	158,31 €
38AT10-BAR	38	119,10	160	160	183,36 €
40AT10-BAR	40	125,45	160	160	197,90 €
42AT10-BAR	42	131,85	160	160	223,82 €
44AT10-BAR	44	138,20	160	160	245,00 €
46AT10-BAR	46	144,55	160	160	269,73 €
48AT10-BAR	48	150,95	160	160	285,33 €
52AT10-BAR	52	163,65	160	160	345,45 €
56AT10-BAR	56	176,40	160	160	397,34 €
60AT10-BAR	60	189,15	160	160	469,99 €

Dimensions in mm