

AT type tooth bar stock

 


AT5-BAR

Aluminium




- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodic oxidation
- Finish : Supplied not-treated



Info.

- We are unable to modify this product

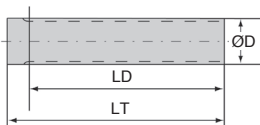

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Z Teeth	ØD External	Length of teeth L _D	Total length L _T	Price each
12AT5-BAR	12	17,85	140	140	9,45 €
13AT5-BAR	13	19,45	140	140	19,64 €
14AT5-BAR	14	21,05	140	140	11,13 €
15AT5-BAR	15	22,65	140	140	12,05 €
16AT5-BAR	16	24,20	140	140	13,57 €
18AT5-BAR	18	27,40	140	140	15,75 €
19AT5-BAR	19	29,00	140	140	17,04 €
20AT5-BAR	20	30,60	160	160	19,64 €
21AT5-BAR	21	32,30	160	160	20,47 €
22AT5-BAR	22	33,85	160	160	22,81 €
23AT5-BAR	23	35,45	160	160	23,01 €
24AT5-BAR	24	37,00	160	160	24,72 €
25AT5-BAR	25	38,55	160	160	26,57 €
26AT5-BAR	26	40,20	160	160	29,26 €
28AT5-BAR	28	43,25	160	160	32,42 €
30AT5-BAR	30	46,55	160	160	34,74 €
32AT5-BAR	32	49,70	160	160	40,31 €
34AT5-BAR	34	52,85	160	160	44,15 €
36AT5-BAR	36	56,05	160	160	46,84 €
38AT5-BAR	38	59,25	160	160	49,71 €
40AT5-BAR	40	62,45	160	160	53,92 €
42AT5-BAR	42	65,60	160	160	58,32 €
44AT5-BAR	44	68,80	160	160	68,68 €
46AT5-BAR	46	72,00	160	160	69,16 €
48AT5-BAR	48	75,15	160	160	77,36 €
52AT5-BAR	52	81,55	160	160	106,18 €
56AT5-BAR	56	87,90	160	160	109,65 €
60AT5-BAR	60	94,25	160	160	116,26 €
64AT5-BAR	64	100,65	160	160	155,16 €
72AT5-BAR	72	113,35	160	160	163,49 €

Dimensions in mm

Our other products



SBF

Sealed flange bearing unit for Food Industry, cover



MAX22

Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



RDE-N

Sealing washer Hygienic Usit®, Stainless steel - Black EPDM



FB_ECO

Eco. range steel bevel gear, 4:1



CLM

Male clevis end, Steel short



BPPE

Ball transfer unit push fit, Light



PX

Optional output shaft stainless steel, P gearboxes single sided outp...



CHA1056_U4

Screw-in hinge, Section 40X40



ADL_M

Male eye bolt conforms to DIN580,



S2B

Short linear bearing housing, Closed - Slim



PRS30

Stainless steel articulated foot Ø30,



M

Bellows cover, Accessory:

Complementary products



AT10-BAR

AT type tooth bar stock, AT10



AT5-10ECO

AT type timing pulley, Economy range - AT5 aluminium



AT5-16ECO

AT type timing pulley, Economy range - AT5 aluminium



AT5-25ECO

AT type timing pulley, Economy range - AT5 aluminium