

AT-type timing belt **per metre**



Pitch

Steel cored polyurethane


AT5
AT10

SINGLE-SIDED



Din 7721

- 2nd generation metric profile
- Transmits a greater load
- Pitch 5 or 10mm
- For linear movements
- Secured using rigid connecting plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length ±0.8mm/1000mm
- Efficiency: up to 98%
- Oil-resistant
- Low noise
- Resists stretching

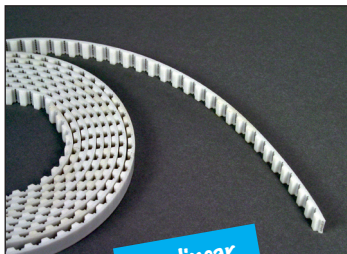

For linear positioning

Uses


- For reciprocating movements

Accessories



- Connecting plate AT.../P

Info.

- Min. length: 1000mm
- Supplied in multiples of 1 metre
- When ordering, add the length (L) and the width (l) to the part number (AT5M/L/l).
- E.g.: AT5M/1000/16

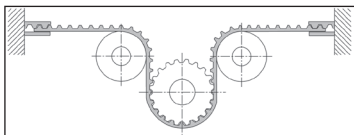

Typical application

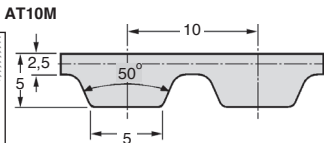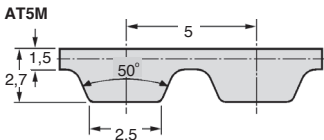

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Pitch	Price 1 to 5, per metre for width				
		10mm	16mm	25mm	32mm	50mm
AT5M	AT5	30,21 €	35,90 €	67,30 €	-	-
AT10M	AT10	-	-	58,04 €	74,08 €	82,33 €

Dimensions in mm

Our other products



ACLAPA

Magnetic stop for aluminium profile,
Magnetic stop



BScm

Knurled torque knobs
- male, Knurled threaded torque



PRF-SCREEN-5

Screen support,
Support with 5 axes of rotation



CDPC

Flanged drill bushing,
Steel



DER63

Stainless steel AC asynchronous motor
0.18 kW, 0.18kW



APB_T

Adjusting rod for clamp - Female, Bored




HTD8M_30

HTD Heavy duty timing pulley, HTD8 Steel



NT61

 Spur gear coaxial gearbox, from 5 to 14 Nm - In-line



T0

Torsion spring,
Stainless steel



CHAK

Hi-Klik TM indent hinge, Hi-Klik™ -



AT10-BAR

AT type tooth bar stock, AT10



UCP

Cast iron pillow block bearing, Cast iron

Complementary products



AT5P_AT10P

Connecting plate for AT type timing belts, AT5



AT5-10ECO

AT type timing pulley, Economy range - AT5 aluminium



AT5-BAR

AT type tooth bar stock, AT5



T5-10ECO

T type timing pulley, Economy range - T5 aluminium