

Alu Connecting plate for AT type timing belts

For AT5M and AT10M timing belts

Pitch
AT5
AT10


- For linear movements
- Rigid connecting plate
- Pitches: 5 and 10mm
- For use with **AT5M** and **AT10M** belts supplied by the metre
- Material:
Aluminium

Uses


- For closing a belt or attaching one end of a belt to a frame



Until
-40%**

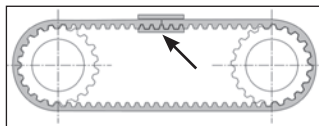

Typical application

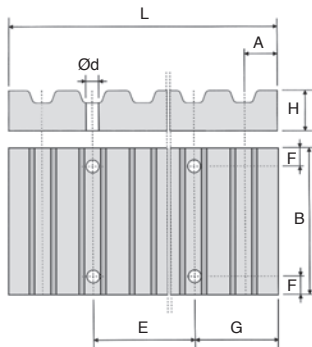

INCREASED STOCK

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pitch	B	L	H	E	F	G	Ød	A	Belt width	Stock*	Price each 1 to 5
AT5/25P	AT5	44	41,5	8	25	6	8,25	5,5	3,25	25	✓	18,30 €
AT10/25P	AT10	50	80,0	15	50	8	15,00	9,0	5,00	25	✓	25,86 €
AT10/32P	AT10	57	80,0	15	50	8	15,00	9,0	5,00	32	✓	27,39 €
AT10/50P	AT10	75	80,0	15	50	8	15,00	9,0	5,00	50	✓	30,43 €

Depending of availability - Dimensions in mm

Our other products



BFM

Flanged bronze nut,
Bronze - 1 thread



UGH16

H Type Guide units,
For Ø12 and Ø16
actuators




BLHM30

Right angled gearbox,
double output shafts,
up to 4.4 Nm



LINK64

Synchronous AC
Motor and- gearbox ,
from 1.3 to 6Nm

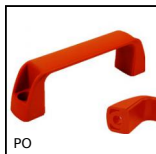

PO

Pull handle - Multi-
sector, Smooth hole



CHTRP

Single and dual
output gearboxes, Up
to 9,1 Nm



UGPL

Actuator guide kit,
Long bearing



CHN_CHNSS

Straight long link
stainless steel chain,
Stainless steel



PTA50ssEB

Articulated foot with
sheet metal base




MSP19

Masterplate®
glueable insert



AT5courroie

 AT type timing belt,
AT5 Steel cored



B

Steel bevel gear, 1:1

Complementary products



AT5M AT10M

AT type timing belt
per metre, AT10 Steel
cored polyurethane