


AT-type timing belt



Pitch AT5

Steel cored polyurethane

- 2nd generation metric profile
- Transmits a greater torque
- Pitch 5mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%
- Oil-resistant
- Low noise
- Resists stretching

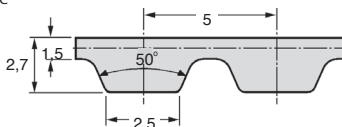

Info.

- When ordering, add the width to the part number.
E.g.: AT5/525/25

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Price each 1 to 5 for widths		
			10mm	16mm	25mm
AT5/225	225	45	16,78 €	24,98 €	34,15 €
AT5/255	255	51	17,21 €	25,28 €	34,38 €
AT5/280	280	56	17,42 €	25,49 €	34,67 €
AT5/300	300	60	17,62 €	25,63 €	34,91 €
AT5/330	330	66	17,72 €	25,95 €	35,54 €
AT5/340	340	68	17,75 €	26,10 €	35,54 €
AT5/375	375	75	18,07 €	26,53 €	36,33 €
AT5/390	390	78	18,17 €	26,82 €	36,68 €
AT5/420	420	84	18,44 €	27,18 €	37,23 €
AT5/450	450	90	18,77 €	27,89 €	37,84 €
AT5/455	455	91	18,85 €	28,01 €	38,10 €
AT5/500	500	100	19,80 €	29,53 €	40,96 €
AT5/525	525	105	20,73 €	31,22 €	43,36 €
AT5/545	545	109	21,34 €	32,42 €	45,36 €
AT5/600	600	120	22,86 €	34,91 €	48,53 €
AT5/610	610	122	23,20 €	35,28 €	49,32 €
AT5/660	660	132	23,83 €	36,33 €	50,91 €
AT5/710	710	142	24,98 €	37,84 €	52,92 €
AT5/720	720	144	25,19 €	38,10 €	53,32 €
AT5/750	750	150	25,49 €	38,92 €	54,10 €
AT5/780	780	156	26,26 €	40,15 €	56,09 €
AT5/825	825	165	27,08 €	41,76 €	58,09 €
AT5/860	860	172	27,73 €	42,96 €	60,11 €
AT5/975	975	195	30,07 €	46,95 €	66,09 €
AT5/1050	1050	210	32,24 €	50,13 €	70,43 €
AT5/1125	1125	225	33,51 €	52,49 €	74,42 €
AT5/1500	1500	300	40,15 €	64,07 €	92,36 €
AT5/2000	2000	400	56,09 €	86,79 €	122,64 €

Dimensions en mm

Our other products



PGB
Accessory-holder for
aluminium profile,
Tool holder



PAMF100EB
Articulated foot with
sheet metal base
Ø100, Articulated foot



KKP-AR
Linear bearing with
inclined ball tracks,
Heavy loads / -20°
+200°



NDS14C
Angular connector,
Universal angular
connector



CLM
Male clevis end, Steel
short



SPIT
Floor mounting
levelling plate, With
anchoring point



F7-SF-SM
Multifunction display,
Right angled
mounting bracket



PRF-P
Aluminium profile feet
support, For feet or
casters



SEV
Vertical stirrup toggle
clamp, Vertical Latch
Clamp - stainless steel



YG1
HEAVY DUTY spur
gear, Steel 35NCD6



MHWC
Double-disc flexible
coupling, Double disk



CAP805
Slat top chain
stainless steel, Large
range 805

Complementary products



GTC
Belt tensioner, For
standard applications



AT5-16ECO
AT type timing pulley,
Economy range - AT5
aluminium