

Diabolo-shaped elasto mount

Ste Stock

AT-ZY

Male / male mounting

- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials:
 - core: Steel plates
 - cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C




Uses

- Dampens sound and vibrations



High flexibility

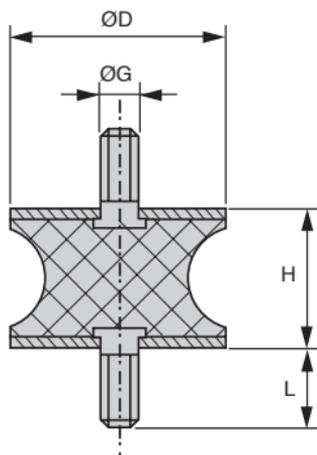

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 40+ | 100+ | 200+ |
|-------|------|------|------|------|------|------------|
| Disc. | List | -10% | -15% | -20% | -25% | On request |

| Part number | $\varnothing G$ | $\varnothing D$ | H | L | Stock* | Price each 1 to 5 |
|----------------|-----------------|-----------------|----|----|--------|----------------------|
| AT-ZY4-10-10 | M4 | 10 | 10 | 10 | ✓ | 1,85 € |
| AT-ZY6-20-15 | M6 | 20 | 15 | 18 | ✓ | 3,71 € |
| AT-ZY6-20-30 | M6 | 20 | 30 | 12 | ✓ | 3,71 € |
| AT-ZY6-25-20 | M6 | 25 | 20 | 12 | ✓ | 3,99 € |
| AT-ZY8-30-20 | M8 | 30 | 20 | 20 | ✓ | 5,45 € |
| AT-ZY8-40-30 | M8 | 40 | 30 | 20 | ✓ | 7,30 € |
| AT-ZY8-40-48 | M8 | 40 | 48 | 23 | ✓ | 10,98 € |
| AT-ZY10-40-28 | M10 | 40 | 28 | 20 | - | 8,08 € |
| AT-ZY10-46-25 | M10 | 46 | 25 | 20 | - | 11,77 € |
| AT-ZY10-50-30 | M10 | 50 | 30 | 33 | ✓ | 13,45 € |
| AT-ZY12-75-40 | M12 | 75 | 40 | 37 | - | 20,20 € |
| AT-ZY16-100-55 | M16 | 100 | 55 | 45 | - | 66,95 € |

*Depending on availability - Dimensions in mm

Our other products



CHA35
Hinge for aluminium profile, Hinge



DILC
Indexing plunger with cam, with cam



PLA
Flat magnet, Flat magnet



LPCM
Lever with cylindrical handle, Black Duroplast, steel lever



PV1R
Adjustable suction-cup support, Standard grip



PTAF100-PAMF100
Articulated fixable foot with pressed base $\varnothing 100$, $\varnothing 100$



M1
Worm and wheel set, Non hardened steel



CHAsb28
Roll of hinge without pin, Plastic hinge



RBGtc
Swivel castor with central hole, Steel - grey rubber - with



VPSS
Small 6 lobe threaded handle - male, Duroplast - Stainless



PENV
Recessed handle, screw fixing



AT5-10ECO
AT type timing pulley, Economy range - AT5 aluminium

Complementary products



ATZYSS
Stainless steel diablo shaped elasto mount, Stainless steel



CTZY
Diablo shaped elasto mount, Steel



AZY
Cylindrical elasto mount, Steel



BZY
Cylindrical elasto mount, Steel