

Diabolo-shaped elasto mount

Ste Stock

AT-ZY

Male / male mounting

- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials:
 - core: Steel plates
 - cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C




Uses

- Dampens sound and vibrations



High flexibility

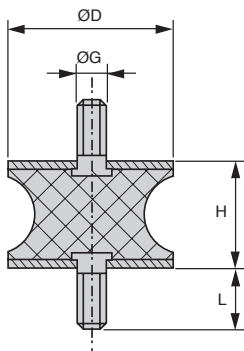

DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10	M4	10	10	10	✓	1,85 €
AT-ZY6-20-15	M6	20	15	18	✓	3,71 €
AT-ZY6-20-30	M6	20	30	12	✓	3,71 €
AT-ZY6-25-20	M6	25	20	12	✓	3,99 €
AT-ZY8-30-20	M8	30	20	20	✓	5,45 €
AT-ZY8-40-30	M8	40	30	20	✓	7,30 €
AT-ZY8-40-48	M8	40	48	23	✓	10,98 €
AT-ZY10-40-28	M10	40	28	20	-	8,08 €
AT-ZY10-46-25	M10	46	25	20	-	11,77 €
AT-ZY10-50-30	M10	50	30	33	✓	13,45 €
AT-ZY12-75-40	M12	75	40	37	-	20,20 €
AT-ZY16-100-55	M16	100	55	45	-	66,95 €

*Depending on availability - Dimensions in mm

Our other products



SF_ZZ
Deep groove ball bearing, Stainless steel



BPTRW
Cap for round tube to be welded, To be welded



BPM_LOK
Long-Lok slotted spring plunger with ball tip, LONG-LOK - Steel



 
WING
Manually tightened wing nut, Stainless steel DIN 314/315



ASH
Hoist ring for welding, for straight lifts - for welding




CHARcav
Spring hinge, to install



EPRF
High helix leadscrew, Flanged nut - up to 40mm per rotation



 BLHM30
Right angled gearbox, double output shafts, up to 4.4 Nm



AC
Strike for toggle latch, 15mm



BPPL
Mini plain bearing ball transfer unit, For countersinking



T2
T type timing belt, T2.5 Steel cored polyurethane



PO
Pull handle - Multi-sector, Tapped recessed insert

Complementary products



ATZYSS
Stainless steel diabolo shaped elasto mount, Stainless steel



CTZY
Diabolo shaped elasto mount, Steel



AZY
Cylindrical elasto mount, Steel



BZY
Cylindrical elasto mount, Steel