

# Diabolo-shaped elasto mount

Ste Stock

## AT-ZY

## Male / male mounting

- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials:
  - core: Steel plates
  - cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C




### Uses

- Dampens sound and vibrations



High flexibility

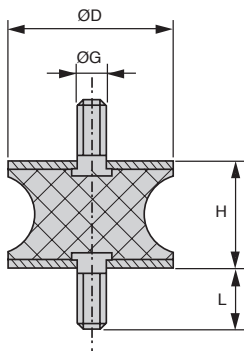

### DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	$\varnothing G$	$\varnothing D$	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10	M4	10	10	10	✓	1,85 €
AT-ZY6-20-15	M6	20	15	18	✓	3,71 €
AT-ZY6-20-30	M6	20	30	12	✓	3,71 €
AT-ZY6-25-20	M6	25	20	12	✓	3,99 €
AT-ZY8-30-20	M8	30	20	20	✓	5,45 €
AT-ZY8-40-30	M8	40	30	20	✓	7,30 €
AT-ZY8-40-48	M8	40	48	23	✓	10,98 €
AT-ZY10-40-28	M10	40	28	20	-	8,08 €
AT-ZY10-46-25	M10	46	25	20	-	11,77 €
AT-ZY10-50-30	M10	50	30	33	✓	13,45 €
AT-ZY12-75-40	M12	75	40	37	-	20,20 €
AT-ZY16-100-55	M16	100	55	45	-	66,95 €

\*Depending on availability - Dimensions in mm

## Our other products



BSPM

Miniature ballscrew,  
Nut+rolled ballscrew



BABTV

Ball lock pins lockable  
, Stainless steel



F7-P-AM

Multifunction display,  
Magnetic ring



BPVMss

Stainless steel  
miniature ball transfer  
unit, Miniature to  
screw



M1

Worm and wheel set,  
Non hardened steel



PSG3

Spur gear - precision  
range, Case hardened  
steel 20NCD2



WSS

Symmetrical S shaped  
hook, Steel




PX

Optional output shaft  
stainless steel, P  
gearboxes single  
sided outp...



RJUM05

 Drylin R® linear  
bearing housing,




RPP5

RPP heavy duty  
timing belt, RPP5



LWL

 Linear ball slide -  
Stainless steel balls,



CT

Telescopic universal  
joint, Normal duty

## Complementary products



ATZYSS

Stainless steel diablo  
shaped elasto mount,  
Stainless steel



CTZY

Diablo shaped elasto  
mount, Steel



AZY

Cylindrical elasto  
mount, Steel



BZY

Cylindrical elasto  
mount, Steel