

Diabolo-shaped elasto mount

Ste Stock

AT-ZY

Male / male mounting

- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials:
 - core: Steel plates
 - cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C




Uses

- Dampens sound and vibrations



High flexibility

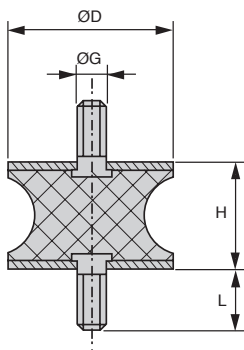

DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10	M4	10	10	10	✓	1,85 €
AT-ZY6-20-15	M6	20	15	18	✓	3,71 €
AT-ZY6-20-30	M6	20	30	12	✓	3,71 €
AT-ZY6-25-20	M6	25	20	12	✓	3,99 €
AT-ZY8-30-20	M8	30	20	20	✓	5,45 €
AT-ZY8-40-30	M8	40	30	20	✓	7,30 €
AT-ZY8-40-48	M8	40	48	23	✓	10,98 €
AT-ZY10-40-28	M10	40	28	20	-	8,08 €
AT-ZY10-46-25	M10	46	25	20	-	11,77 €
AT-ZY10-50-30	M10	50	30	33	✓	13,45 €
AT-ZY12-75-40	M12	75	40	37	-	20,20 €
AT-ZY16-100-55	M16	100	55	45	-	66,95 €

*Depending on availability - Dimensions in mm

Our other products



SUPCC

Self-centering clamping hub steel, With lock nut



YG2

HEAVY DUTY spur gear, Steel 35NCD6



BABreglable

Adjustable ball pin hardened stainless steel, adjustable



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...




TIFss

Threaded stud - DIN976A, Stainless steel




BH02

 Single housed bearing assembly, Bearing secured with circlips



H0

 Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



GPLso

Brush, silk



HK

Manual locking clamp, Manual locking clamp LWL




HK

Manual locking clamp, Manual locking clamp LRX



RFV40

 Stainless steel worm and wheel gearbox, up to 47 Nm



PRF_PSA

Shaft support for aluminium profile, Shaft support

Complementary products



ATZYSS

Stainless steel diablo shaped elasto mount, Stainless steel



CTZY

Diablo shaped elasto mount, Steel



AZY

Cylindrical elasto mount, Steel



BZY

Cylindrical elasto mount, Steel