

Diabolo-shaped elasto mount

Ste Stock

AT-ZY

Male / male mounting

- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials:
 - core: Steel plates
 - cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C




Uses

- Dampens sound and vibrations



High flexibility

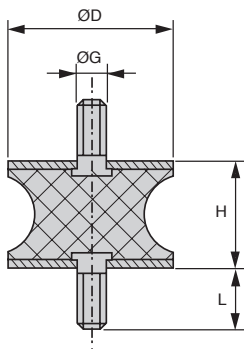

DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	$\varnothing G$	$\varnothing D$	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10	M4	10	10	10	✓	1,85 €
AT-ZY6-20-15	M6	20	15	18	✓	3,71 €
AT-ZY6-20-30	M6	20	30	12	✓	3,71 €
AT-ZY6-25-20	M6	25	20	12	✓	3,99 €
AT-ZY8-30-20	M8	30	20	20	✓	5,45 €
AT-ZY8-40-30	M8	40	30	20	✓	7,30 €
AT-ZY8-40-48	M8	40	48	23	✓	10,98 €
AT-ZY10-40-28	M10	40	28	20	-	8,08 €
AT-ZY10-46-25	M10	46	25	20	-	11,77 €
AT-ZY10-50-30	M10	50	30	33	✓	13,45 €
AT-ZY12-75-40	M12	75	40	37	-	20,20 €
AT-ZY16-100-55	M16	100	55	45	-	66,95 €

*Depending on availability - Dimensions in mm

Our other products



SHTP

Drylin® Linear table,
Economy range



CHAR

Spring hinge, screwed




PRF1932

Standard aluminium
profile, 19 x 32 mm



CHA60

 Rectangular hinge,
drilled or countersunk,
Rectangular, drilled or
C...



CHB

Worm and wheel gear
reducer, up to 41 Nm



E50

Right angle helical
reducers, from 3 to 41
Nm



 
BOXsap

Boxed set of spring
pins ISO8752, Boxed
set - Split ISO 8752




SSBRA

Stainless steel bevel
gear, 1:1



PO

 Pull handle - Multi-
sector, Smooth hole



ACLBS

Closing system for
aluminium profile, 90°



BZY_SS

Stainless steel
cylindrical elasto



DP

Dowel pin, Solid ISO
2338

Complementary products



ATZYSS

Stainless steel diablo
shaped elasto mount,
Stainless steel



CTZY

Diablo shaped elasto
mount, Steel



AZY

Cylindrical elasto
mount, Steel



BZY

Cylindrical elasto
mount, Steel