

# Diabolo-shaped elasto mount

Ste Stock

## AT-ZY

## Male / male mounting

- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials:
  - core: Steel plates
  - cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C




### Uses

- Dampens sound and vibrations



High flexibility

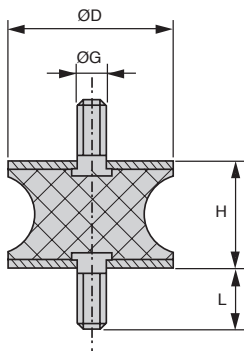

### DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10	M4	10	10	10	✓	1,85 €
AT-ZY6-20-15	M6	20	15	18	✓	3,71 €
AT-ZY6-20-30	M6	20	30	12	✓	3,71 €
AT-ZY6-25-20	M6	25	20	12	✓	3,99 €
AT-ZY8-30-20	M8	30	20	20	✓	5,45 €
AT-ZY8-40-30	M8	40	30	20	✓	7,30 €
AT-ZY8-40-48	M8	40	48	23	✓	10,98 €
AT-ZY10-40-28	M10	40	28	20	-	8,08 €
AT-ZY10-46-25	M10	46	25	20	-	11,77 €
AT-ZY10-50-30	M10	50	30	33	✓	13,45 €
AT-ZY12-75-40	M12	75	40	37	-	20,20 €
AT-ZY16-100-55	M16	100	55	45	-	66,95 €

\*Depending on availability - Dimensions in mm

## Our other products



 
PDD

Spring plunger, With sensor adaptor



BEAB

Knob star grip antibacterial, Star, anti-bacterial



QNJ

Single row cylindrical roller bearing, Single flange on inner ring



PRESS5HR

Manual workbench press, Force up to 500kg



PTA50

Articulated levelling foot, pressed base Ø50, Ø 50



BOX-TOR-G

Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x 3.00



PARF110

Pressed steel base rigid foot, Swivelling Ø110



NK40

Drylin®N miniature guiding system, Withd 40 mm



BSM\_LOK

Long-Lok spring plunger with internal



GMK17\_RG

Joint for guiding profile, Rounded



UTKswr

Utilitak® V rail, V rail



YG2

HEAVY DUTY spur gear, Steel 35NCD6

## Complementary products



ATZYSS

Stainless steel diablo shaped elasto mount, Stainless steel



CTZY

Diablo shaped elasto mount, Steel



AZY

Cylindrical elasto mount, Steel



BZY

Cylindrical elasto mount, Steel