

Sta Diabolo shaped stainless steel anti vibration mount

Male / male mounting

AT-ZYss


- Radial elasticity greater than axial elasticity
- Works under both compression or shear
- Materials :
 - Core : Stainless steel (A2)
 - Cylinder : Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

Applications

- Dampening sound and vibrations



High flexibility

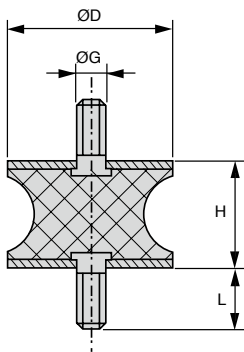

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10/SS	M4	10	10	10	✓	3,31 €
AT-ZY6-20-15/SS	M6	20	15	18	✓	4,95 €
AT-ZY6-20-30/SS	M6	20	30	12	-	5,51 €
AT-ZY6-25-20/SS	M6	25	20	18	-	5,51 €
AT-ZY8-30-20/SS	M8	30	20	20	✓	8,45 €
AT-ZY8-40-30/SS	M8	40	30	20	✓	14,92 €
AT-ZY8-40-48/SS	M8	40	48	23	✓	15,47 €
AT-ZY10-40-28/SS	M10	40	28	20	✓	14,92 €
AT-ZY10-46-25/SS	M10	46	25	20	-	17,67 €
AT-ZY10-50-30/SS	M10	50	30	33	✓	17,67 €

*Depending on availability - Dimensions in mm

Our other products



SHW
Plain washer, A2
Stainless steel



RPCtc
Swivel castor with
central hole, Steel -
Polyamide - with
double brake



VRBS
Folding lifting ring for
welding, Folding - for
welding



EPE
Wing nuts Hygienic
Design®, Narrow



VDSQCB
Sliding lock
adjustment system,
Blocking wedge



SLB
Indexing plunger,
steel class 5.8




WBGV
Lifting ring, Threaded



MDR
Dee shackle with eye
bolt, Steel



TPEpbd
Castor for aluminium
profile, Swivel with
brake

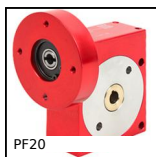

PF20
Worm and wheel gear
reducer, up to 5 Nm



SLHVlok
Horizontal toggle
clamp, Horizontal
toggle clamp / vertical



ETP
Modular handle for
aluminium profile,
Modular handle

Complementary products



ATZY
Diabolo shaped elasto
mount, Steel



CTZYSS
Stainless steel diabolo
shaped elasto mount,
Stainless steel



AZY
Cylindrical elasto
mount, Steel



DPAR_DKON
Progressive stop,
Steel