

# Sta Diabolo shaped stainless steel anti vibration mount

Male / male mounting

AT-ZYss


- Radial elasticity greater than axial elasticity
- Works under both compression or shear
- Materials :
  - Core : Stainless steel (A2)
  - Cylinder : Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

## Applications

- Dampening sound and vibrations



High flexibility

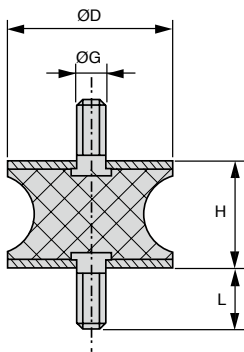

## DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10/SS	M4	10	10	10	✓	3,31 €
AT-ZY6-20-15/SS	M6	20	15	18	✓	4,95 €
AT-ZY6-20-30/SS	M6	20	30	12	-	5,51 €
AT-ZY6-25-20/SS	M6	25	20	18	-	5,51 €
AT-ZY8-30-20/SS	M8	30	20	20	✓	8,45 €
AT-ZY8-40-30/SS	M8	40	30	20	✓	14,92 €
AT-ZY8-40-48/SS	M8	40	48	23	✓	15,47 €
AT-ZY10-40-28/SS	M10	40	28	20	✓	14,92 €
AT-ZY10-46-25/SS	M10	46	25	20	-	17,67 €
AT-ZY10-50-30/SS	M10	50	30	33	✓	17,67 €

\*Depending on availability - Dimensions in mm

## Our other products



NSB

Standard linear bearing housing, Closed - Long



ADL\_M

Male eye bolt conforms to DIN580, Steel



PRF\_PIV

Internal hinge pin for aluminium profile, Internal hinge pin



PCF4

Conical flexible mount, Square base plate



HLC24

Right angle spiro bevel gearbox, Up to 78Nm




G0

Steel spur gear, Steel 20NCD2



EFTC

Fixing support, Stainless steel

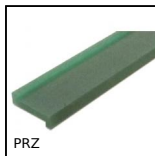


PRZ

Wear strip for slat top chain, Z profile to be filled



DOG258

 Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



RPPM

RPP type belt per metre, RPP14 Steel cored polyurethane



CCLSS

Stainless steel wire thimble, Stainless steel



CHA60

Rectangular hinge, drilled or countersunk, Rectangular, drilled or C...

## Complementary products



ATZY

Diabolo shaped elasto mount, Steel



CTZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel



AZY

Cylindrical elasto mount, Steel



DPAR\_DKON

Progressive stop, Steel