

# Sta Diabolo shaped stainless steel anti vibration mount

Male / male mounting

AT-ZYss


- Radial elasticity greater than axial elasticity
- Works under both compression or shear
- Materials :
  - Core : Stainless steel (A2)
  - Cylinder : Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

## Applications

- Dampening sound and vibrations



High flexibility

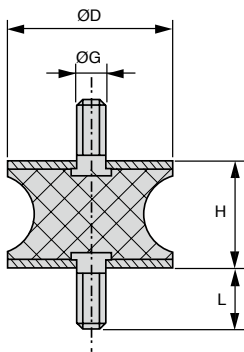

## DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10/SS	M4	10	10	10	✓	3,31 €
AT-ZY6-20-15/SS	M6	20	15	18	✓	4,95 €
AT-ZY6-20-30/SS	M6	20	30	12	-	5,51 €
AT-ZY6-25-20/SS	M6	25	20	18	-	5,51 €
AT-ZY8-30-20/SS	M8	30	20	20	✓	8,45 €
AT-ZY8-40-30/SS	M8	40	30	20	✓	14,92 €
AT-ZY8-40-48/SS	M8	40	48	23	✓	15,47 €
AT-ZY10-40-28/SS	M10	40	28	20	✓	14,92 €
AT-ZY10-46-25/SS	M10	46	25	20	-	17,67 €
AT-ZY10-50-30/SS	M10	50	30	33	✓	17,67 €

\*Depending on availability - Dimensions in mm

## Our other products



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



AC

Strike for toggle latch, 12,13,18 and 20mm



ASL

45° Hoist ring for welding, for 45° lifts - for welding



CABPVC

PVC covered galvanised steel cable, Galvanised steel with



GE\_ES\_2RS

Spherical bushing, Steel / steel with seals



BCM\_MPBT

Modular cylindrical brush, PBT polyester bristles



BOX-NINA

Self locking nut - DIN985, Box set of steel nuts



SLHVlok

Horizontal toggle clamp, Horizontal toggle clamp / vertical foot



PRF\_GAL

Roller for aluminium profile, Fixing kit for roller eccentric



DSF

Slip friction clutch, 4 to 2600 Nm



ACL

Joints for aluminium profile, Variable angle hinge



PRS50

Stainless steel articulated foot Ø50, Ø 50

## Complementary products



ATZY

Diabolo shaped elasto mount, Steel



CTZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel



AZY

Cylindrical elasto mount, Steel



DPAR\_DKON

Progressive stop, Steel