

Sta Diabolo shaped stainless steel anti vibration mount

Male / male mounting

AT-ZYss


- Radial elasticity greater than axial elasticity
- Works under both compression or shear
- Materials :
 - Core : Stainless steel (A2)
 - Cylinder : Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

Applications

- Dampening sound and vibrations



High flexibility

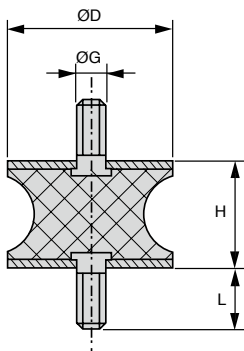

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10/SS	M4	10	10	10	✓	3,31 €
AT-ZY6-20-15/SS	M6	20	15	18	✓	4,95 €
AT-ZY6-20-30/SS	M6	20	30	12	-	5,51 €
AT-ZY6-25-20/SS	M6	25	20	18	-	5,51 €
AT-ZY8-30-20/SS	M8	30	20	20	✓	8,45 €
AT-ZY8-40-30/SS	M8	40	30	20	✓	14,92 €
AT-ZY8-40-48/SS	M8	40	48	23	✓	15,47 €
AT-ZY10-40-28/SS	M10	40	28	20	✓	14,92 €
AT-ZY10-46-25/SS	M10	46	25	20	-	17,67 €
AT-ZY10-50-30/SS	M10	50	30	33	✓	17,67 €

*Depending on availability - Dimensions in mm

Our other products



PC5505S

Chain sprocket -
Stainless steel,
12.7mm (DIN 08B-1)



SCR

Suction cup threaded
insert, Insert for
suction cup - Socket
screw



CHAE4080PA

Symmetrical decorative
screwed hinge,
Polyamide



SFE

Female rod ends,
Stainless steel / PTFE



PR40

Articulated foot Ø50,
Ø 50



PRES3HR

Manual workbench
press, Force up to
400kg



PTA150

Articulated levelling
foot, pressed base
Ø150, Ø 150



SBF

Sealed flange bearing
unit for Food Industry,
cover



DBL820

Idler for slat top
chain, Ranges 820



FR

Steel thread inserts,
Steel



HCSS

Set screw with
hexagonal socket,



SHW

Plain washer, A2
Stainless steel

Complementary products



ATZY

Diabolo shaped elasto
mount, Steel



CTZYSS

Stainless steel diabolo
shaped elasto mount,
Stainless steel



AZY

Cylindrical elasto
mount, Steel



DPAR_DKON

Progressive stop,
Steel