

Sta Diabolo shaped stainless steel anti vibration mount

Male / male mounting

AT-ZYss


- Radial elasticity greater than axial elasticity
- Works under both compression or shear
- Materials :
 - Core : Stainless steel (A2)
 - Cylinder : Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

Applications

- Dampening sound and vibrations



High flexibility

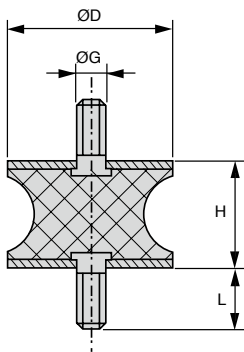

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10/SS	M4	10	10	10	✓	3,31 €
AT-ZY6-20-15/SS	M6	20	15	18	✓	4,95 €
AT-ZY6-20-30/SS	M6	20	30	12	-	5,51 €
AT-ZY6-25-20/SS	M6	25	20	18	-	5,51 €
AT-ZY8-30-20/SS	M8	30	20	20	✓	8,45 €
AT-ZY8-40-30/SS	M8	40	30	20	✓	14,92 €
AT-ZY8-40-48/SS	M8	40	48	23	✓	15,47 €
AT-ZY10-40-28/SS	M10	40	28	20	✓	14,92 €
AT-ZY10-46-25/SS	M10	46	25	20	-	17,67 €
AT-ZY10-50-30/SS	M10	50	30	33	✓	17,67 €

*Depending on availability - Dimensions in mm

Our other products



PDD

Actuating plunger,
Non-rotating detector
shaft



S2B

Short linear bearing
housing, Closed - Slim



HW_HT

Half-rail guide, Rail



BLM

Spring loaded plunger
with ball tip, Plastic
body



BCH_SS

Mushroom headed
button, M3 to M8



BABss

303 Stainless steel
ball pin, 303 Stainless
steel



TOL

Swivel head, Long



RPCplss

Fixed castor with
plate, Stainless steel -
Polyamide



SLB

Indexing plunger,
stainless steel



FTSN

Supported shaft for
linear guide, Steel
shaft / Aluminium



SH1

Parallel axis helical
gear, Steel 20NCD2



PRF_CLIP_45

Cable clip for
aluminium profile, For
cable chute

Complementary products



ATZY

Diabolo shaped elasto
mount, Steel



CTZYSS

Stainless steel diabolo
shaped elasto mount,
Stainless steel



AZY

Cylindrical elasto
mount, Steel



DPAR_DKON

Progressive stop,
Steel