

# Sta Diabolo shaped stainless steel anti vibration mount

Male / male mounting

AT-ZYss


- Radial elasticity greater than axial elasticity
- Works under both compression or shear
- Materials :
  - Core : Stainless steel (A2)
  - Cylinder : Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

## Applications

- Dampening sound and vibrations



High flexibility

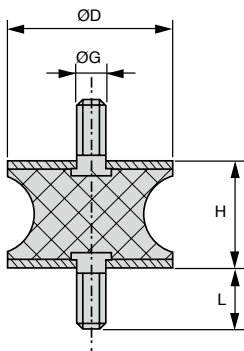

## DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10/SS	M4	10	10	10	✓	3,31 €
AT-ZY6-20-15/SS	M6	20	15	18	✓	4,95 €
AT-ZY6-20-30/SS	M6	20	30	12	-	5,51 €
AT-ZY6-25-20/SS	M6	25	20	18	-	5,51 €
AT-ZY8-30-20/SS	M8	30	20	20	✓	8,45 €
AT-ZY8-40-30/SS	M8	40	30	20	✓	14,92 €
AT-ZY8-40-48/SS	M8	40	48	23	✓	15,47 €
AT-ZY10-40-28/SS	M10	40	28	20	✓	14,92 €
AT-ZY10-46-25/SS	M10	46	25	20	-	17,67 €
AT-ZY10-50-30/SS	M10	50	30	33	✓	17,67 €

\*Depending on availability - Dimensions in mm

## Our other products



 
BIM

Indexing plunger mini,  
miniature



RFVbr

Stainless steel  
reaction arm,  
Reaction arm



KGS

Ball screw, supplied by  
the metre, Rolled  
ballscrew, per metre



DOMI80

Connecting kits, XZ  
linking kit



F7-SN

Multifunction display,  
Articulated support



MLY\_SS

Stainless steel bow  
shackle with eye bolt,  
Stainless steel



CLSCLP\_SS

Clevis components,  
short version,  
Stainless steel - short  
range



BDP2R

Adjustable support  
arm, Increased grip



SVG

Adjustable latch  
clamp with strike  
plate, Stroke from




APB\_F

Adjusting rod for  
clamp - Male,  
Threaded



DOMI30

 Connecting kits, XY  
linking kit



TBL

Mini leadscrew table  
with metric thread,  
Base plate

## Complementary products



ATZY

Diabolo shaped elasto  
mount, Steel



CTZYSS

Stainless steel diabolo  
shaped elasto mount,  
Stainless steel



AZY

Cylindrical elasto  
mount, Steel



DPAR\_DKON

Progressive stop,  
Steel