

Sta Diabolo shaped stainless steel anti vibration mount

Male / male mounting

AT-ZYss


- Radial elasticity greater than axial elasticity
- Works under both compression or shear
- Materials :
 - Core : Stainless steel (A2)
 - Cylinder : Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

Applications

- Dampening sound and vibrations



High flexibility

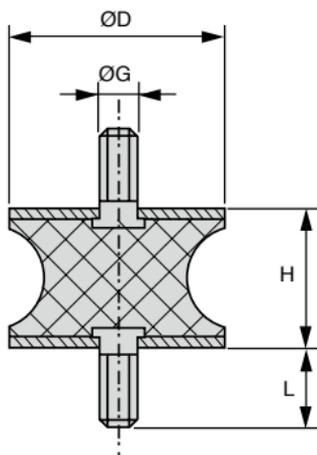

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10/SS	M4	10	10	10	✓	3,31 €
AT-ZY6-20-15/SS	M6	20	15	18	✓	4,95 €
AT-ZY6-20-30/SS	M6	20	30	12	-	5,51 €
AT-ZY6-25-20/SS	M6	25	20	18	-	5,51 €
AT-ZY8-30-20/SS	M8	30	20	20	✓	8,45 €
AT-ZY8-40-30/SS	M8	40	30	20	✓	14,92 €
AT-ZY8-40-48/SS	M8	40	48	23	✓	15,47 €
AT-ZY10-40-28/SS	M10	40	28	20	✓	14,92 €
AT-ZY10-46-25/SS	M10	46	25	20	-	17,67 €
AT-ZY10-50-30/SS	M10	50	30	33	✓	17,67 €

*Depending on availability - Dimensions in mm

Our other products



BLHT20

Right angled gearbox,
from 0.66 to 1.77 Nm



GB-RA

Brass spur gear, Brass
CuZn39Pb3



DCG

Suction cup, 2.5
bellows, silicon



CHA38_SS

Stainless steel face
frame hinge, Surface
mount



M0

Worm and wheel set,
Non hardened steel



PW_PWG3

Worm - precision
range, Steel




DHX

Dowel pin internal
thread, Extractable
DIN 7979D



DOMI30

Connecting kits, XY
linking kit

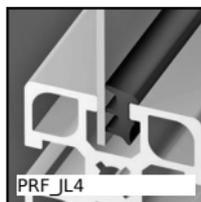

PRF_JL4

Lip seal for panel,
Door seal - Ø 4mm



NSA

Adjustable clamp,
Articulated



E15

Right angle helical
reducers, from 0.40 to



TS01_TW01

Drylin® T linear slide,
up to 7000 N

Complementary products



ATZY

Diabolo shaped elasto
mount, Steel



CTZYSS

Stainless steel diabolo
shaped elasto mount,
Stainless steel



AZY

Cylindrical elasto
mount, Steel



DPAR_DKON

Progressive stop,
Steel