


Recommended for use
with RJUM linear bearings

AWMP

- Shaft recommended for use with DryLin® RJUM bearings
- Material: Drawn aluminium AIMgSi0 5F22
- Linearity conforms to DIN EN574-3
- Hardness: 75HB
- Hard anodised surface
- **Not compatible with linear ball bearings, see Z-A or Z-B shafts instead**

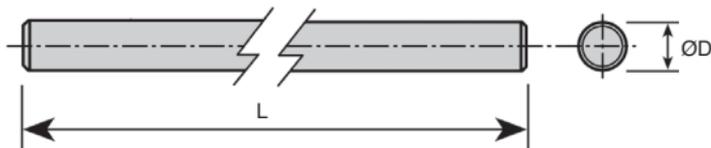

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-15%	-20%	On request

Part number	Version	Diameter ØD (mm)	Tolerance	Length L (mm)	Weight (kg/m)	Stock*	Price each 1 to 5
AWMP8-1000	Solid shaft	8	h8	1000	0,14	✓	28,54 €
AWMP10-1000	Solid shaft	10	h8	1000	0,22	✓	30,38 €
AWMP12-1000	Solid shaft	12	h8	1000	0,32	✓	42,86 €
AWMP16-1000	Solid shaft	16	h8	1000	0,57	-	52,02 €
AWMP20-1000	Solid shaft	20	h8	1000	0,89	-	70,61 €
AWMP25-1000	Solid shaft	25	h8	1000	1,41	-	97,49 €
AWM30-1000	Hollow shaft	30x7,5	h10	1000	1,48	-	153,16 €
AWM40-1000	Hollow shaft	40x10	h10	1000	2,63	-	270,65 €
AWM50-1000	Hollow shaft	50x11	h10	1000	3,75	-	358,77 €

* Depending on availability - Dimensions in mm