 


Recommended for use
with RJUM linear bearings

AWMP

- Shaft recommended for use with DryLin® RJUM bearings
- Material: Drawn aluminium AIMgSi0 5F22
- Linearity conforms to DIN EN574-3
- Hardness: 75HB
- Hard anodised surface
- Specific electric resistance: 4×10^{11} Ohm mm^2/m
- Chemical resistance: $2 < \text{pH} < 9$
- **Not compatible with linear ball bearings, see Z-A or Z-B shafts instead**


**DISCOUNTS**

Qty	1+	5+	10+	25+
Disc.	List -15%	List -20%	On request	On request

Part number	Version	Diameter ØD (mm)	Tolerance	Length L (mm)	Weight (kg/m)	Stock*	Price each 1 to 5
AWMP8-1000	Solid shaft	8	h8	1000	0,14	✓	20,42 €
AWMP10-1000	Solid shaft	10	h8	1000	0,22	✓	26,31 €
AWMP12-1000	Solid shaft	12	h8	1000	0,32	✓	32,78 €
AWMP16-1000	Solid shaft	16	h8	1000	0,57	✓	45,03 €
AWMP20-1000	Solid shaft	20	h8	1000	0,89	✓	61,10 €
AWMP25-1000	Solid shaft	25	h8	1000	1,41	✓	82,43 €
AWM30-1000	Hollow shaft	30x7,5	h10	1000	1,48	-	129,46 €
AWM40-1000	Hollow shaft	40x10	h10	1000	2,63	-	243,22 €
AWM50-1000	Hollow shaft	50x11	h10	1000	3,75	-	322,40 €

*Depending on availability - Dimensions in mm

Our other products

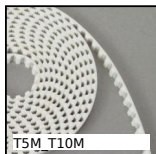

T5M T10M
T type timing belt per metre, T10 Steel cored polyurethane



BCM_TP
Modular cylindrical brush, Tampico bristles



ACLEPP
Right angled bracket for aluminium profile, 4 holes



RBN
Wheel, Rubber tyre - Polypropylene rim



NPTF30
Spacer for tube carrier, Fixing accessory Ø14 to Ø20



PSG125HC
Skive hobbled spur gears - precision range, Case hardened steel 20NCD2



BLHT70
Right angled gearbox, from 26 to 128 Nm




RTE
Rotex®, jaw coupling, cast iron



RT25
Self-centering flanged locking assembly, Medium/high torque



 SH4
Parallel axis helical gear, Steel 20NCD2



BOX-TOR-TOOL
Box set of tool for Nitrile O-rings, Extraction tools



ZA
Shaft for linear guides, Hardened ground steel

Complementary products



RJUM01
Closed polymer Drylin® R bearing, Drylin® R



FGWA
End support, With base



SFWR
End support, Surface mounting



RJUM05
Drylin® linear bearing housing, Closed - Slim