


- Axle for idler pulley
- Material:  
Zinc plated C45 steel

### Info.

- Compatible with **PTGP, PTGT** and **PTGR** tensioner pulleys

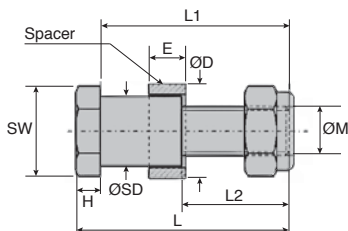

**INCREASED STOCK**

### DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	ØM	ØSD	ØD	L	L1	L2	E	SW	H	Stock*	Price each 1 to 9
AXTR-M8	M8	8	12	30	25	14,5	4	13	5	✓	7,11 €
AXTR-M12	M12	17	23	53	47	26,5	9	22	6	✓	5,59 €


Dimensions in mm

## Our other products



AFA

Locking pin, with ring

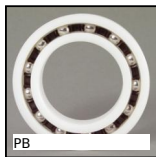

PB

Plastic deep groove ball bearing, Plastic - balls material : staine...



FR

Steel thread inserts, Steel



CHAGC-AL

Screw-in garnet hinge, Screw-on



VBFP

Small 6 lobe threaded handle - female, Duroplast - Brass



BOX-TOR-ORFS

Box set of Nitrile O-rings NBR90Sh A, 7.65 x 1.78mm to 37.82 x 1.78



Q7

Angular contact ball bearing, Steel



ASL

45° Hoist ring for welding, for 45° lifts - for welding



PRF\_GAL

Roller for aluminium profile, Hollow roller



PITAss

Locking bolt, with T handle



GB-RA

Brass spur gear, Brass CuZn39Pb3



CHB

Worm and wheel gear reducer, up to 73 Nm

## Complementary products



PTGP

Tensioner pulley, For flat belts



PTGT

Tensioner pulley, For V belts



PTGR

Tensioner pulley, For round belts