

Diabolo-shaped anti vibration mount **Ste** **Stock**

AT-ZY

Male / male mounting

- **Radial elasticity greater than axial elasticity**
- Works under compression or shear
- **Materials:**
 - core: Steel plates
 - cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- **Working temp: -40°C to +70°C**




Applications

- Dampening sound and vibrations



High flexibility

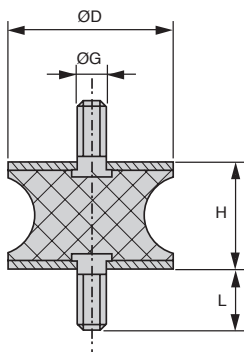

DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-20%	-30%	-40%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10	M4	10	10	10	✓	2,27 €
AT-ZY6-20-15	M6	20	15	18	✓	4,62 €
AT-ZY6-20-30	M6	20	30	12	✓	4,62 €
AT-ZY6-25-20	M6	25	20	12	✓	4,96 €
AT-ZY8-30-20	M8	30	20	20	✓	6,79 €
AT-ZY8-40-30	M8	40	30	20	✓	9,09 €
AT-ZY8-40-48	M8	40	48	23	✓	13,71 €
AT-ZY10-40-28	M10	40	28	20	-	10,08 €
AT-ZY10-46-25	M10	46	25	20	-	14,67 €
AT-ZY10-50-30	M10	50	30	33	-	16,78 €
AT-ZY12-75-40	M12	75	40	37	-	25,23 €
AT-ZY16-100-55	M16	100	55	45	-	83,66 €

*Depending on availability - Dimensions in mm

Stal Diabolo shaped stainless steel anti vibration mount

Male / male mounting

AT-ZYss

- Radial elasticity greater than axial elasticity
- Works under both compression or shear
- Materials :
 - Core : Stainless steel (A2)
 - Cylinder : Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

Applications


- Dampening sound and vibrations



stainless steel



High flexibility

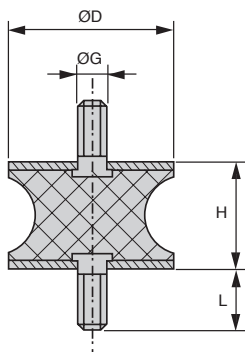

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
AT-ZY4-10-10/SS	M4	10	10	10	✓	4,50 €
AT-ZY6-20-15/SS	M6	20	15	18	✓	6,76 €
AT-ZY6-20-30/SS	M6	20	30	12	✓	7,51 €
AT-ZY6-25-20/SS	M6	25	20	18	✓	7,51 €
AT-ZY8-30-20/SS	M8	30	20	20	✓	11,55 €
AT-ZY8-40-30/SS	M8	40	30	20	✓	20,43 €
AT-ZY8-40-48/SS	M8	40	48	23	✓	21,19 €
AT-ZY10-40-28/SS	M10	40	28	20	-	20,43 €
AT-ZY10-46-25/SS	M10	46	25	20	-	24,22 €
AT-ZY10-50-30/SS	M10	50	30	33	-	24,22 €

*Depending on availability - Dimensions in mm

Diabolo-shaped anti vibration mount **Ste** **Stock**


CT-ZY

Female / female mounting


- **Radial elasticity greater than axial elasticity**
- Works under compression or shear
- Materials:
 - core: Steel plates
 - cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- Working temp: -40°C to +70°C

Applications

- Dampening sound and vibrations

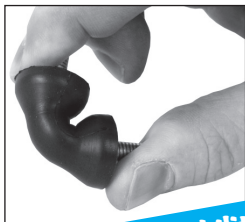

High flexibility

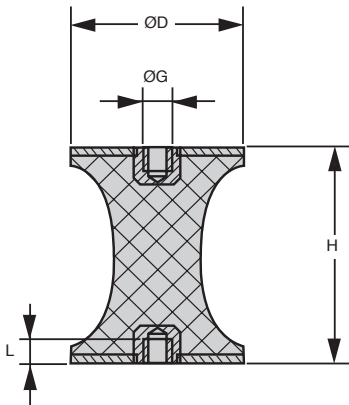

DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc. List	-10%	-15%	-20%	-25%	On request	

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10	M4	10	10	4	✓	2,27 €
CT-ZY8-30-20	M8	30	20	8	✓	6,79 €
CT-ZY8-40-48	M8	40	48	8	✓	13,71 €
CT-ZY10-50-30	M10	50	30	10	-	24,05 €

*Depending on availability - Dimensions in mm

Stal Diabolo shaped stainless steel anti vibration mount

Female / female mounting

CT-ZYss

- **Radial elasticity greater than axial elasticity**
- Works under both compression and shear
- **Materials :**
 - Core: Stainless steel (A2)
 - Cylinder: Rubber
- **Hardness NK55-60 Shore A**
- Working temp: -40°C to +70°C

Applications


- Dampening sound and vibrations



stainless steel



High flexibility

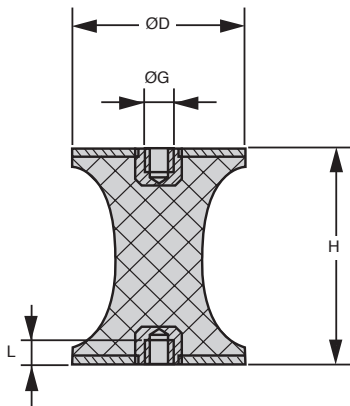

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10/SS	M4	10	10	4	✓	4,49 €
CT-ZY8-30-20/SS	M8	30	20	8	✓	10,19 €
CT-ZY8-40-48/SS	M8	40	48	8	✓	21,13 €
CT-ZY10-50-30/SS	M10	50	30	10	-	33,26 €

*Depending on availability - Dimensions in mm

Cylindrical anti vibration mount **Ste** **Stock**

A-ZY

Male / male mounting

- Radial elasticity greater than axial elasticity
- Works under compression or shear
- Materials
core: Steel plates
cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- Working temp: -40°C to +70°C

applications



- Dampening sound and vibrations

Options


- Stainless steel version available on request

Info.


- Not sold individually, please contact us for details
- Values for loads and rigidity are given as a guide only

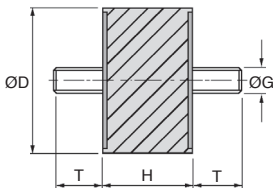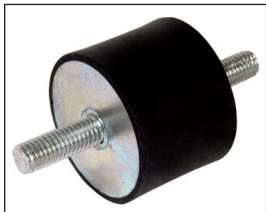


**From size M3
upwards**

 

Compression

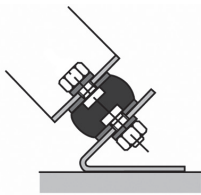

Compression
Shear

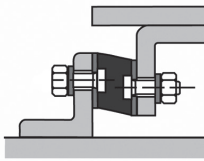

Shear

DISCOUNTS **A**

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

DISCOUNTS **B**

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	T	Compression stiffness (N/mm)		Shear stiffness (N/mm)		Stock*	Price each 1 to 5
					Max. load(N)	Max. load(N)	Max. load(N)	Max. load(N)		
A-ZY3-8-8	M3	8	8	6	-	-	-	-	✓	A 2,11 €
A-ZY4-10-10	M4	10	10	10	44	43	9	15	✓	A 1,94 €
A-ZY4-15-7	M4	15	7	10	174	95	29	35	-	A 1,84 €
A-ZY4-15-8	M4	15	8	10	160	95	27	35	-	A 1,84 €
A-ZY4-15-10	M4	15	10	10	124	95	24	35	-	A 1,94 €
A-ZY4-15-15	M4	15	15	10	61	95	13	35	✓	A 2,03 €
A-ZY4-15-20	M4	15	20	10	-	-	-	-	✓	A 2,28 €
A-ZY5-15-15	M5	15	15	8	61	95	24	35	✓	A 2,11 €
A-ZY6-20-8	M6	20	8	18	307	170	36	60	✓	A 2,28 €
A-ZY6-20-10	M6	20	10	18	-	-	-	-	✓	A 2,37 €
A-ZY6-20-15	M6	20	15	18	130	170	24	60	✓	A 2,37 €
A-ZY6-20-20	M6	20	20	18	-	-	-	-	✓	A 2,55 €
A-ZY6-20-25	M6	20	25	18	85	170	17	60	✓	A 2,55 €
A-ZY6-25-10	M6	25	10	18	750	280	74	95	✓	A 2,55 €
A-ZY6-25-15	M6	25	15	18	-	-	-	-	✓	A 2,89 €
A-ZY6-25-20	M6	25	20	18	-	-	-	-	✓	A 3,07 €
A-ZY6-25-25	M6	25	25	18	-	-	-	-	✓	A 3,27 €
A-ZY8-30-15	M8	30	15	20	525	400	58	140	✓	A 3,87 €
A-ZY8-30-20	M8	30	20	20	204	400	40	140	✓	A 4,13 €
A-ZY8-30-25	M8	30	25	20	-	-	-	-	✓	A 4,30 €
A-ZY8-30-30	M8	30	30	20	108	400	25	140	✓	A 4,85 €
A-ZY8-30-40	M8	30	40	20	-	-	-	-	✓	A 5,72 €
A-ZY8-40-25	M8	40	25	23	-	-	-	-	✓	A 6,34 €
A-ZY8-40-30	M8	40	30	23	213	650	43	250	✓	A 6,61 €
A-ZY10-40-25	M10	40	25	28	-	-	-	-	-	A 6,34 €
A-ZY10-40-30	M10	40	30	28	-	-	-	-	✓	A 6,70 €
A-ZY10-50-20	M10	50	20	28	857	1000	110	400	✓	A 8,18 €
A-ZY10-50-30	M10	50	30	28	375	1000	66	400	✓	A 9,24 €
A-ZY10-50-40	M10	50	40	28	260	1000	53	400	✓	A 10,57 €
A-ZY10-50-45	M10	50	45	28	215	1000	43	400	-	A 11,11 €
A-ZY10-50-50	M10	50	50	28	-	-	-	-	✓	A 11,46 €
A-ZY10-60-40	M10	60	40	28	-	-	-	-	-	A 16,00 €
A-ZY10-70-45	M10	70	45	28	-	-	-	-	✓	A 22,83 €
A-ZY12-60-40	M12	60	40	33	-	-	-	-	✓	B 10,59 €
A-ZY12-75-25	M12	75	25	37	2710	2300	211	850	✓	B 12,46 €
A-ZY12-75-40	M12	75	40	37	734	2300	117	850	✓	B 13,78 €
A-ZY12-75-50	M12	75	50	37	506	2300	91	850	-	B 16,05 €
A-ZY12-75-55	M12	75	55	37	417	2300	78	850	✓	B 16,71 €
A-ZY16-100-40	M16	100	40	41	1970	4200	257	1600	-	B 25,06 €
A-ZY16-100-55	M16	100	55	41	892	4200	145	1600	-	B 27,93 €
A-ZY16-100-75	M16	100	75	41	-	-	-	-	-	B 37,67 €

* Depending on availability - Dimensions in mm

A-ZYss

Male / male mounting

- Radial elasticity greater than axial elasticity.
- Works under compression or shear
- Materials:
 - Core: Steel plates
 - Cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- Working temp: -40°C to +70°C

stainless steel




Applications


- Dampening sound and vibrations

Info.


- Not sold individually, please contact us for details
- Values for loads and rigidity are given as a guide only

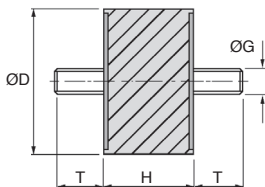


From size M3 upwards

 

Compression

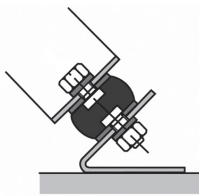

Compression Shear

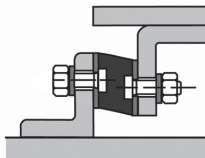

Shear

DISCOUNTS **A**

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

DISCOUNTS **B**

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	T	Compression		Shear		Stock*	Price each 1 to 5
					stiffness (N/mm)	Max. load (N)	stiffness (N/mm)	Max. load (N)		
A-ZY3-8-8/SS	M3	8	8	6	-	-	-	-	✓	A 3,81 €
A-ZY4-10-10/SS	M4	10	10	10	44	43	9	15	✓	A 3,81 €
A-ZY4-15-7/SS	M4	15	7	10	174	95	29	35	-	A 5,48 €
A-ZY4-15-8/SS	M4	15	8	10	160	95	27	35	-	A 3,41 €
A-ZY4-15-10/SS	M4	15	10	10	124	95	24	35	✓	A 3,55 €
A-ZY4-15-15/SS	M4	15	15	10	61	95	13	35	-	A 3,55 €
A-ZY4-15-20/SS	M4	15	20	10	-	-	-	-	✓	A 4,04 €
A-ZY5-15-15/SS	M5	15	15	8	61	95	24	35	✓	A 3,43 €
A-ZY6-20-8/SS	M6	20	8	18	307	170	36	60	-	A 5,85 €
A-ZY6-20-10/SS	M6	20	10	18	-	-	-	-	✓	A 4,02 €
A-ZY6-20-15/SS	M6	20	15	18	130	170	24	60	✓	A 4,08 €
A-ZY6-20-20/SS	M6	20	20	18	-	-	-	-	✓	A 4,69 €
A-ZY6-20-25/SS	M6	20	25	18	85	170	17	60	✓	A 4,69 €
A-ZY6-25-10/SS	M6	25	10	18	750	280	74	95	✓	A 6,16 €
A-ZY6-25-15/SS	M6	25	15	18	-	-	-	-	-	A 4,61 €
A-ZY6-25-20/SS	M6	25	20	18	-	-	-	-	✓	A 5,37 €
A-ZY6-25-25/SS	M6	25	25	18	-	-	-	-	✓	A 5,93 €
A-ZY8-30-15/SS	M8	30	15	20	525	400	58	140	✓	A 7,03 €
A-ZY8-30-20/SS	M8	30	20	20	204	400	40	140	✓	A 7,28 €
A-ZY8-30-25/SS	M8	30	25	20	-	-	-	-	✓	A 7,89 €
A-ZY8-30-30/SS	M8	30	30	20	108	400	25	140	✓	A 7,89 €
A-ZY8-30-40/SS	M8	30	40	20	-	-	-	-	✓	A 9,68 €
A-ZY8-40-25/SS	M8	40	25	23	-	-	-	-	✓	A 10,54 €
A-ZY8-40-30/SS	M8	40	30	23	213	650	43	250	✓	A 9,50 €
A-ZY10-40-25/SS	M10	40	25	28	-	-	-	-	✓	A 9,04 €
A-ZY10-40-30/SS	M10	40	30	28	-	-	-	-	✓	A 10,83 €
A-ZY10-50-20/SS	M10	50	20	28	857	1000	110	400	✓	A 13,04 €
A-ZY10-50-30/SS	M10	50	30	28	375	1000	66	400	✓	A 15,75 €
A-ZY10-50-40/SS	M10	50	40	28	260	1000	53	400	✓	A 19,22 €
A-ZY10-50-45/SS	M10	50	45	28	215	1000	43	400	✓	A 15,88 €
A-ZY10-50-50/SS	M10	50	50	28	-	-	-	-	✓	A 20,84 €
A-ZY10-60-40/SS	M10	60	40	28	-	-	-	-	-	A 24,22 €
A-ZY10-70-45/SS	M10	70	45	28	-	-	-	-	-	A 33,34 €
A-ZY12-60-40/SS	M12	60	40	33	-	-	-	-	-	B 21,43 €
A-ZY12-75-25/SS	M12	75	25	37	2710	2300	211	850	✓	B 25,80 €
A-ZY12-75-40/SS	M12	75	40	37	734	2300	117	850	✓	B 28,40 €
A-ZY12-75-50/SS	M12	75	50	37	506	2300	91	850	-	B 32,29 €
A-ZY12-75-55/SS	M12	75	55	37	417	2300	78	850	-	B 34,21 €
A-ZY16-100-40/SS	M16	100	40	41	1970	4200	257	1600	-	B 60,64 €
A-ZY16-100-55/SS	M16	100	55	41	892	4200	145	1600	-	B 66,60 €
A-ZY16-100-75/SS	M16	100	75	41	-	-	-	-	-	B 76,55 €

*Depending on availability - Dimensions in mm

Cylindrical anti vibration mount **Ste** **Stock**

B-ZY

Male / female mounting


- **Radial elasticity greater than axial elasticity**
- Works under compression or shear
- Materials
core: Steel plates
cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- Working temp: -40°C to +70°C

Applications


- Dampening sound and vibrations

Info.


- **Not sold individually, please contact us for details**
- Values for loads and rigidity are given as a guide only

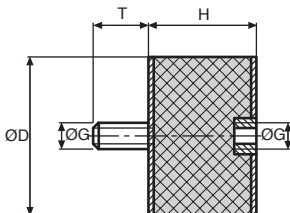


From size M3 upwards

 

Compression

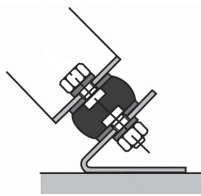

Compression
Shear

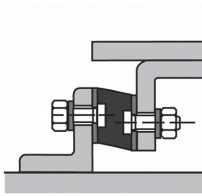

Shear

DISCOUNTS A

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

DISCOUNTS B

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	T	Compression		Shear		Stock*	Price each 1 to 5
					stiffness (N/mm)	Max. load (N)	stiffness (N/mm)	Max. load (N)		
B-ZY3-8-8	M3	8	8	6	-	-	-	-	✓	A 4,13 €
B-ZY4-10-10	M4	10	10	10	48	43	10	35	✓	A 2,19 €
B-ZY4-10-15	M4	10	15	10	29	43	5	15	✓	A 2,28 €
B-ZY4-15-15	M4	15	15	10	67	95	15	35	✓	A 2,46 €
B-ZY4-15-20	M4	15	20	10	-	-	-	-	✓	A 2,28 €
B-ZY4-15-30	M4	15	30	15	-	-	-	-	✓	A 2,46 €
B-ZY5-15-15	M5	15	15	8	67	95	15	35	✓	A 2,46 €
B-ZY6-20-15	M6	20	15	18	130	170	24	60	✓	A 2,64 €
B-ZY6-20-20	M6	20	20	18	-	-	-	-	✓	A 2,64 €
B-ZY6-20-25	M6	20	25	18	61	170	11	60	✓	A 2,64 €
B-ZY6-25-15	M6	25	15	18	-	-	-	-	✓	A 2,99 €
B-ZY6-25-20	M6	25	20	18	130	280	30	95	✓	A 3,16 €
B-ZY6-25-25	M6	25	25	18	-	-	-	-	✓	A 3,34 €
B-ZY6-25-30	M6	25	30	18	71	280	19	95	✓	A 3,61 €
B-ZY8-30-15	M8	30	15	20	525	400	58	140	✓	A 4,13 €
B-ZY8-30-20	M8	30	20	20	235	400	42	140	✓	A 4,30 €
B-ZY8-30-25	M8	30	25	20	-	-	-	-	✓	A 4,59 €
B-ZY8-30-30	M8	30	30	20	113	400	28	140	✓	A 5,11 €
B-ZY8-30-40	M8	30	40	20	106	400	13	140	✓	A 6,00 €
B-ZY8-40-25	M8	40	25	23	-	-	-	-	✓	A 6,34 €
B-ZY8-40-30	M8	40	30	23	234	650	49	250	✓	A 6,70 €
B-ZY8-40-40	M8	40	40	23	147	650	23	250	✓	A 7,58 €
B-ZY10-40-30	M10	40	30	28	-	-	-	-	✓	A 6,70 €
B-ZY10-50-20	M10	50	20	28	857	1000	110	400	✓	A 8,18 €
B-ZY10-50-25	M10	50	25	28	-	-	-	-	✓	A 8,90 €
B-ZY10-50-30	M10	50	30	28	395	1000	73	400	-	A 9,24 €
B-ZY10-50-40	M10	50	40	28	273	1000	58	400	✓	A 10,82 €
B-ZY10-50-45	M10	50	45	28	-	-	-	-	-	A 11,09 €
B-ZY10-50-50	M10	50	50	28	210	1000	37	400	✓	A 11,64 €
B-ZY10-60-40	M10	60	40	28	-	-	-	-	-	A 15,87 €
B-ZY10-70-45	M10	70	45	28	-	-	-	-	-	A 23,27 €
B-ZY12-60-40	M12	60	40	33	-	-	-	-	✓	B 10,55 €
B-ZY12-75-25	M12	75	25	37	-	-	-	-	-	B 12,46 €
B-ZY12-75-40	M12	75	40	37	735	2300	118	850	✓	B 12,80 €
B-ZY12-75-50	M12	75	50	37	530	2300	101	850	-	B 16,20 €
B-ZY12-75-55	M12	75	55	37	417	2300	78	850	-	B 16,86 €
B-ZY16-100-40	M16	100	40	41	2160	4200	283	1600	-	B 25,41 €
B-ZY16-100-55	M16	100	55	41	892	4200	145	1600	-	B 28,89 €
B-ZY16-100-60	M16	100	60	41	843	4200	142	1600	-	B 30,31 €
B-ZY16-100-75	M16	100	75	41	-	-	-	-	-	B 38,13 €

*Depending on availability - Dimensions in mm

Stainless steel anti vibration mount **Sta Stock**

B-ZYss

Male / female fixing

- Radial elasticity greater than axial elasticity
- Works under compression and shear
- Materials:
 - core: stainless steel A2 plates
 - cylinder: rubber
- **Hardness: NK 55-60 shore A**
- Working temp: -40°C to +70°C

stainless steel



 

Applications

- Noise and vibration dampening


Info.

- Not sold individually, please contact us for details
- Values for loads and rigidity are given as a guide only


From size M3 upwards

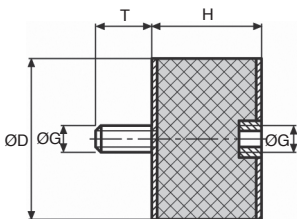

Compression

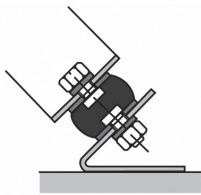

Compression
Shear

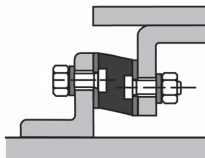

Shear

DISCOUNTS **A**

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

DISCOUNTS **B**

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	T	Compression		Shear		Stock*	Price each 1 to 5
					stiffness (N/mm)	Max. load (N)	stiffness (N/mm)	Max. load (N)		
B-ZY3-8-8/SS	M3	8	8	6	-	-	-	-	✓	A 7.45 €
B-ZY4-10-10/SS	M4	10	10	10	48	43	10	35	✓	A 3.90 €
B-ZY4-10-15/SS	M4	10	15	10	29	43	5	15	✓	A 4.27 €
B-ZY4-15-15/SS	M4	15	15	10	67	95	15	35	✓	A 3.81 €
B-ZY4-15-20/SS	M4	15	20	10	-	-	-	-	-	A 4.04 €
B-ZY4-15-30/SS	M4	15	30	15	-	-	-	-	-	A 4.19 €
B-ZY5-15-15/SS	M5	15	15	8	67	95	15	35	✓	A 4.19 €
B-ZY6-20-15/SS	M6	20	15	18	130	170	24	60	✓	A 4.50 €
B-ZY6-20-20/SS	M6	20	20	18	-	-	-	-	✓	A 4.61 €
B-ZY6-20-25/SS	M6	20	25	18	61	170	11	60	✓	A 4.61 €
B-ZY6-25-15/SS	M6	25	15	18	-	-	-	-	-	A 4.97 €
B-ZY6-25-20/SS	M6	25	20	18	130	280	30	95	✓	A 5.74 €
B-ZY6-25-25/SS	M6	25	25	18	-	-	-	-	✓	A 6.82 €
B-ZY6-30-30/SS	M6	25	30	18	71	280	19	95	✓	A 6.01 €
B-ZY8-30-15/SS	M8	30	15	20	525	400	58	140	✓	A 7.37 €
B-ZY8-30-20/SS	M8	30	20	20	235	400	42	140	✓	A 7.03 €
B-ZY8-30-25/SS	M8	30	25	20	-	-	-	-	-	A 8.20 €
B-ZY8-30-30/SS	M8	30	30	20	113	400	28	140	✓	A 8.35 €
B-ZY8-30-40/SS	M8	30	40	20	106	400	13	140	✓	A 9.04 €
B-ZY8-40-25/SS	M8	40	25	23	-	-	-	-	-	A 9.79 €
B-ZY8-40-30/SS	M8	40	30	23	234	650	49	250	✓	A 10.28 €
B-ZY8-40-40/SS	M8	40	40	23	147	650	23	250	✓	A 12.08 €
B-ZY10-40-30/SS	M10	40	30	28	-	-	-	-	-	A 11.34 €
B-ZY10-50-20/SS	M10	50	20	28	857	1000	110	400	✓	A 15.76 €
B-ZY10-50-25/SS	M10	50	25	28	-	-	-	-	✓	A 16.05 €
B-ZY10-50-30/SS	M10	50	30	28	395	1000	73	400	✓	A 15.75 €
B-ZY10-50-40/SS	M10	50	40	28	273	1000	58	400	✓	A 17.32 €
B-ZY10-50-45/SS	M10	50	45	28	-	-	-	-	✓	A 17.13 €
B-ZY10-50-50/SS	M10	50	50	28	210	1000	37	400	✓	A 19.26 €
B-ZY10-60-40/SS	M10	60	40	28	-	-	-	-	-	A 22.73 €
B-ZY10-70-45/SS	M10	70	45	28	-	-	-	-	-	A 33.34 €
B-ZY12-60-40/SS	M12	60	40	33	-	-	-	-	-	B 21.43 €
B-ZY12-75-25/SS	M12	75	25	37	-	-	-	-	-	B 25.80 €
B-ZY12-75-40/SS	M12	75	40	37	735	2300	118	850	✓	B 28.40 €
B-ZY12-75-50/SS	M12	75	50	37	530	2300	101	850	-	B 33.55 €
B-ZY12-75-55/SS	M12	75	55	37	417	2300	78	850	-	B 34.21 €
B-ZY16-100-40/SS	M16	100	40	41	2160	4200	283	1600	-	B 60.64 €
B-ZY16-100-55/SS	M16	100	55	41	892	4200	145	1600	-	B 66.60 €
B-ZY16-100-60/SS	M16	100	60	41	843	4200	142	1600	-	B 68.59 €
B-ZY16-100-75/SS	M16	100	75	41	-	-	-	-	-	B 79.53 €

*Depending on availability - Dimensions in mm