

- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials
  - core: Steel plates
  - cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C

### Uses



- Dampens sound and vibrations

### Options


- Stainless steel version available on request

### Info.


- Not sold individually, please contact us for details
- Values for loads and rigidity are given as a guide only

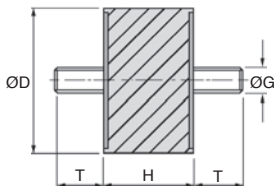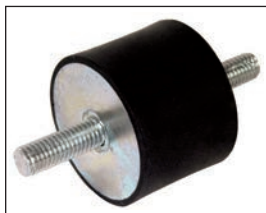


From size M3  
upwards

 

Compression

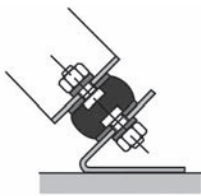

Compression  
Shearing

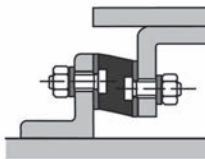

Shearing

DISCOUNTS **A**

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

DISCOUNTS **B**

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	T	Compression		Shearing		Stock*	Price each 1 to 5
					stiffness (N/mm)	Max. load(N)	stiffness (N/mm)	Max. load(N)		
A-ZY3-8-8	M3	8	8	6	-	-	-	-	✓	A 2,00 €
A-ZY4-10-10	M4	10	10	10	44	43	9	15	✓	A 1,85 €
A-ZY4-15-7	M4	15	7	10	174	95	29	35	✓	A 1,68 €
A-ZY4-15-8	M4	15	8	10	160	95	27	35	✓	A 1,68 €
A-ZY4-15-10	M4	15	10	10	124	95	24	35	✓	A 1,85 €
A-ZY4-15-15	M4	15	15	12	61	95	13	35	✓	A 1,97 €
A-ZY4-15-20	M4	15	20	13	-	-	-	-	✓	A 2,20 €
A-ZY5-15-15	M5	15	15	8	61	95	24	35	✓	A 1,97 €
A-ZY6-20-8	M6	20	8	18	307	170	36	60	✓	A 2,20 €
A-ZY6-20-10	M6	20	10	18	-	-	-	-	✓	A 2,29 €
A-ZY6-20-15	M6	20	15	18	130	170	24	60	✓	A 2,29 €
A-ZY6-20-20	M6	20	20	18	-	-	-	-	✓	A 2,29 €
A-ZY6-20-25	M6	20	25	18	85	170	17	60	✓	A 2,47 €
A-ZY6-25-10	M6	25	10	18	750	280	74	95	✓	A 2,47 €
A-ZY6-25-15	M6	25	15	18	-	-	-	-	✓	A 2,64 €
A-ZY6-25-20	M6	25	20	18	-	-	-	-	✓	A 3,00 €
A-ZY6-25-25	M6	25	25	18	-	-	-	-	✓	A 3,17 €
A-ZY8-30-15	M8	30	15	20	525	400	58	140	✓	A 3,61 €
A-ZY8-30-20	M8	30	20	20	204	400	40	140	✓	A 3,78 €
A-ZY8-30-25	M8	30	25	20	-	-	-	-	✓	A 4,21 €
A-ZY8-30-30	M8	30	30	20	108	400	25	140	✓	A 4,22 €
A-ZY8-30-40	M8	30	40	20	-	-	-	-	✓	A 5,12 €
A-ZY8-40-25	M8	40	25	23	-	-	-	-	✓	A 5,20 €
A-ZY8-40-30	M8	40	30	23	213	650	43	250	✓	A 5,36 €
A-ZY10-40-25	M10	40	25	28	-	-	-	-	✓	A 5,20 €
A-ZY10-40-30	M10	40	30	28	-	-	-	-	✓	A 6,33 €
A-ZY10-50-20	M10	50	20	28	857	1000	110	400	✓	A 7,49 €
A-ZY10-50-30	M10	50	30	28	375	1000	66	400	✓	A 8,53 €
A-ZY10-50-40	M10	50	40	28	260	1000	53	400	✓	A 8,72 €
A-ZY10-50-45	M10	50	45	28	215	1000	43	400	-	A 8,90 €
A-ZY10-50-50	M10	50	50	28	-	-	-	-	✓	A 9,49 €
A-ZY10-60-40	M10	60	40	28	-	-	-	-	✓	A 12,83 €
A-ZY10-70-45	M10	70	45	28	-	-	-	-	✓	A 19,26 €
A-ZY12-60-40	M12	60	40	33	-	-	-	-	✓	B 8,50 €
A-ZY12-75-25	M12	75	25	37	2710	2300	211	850	✓	B 10,00 €
A-ZY12-75-40	M12	75	40	37	734	2300	117	850	✓	B 11,03 €
A-ZY12-75-50	M12	75	50	37	506	2300	91	850	✓	B 12,86 €
A-ZY12-75-55	M12	75	55	37	417	2300	78	850	✓	B 13,39 €
A-ZY16-100-40	M16	100	40	41	1970	4200	257	1600	-	B 20,07 €
A-ZY16-100-55	M16	100	55	41	892	4200	145	1600	-	B 22,35 €
A-ZY16-100-75	M16	100	75	41	-	-	-	-	-	B 30,16 €

\*Depending on availability - Dimensions in mm

## Our other products



SLBS  
Stainless steel  
indexing plunger,  
Stainless steel



DER63  
Stainless steel AC  
asynchronous motor  
0.18 kW, 0.18kW



EPE  
Wing nuts Hygienic  
Design®, Narrow



J53  
Spur gear coaxial  
gearbox, from 0.43 to  
1.15 - In-line



VLBS  
Folding lifting ring for  
welding, Folding - for  
welding



RTE  
Rotex®, jaw coupling,  
steel



CDPC  
Flanged drill bushing,  
Steel



RHTccs  
High Temperature  
Castor, up to 200kg



CHM110  
Worm and wheel gear  
reducer, up to 980



PSPE22  
Conical flexible shaft  
handlee Ø22, Black



AT5-25ECO  
AT type timing pulley,  
Economy range - AT5



KSTM  
Igubal® pillow block  
bearing, Polymer

## Complementary products



AZY\_SS  
Stainless steel  
cylindrical elasto  
mount, Stainless steel



BZY  
Cylindrical elasto  
mount, Steel



ATZY  
Diabolo shaped elasto  
mount, Steel



PMB  
Anti-vibration  
machine mount, Oval  
base plate