


- Radial elasticity greater than axial elasticity.
- Cylinder worked under compression or shearing
- Materials:
  - Core: Steel plates
  - Cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C

### Uses


- Dampens sound and vibrations

### Info.


- Not sold individually, please contact us for details
- Values for loads and rigidity are given as a guide only

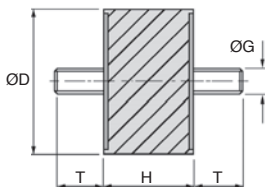


From size M3 upwards

 

Compression

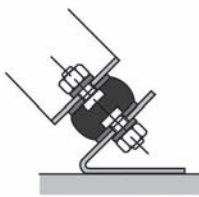

Compression  
Shearing

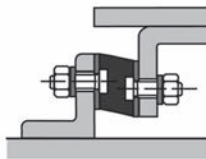

Shearing

## DISCOUNTS **A**

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

## DISCOUNTS **B**

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	T	Compression		Shearing		Stock*	Price each 1 to 5
					stiffness (N/mm)	Max. load (N)	stiffness (N/mm)	Max. load (N)		
A-ZY3-8-8/SS	M3	8	8	6	-	-	-	-	✓	<b>A</b> 3,07 €
A-ZY4-10-10/SS	M4	10	10	10	44	43	9	15	✓	<b>A</b> 3,07 €
A-ZY4-15-7/SS	M4	15	7	10	174	95	29	35	✓	<b>A</b> 2,54 €
A-ZY4-15-8/SS	M4	15	8	10	160	95	27	35	✓	<b>A</b> 2,75 €
A-ZY4-15-10/SS	M4	15	10	10	124	95	24	35	✓	<b>A</b> 2,85 €
A-ZY4-15-15/SS	M4	15	15	12	61	95	13	35	✓	<b>A</b> 2,85 €
A-ZY4-15-20/SS	M4	15	20	13	-	-	-	-	✓	<b>A</b> 3,27 €
A-ZY5-15-15/SS	M5	15	15	8	61	95	24	35	✓	<b>A</b> 2,77 €
A-ZY6-20-8/SS	M6	20	8	18	307	170	36	60	✓	<b>A</b> 3,15 €
A-ZY6-20-10/SS	M6	20	10	18	-	-	-	-	✓	<b>A</b> 3,25 €
A-ZY6-20-15/SS	M6	20	15	18	130	170	24	60	✓	<b>A</b> 3,30 €
A-ZY6-20-20/SS	M6	20	20	18	-	-	-	-	✓	<b>A</b> 3,78 €
A-ZY6-20-25/SS	M6	20	25	18	85	170	17	60	✓	<b>A</b> 3,78 €
A-ZY6-25-10/SS	M6	25	10	18	750	280	74	95	✓	<b>A</b> 3,46 €
A-ZY6-25-15/SS	M6	25	15	18	-	-	-	-	✓	<b>A</b> 3,70 €
A-ZY6-25-20/SS	M6	25	20	18	-	-	-	-	✓	<b>A</b> 4,31 €
A-ZY6-25-25/SS	M6	25	25	18	-	-	-	-	✓	<b>A</b> 4,76 €
A-ZY8-30-15/SS	M8	30	15	20	525	400	58	140	✓	<b>A</b> 5,65 €
A-ZY8-30-20/SS	M8	30	20	20	204	400	40	140	✓	<b>A</b> 5,85 €
A-ZY8-30-25/SS	M8	30	25	20	-	-	-	-	✓	<b>A</b> 6,32 €
A-ZY8-30-30/SS	M8	30	30	20	108	400	25	140	✓	<b>A</b> 6,32 €
A-ZY8-30-40/SS	M8	30	40	20	-	-	-	-	✓	<b>A</b> 7,76 €
A-ZY8-40-25/SS	M8	40	25	23	-	-	-	-	✓	<b>A</b> 8,47 €
A-ZY8-40-30/SS	M8	40	30	23	213	650	43	250	✓	<b>A</b> 7,62 €
A-ZY10-40-25/SS	M10	40	25	28	-	-	-	-	✓	<b>A</b> 7,26 €
A-ZY10-40-30/SS	M10	40	30	28	-	-	-	-	✓	<b>A</b> 8,70 €
A-ZY10-50-20/SS	M10	50	20	28	857	1000	110	400	✓	<b>A</b> 10,45 €
A-ZY10-50-30/SS	M10	50	30	28	375	1000	66	400	✓	<b>A</b> 12,63 €
A-ZY10-50-40/SS	M10	50	40	28	260	1000	53	400	✓	<b>A</b> 15,40 €
A-ZY10-50-45/SS	M10	50	45	28	215	1000	43	400	✓	<b>A</b> 12,73 €
A-ZY10-50-50/SS	M10	50	50	28	-	-	-	-	✓	<b>A</b> 16,70 €
A-ZY10-60-40/SS	M10	60	40	28	-	-	-	-	✓	<b>A</b> 19,40 €
A-ZY10-70-45/SS	M10	70	45	28	-	-	-	-	✓	<b>A</b> 26,69 €
A-ZY12-60-40/SS	M12	60	40	33	-	-	-	-	✓	<b>B</b> 17,16 €
A-ZY12-75-25/SS	M12	75	25	37	2710	2300	211	850	✓	<b>B</b> 20,67 €
A-ZY12-75-40/SS	M12	75	40	37	734	2300	117	850	✓	<b>B</b> 22,75 €
A-ZY12-75-50/SS	M12	75	50	37	506	2300	91	850	✓	<b>B</b> 25,85 €
A-ZY12-75-55/SS	M12	75	55	37	417	2300	78	850	✓	<b>B</b> 27,38 €
A-ZY16-100-40/SS	M16	100	40	41	1970	4200	257	1600	-	<b>B</b> 48,53 €
A-ZY16-100-55/SS	M16	100	55	41	892	4200	145	1600	-	<b>B</b> 53,30 €
A-ZY16-100-75/SS	M16	100	75	41	-	-	-	-	-	<b>B</b> 61,25 €

\*Depending on availability - Dimensions in mm

## Our other products



WSSss

Symmetrical S shaped hook stainless steel, Stainless steel




SEH

Horizontal stirrup toggle clamp, Horizontal stirrup clamp - steel



GTCCS

Belt tensioner, For use in hostile environments

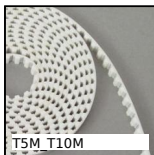

T5M T10M

T type timing belt per metre, T5 Steel cored polyurethane



RDERSS

Stainless steel manual rigging screw, Stainless steel - manual



QNUP

Single row cylindrical roller bearing, 1 fixed inner flange and 1 fr...



P40

Worm and wheel gear reducer, up to 18 Nm



PLC\_PLT

Magnetic stud with central hole, With central hole



 
CHB

Feet, For CHB gearbox



KKSS

Rounded end feather key, Stainless steel



G0

Steel spur gear, Steel 20NCD2



BVR

Adjustable screw stop, Steel

## Complementary products



AZY

Cylindrical elasto mount, Steel



BZY\_SS

Stainless steel cylindrical elasto mount, Stainless steel



BZY

Cylindrical elasto mount, Steel



PMB

Anti-vibration machine mount, Oval base plate