


- **Radial elasticity greater than axial elasticity.**
- Cylinder worked under compression or shearing
- **Materials:**
 - Core: Steel plates
 - Cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- **Working temp: -40°C to +70°C**

Uses


- Dampens sound and vibrations

Info.


- **Not sold individually, please contact us for details**
- Values for loads and rigidity are given as a guide only

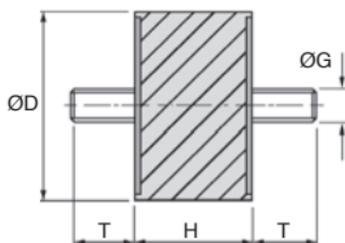


From size M3 upwards

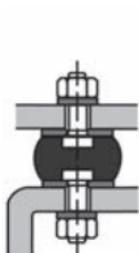

Compression

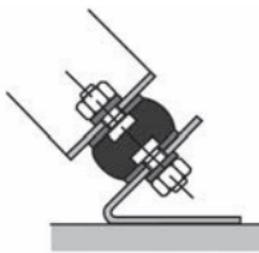

Compression Shearing

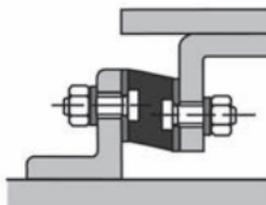

Shearing

DISCOUNTS **A**

| Qty | 1+ | 6+ | 20+ | 40+ | 100+ |
|-------|------|------|------|------|------------|
| Disc. | List | -10% | -15% | -20% | On request |

DISCOUNTS **B**

| Qty | 1+ | 6+ | 10+ | 15+ | 20+ | 50+ |
|-------|------|------|------|------|------|------------|
| Disc. | List | -10% | -15% | -20% | -25% | On request |

| Part number | ØG | ØD | H | T | Compression | | Shearing | | Stock* | Price each 1 to 5 |
|------------------|-----|-----|----|----|---------------------|------------------|---------------------|------------------|--------|----------------------|
| | | | | | stiffness (N/mm) | Max. load (N) | stiffness (N/mm) | Max. load (N) | | |
| A-ZY3-8-8/SS | M3 | 8 | 8 | 6 | - | - | - | - | ✓ | A 3,07 € |
| A-ZY4-10-10/SS | M4 | 10 | 10 | 10 | 44 | 43 | 9 | 15 | ✓ | A 3,07 € |
| A-ZY4-15-7/SS | M4 | 15 | 7 | 10 | 174 | 95 | 29 | 35 | ✓ | A 2,54 € |
| A-ZY4-15-8/SS | M4 | 15 | 8 | 10 | 160 | 95 | 27 | 35 | ✓ | A 2,75 € |
| A-ZY4-15-10/SS | M4 | 15 | 10 | 10 | 124 | 95 | 24 | 35 | ✓ | A 2,85 € |
| A-ZY4-15-15/SS | M4 | 15 | 15 | 12 | 61 | 95 | 13 | 35 | ✓ | A 2,85 € |
| A-ZY4-15-20/SS | M4 | 15 | 20 | 13 | - | - | - | - | ✓ | A 3,27 € |
| A-ZY5-15-15/SS | M5 | 15 | 15 | 8 | 61 | 95 | 24 | 35 | ✓ | A 2,77 € |
| A-ZY6-20-8/SS | M6 | 20 | 8 | 18 | 307 | 170 | 36 | 60 | ✓ | A 3,15 € |
| A-ZY6-20-10/SS | M6 | 20 | 10 | 18 | - | - | - | - | ✓ | A 3,25 € |
| A-ZY6-20-15/SS | M6 | 20 | 15 | 18 | 130 | 170 | 24 | 60 | ✓ | A 3,30 € |
| A-ZY6-20-20/SS | M6 | 20 | 20 | 18 | - | - | - | - | ✓ | A 3,78 € |
| A-ZY6-20-25/SS | M6 | 20 | 25 | 18 | 85 | 170 | 17 | 60 | ✓ | A 3,78 € |
| A-ZY6-25-10/SS | M6 | 25 | 10 | 18 | 750 | 280 | 74 | 95 | ✓ | A 3,46 € |
| A-ZY6-25-15/SS | M6 | 25 | 15 | 18 | - | - | - | - | ✓ | A 3,70 € |
| A-ZY6-25-20/SS | M6 | 25 | 20 | 18 | - | - | - | - | ✓ | A 4,31 € |
| A-ZY6-25-25/SS | M6 | 25 | 25 | 18 | - | - | - | - | ✓ | A 4,76 € |
| A-ZY8-30-15/SS | M8 | 30 | 15 | 20 | 525 | 400 | 58 | 140 | ✓ | A 5,65 € |
| A-ZY8-30-20/SS | M8 | 30 | 20 | 20 | 204 | 400 | 40 | 140 | ✓ | A 5,85 € |
| A-ZY8-30-25/SS | M8 | 30 | 25 | 20 | - | - | - | - | ✓ | A 6,32 € |
| A-ZY8-30-30/SS | M8 | 30 | 30 | 20 | 108 | 400 | 25 | 140 | ✓ | A 6,32 € |
| A-ZY8-30-40/SS | M8 | 30 | 40 | 20 | - | - | - | - | ✓ | A 7,76 € |
| A-ZY8-40-25/SS | M8 | 40 | 25 | 23 | - | - | - | - | ✓ | A 8,47 € |
| A-ZY8-40-30/SS | M8 | 40 | 30 | 23 | 213 | 650 | 43 | 250 | ✓ | A 7,62 € |
| A-ZY10-40-25/SS | M10 | 40 | 25 | 28 | - | - | - | - | ✓ | A 7,26 € |
| A-ZY10-40-30/SS | M10 | 40 | 30 | 28 | - | - | - | - | ✓ | A 8,70 € |
| A-ZY10-50-20/SS | M10 | 50 | 20 | 28 | 857 | 1000 | 110 | 400 | ✓ | A 10,45 € |
| A-ZY10-50-30/SS | M10 | 50 | 30 | 28 | 375 | 1000 | 66 | 400 | ✓ | A 12,63 € |
| A-ZY10-50-40/SS | M10 | 50 | 40 | 28 | 260 | 1000 | 53 | 400 | ✓ | A 15,40 € |
| A-ZY10-50-45/SS | M10 | 50 | 45 | 28 | 215 | 1000 | 43 | 400 | ✓ | A 12,73 € |
| A-ZY10-50-50/SS | M10 | 50 | 50 | 28 | - | - | - | - | ✓ | A 16,70 € |
| A-ZY10-60-40/SS | M10 | 60 | 40 | 28 | - | - | - | - | ✓ | A 19,40 € |
| A-ZY10-70-45/SS | M10 | 70 | 45 | 28 | - | - | - | - | ✓ | A 26,69 € |
| A-ZY12-60-40/SS | M12 | 60 | 40 | 33 | - | - | - | - | ✓ | B 17,16 € |
| A-ZY12-75-25/SS | M12 | 75 | 25 | 37 | 2710 | 2300 | 211 | 850 | ✓ | B 20,67 € |
| A-ZY12-75-40/SS | M12 | 75 | 40 | 37 | 734 | 2300 | 117 | 850 | ✓ | B 22,75 € |
| A-ZY12-75-50/SS | M12 | 75 | 50 | 37 | 506 | 2300 | 91 | 850 | ✓ | B 25,85 € |
| A-ZY12-75-55/SS | M12 | 75 | 55 | 37 | 417 | 2300 | 78 | 850 | ✓ | B 27,38 € |
| A-ZY16-100-40/SS | M16 | 100 | 40 | 41 | 1970 | 4200 | 257 | 1600 | - | B 48,53 € |
| A-ZY16-100-55/SS | M16 | 100 | 55 | 41 | 892 | 4200 | 145 | 1600 | - | B 53,30 € |
| A-ZY16-100-75/SS | M16 | 100 | 75 | 41 | - | - | - | - | - | B 61,25 € |

*Depending on availability - Dimensions in mm

Our other products



GE

Toggle latches,
Miniature



PITA

Locking bolt, with T
handle



RHTplss

High Temperature
Castor, up to 200kg



AK

Bellows coupling
Gerwah®, from 36 to
800Nm



PO

Pull handle - Multi-
sector, Tapped
recessed insert



PENV

Recessed handle,
screw fixing



ARTE

Flexible bush, For
multi-directional loads



CT

Telescopic universal
joint, Normal duty



UGH50

H Type Guide units,
For Ø50 actuators



PW_PWG2

Wheel - precision
range, Bronze



RTL450

Self-centering locking
assembly, High torque



PX

Optional output shaft
stainless steel, P
gearboxes single
sided outp...

Complementary products



AZY

Cylindrical elasto
mount, Steel



BZY_SS

Stainless steel
cylindrical elasto
mount, Stainless steel



BZY

Cylindrical elasto
mount, Steel



PMB

Anti-vibration
machine mount, Oval
base plate