

# Mounting collar for ball pin

**BABFC**  
**BABFO**



With a round or oval flange

- For use on thin sheet metal
- These collars offer a quick and securing method of mounting ball pins
- For the construction of boxes or other containers
- Material: 303, stainless steel




## Fonctionnement


- The large contact surface area ensures that all the force is spread evenly over thin walled structures

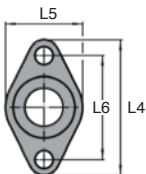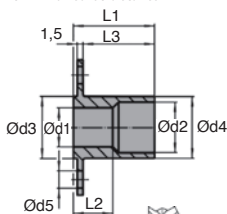

**BABFO :**  
Oval flange

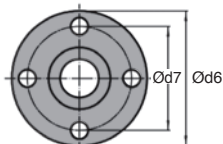

**BABFC :**  
Cylindrical flange

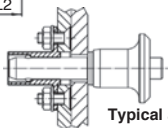

Typical application

## DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

### With cylindrical flange

Part number	Ød1	Ød2	Ød3		Ød4	Ød5	Ød6	Ød7	L1	L2	L3	Weight (g)	Price each 1 to 5
			-0,05	-0,1									
BAB5-8/FC/SS	5	8	10	9,9	3,4	25	19	12	5,4	9,5	9	19,01 €	
BAB6-8/FC/SS	6	8	10	9,9	3,4	25	19	13	5,3	10,5	9	19,01 €	
BAB8-10/FC/SS	8	10	12	11,9	4,5	30	22	19	10,3	16,5	14	21,15 €	
BAB10-13/FC/SS	10	13	16	15,9	4,5	35	27	21	10,2	18,5	24	23,38 €	
BAB12-15/FC/SS	12	15	19	18,9	4,5	40	30	27	15,2	24,5	41	26,60 €	
BAB16-20/FC/SS	16	20	24	23,9	5,5	50	40	30	15,3	27,5	63	31,25 €	

### With oval flange

Part number	Ød1	Ød2	Ød3		Ød4	Ød5	L1	L2	L3	L4	L5	L6	Weight (g)	Price each 1 to 5
			-0,05	-0,1										
BAB5-8/FO/SS	5	8	10	9,9	3,4	12	5,4	9,5	25	15	19	6	21,95 €	
BAB6-8/FO/SS	6	8	10	9,9	3,4	13	5,3	10,5	25	15	19	6	21,95 €	
BAB8-10/FO/SS	8	10	12	11,9	4,5	19	10,3	16,5	30	18	22	10	24,58 €	
BAB10-13/FO/SS	10	13	16	15,9	4,5	21	10,2	18,5	35	20	27	19	27,19 €	
BAB12-15/FO/SS	12	15	19	18,9	4,5	27	15,2	24,5	40	24	30	34	30,41 €	
BAB16-20/FO/SS	16	20	24	23,9	5,5	30	15,3	27,5	50	30	40	52	33,65 €	

Dimensions in mm

## Our other products



ACLEPP  
Right angled bracket for aluminium profile, 8 holes



DHX  
Dowel pin internal thread, Extractable DIN 7979D



UCFL\_SS  
Stainless steel flanged bearing, Stainless steel



RBNTc  
Swivel castor with central hole, Steel - rubber



PCS62K  
Chain sprocket with hardened teeth, 15.875mm (DIN10B-1)



BLHB50  
Right angled gearbox, bored shafts, up to 30 Nm



NPTF20  
Spacer for tube carrier, Fixing accessory Ø10 to Ø14



MDPOT  
Potentiometer,



BSM\_LOK  
Long-Lok spring plunger with internal



BLHB60  
Right angled gearbox, bored shafts, up to 70 Nm



NKXR  
Combined bearing without inner ring,



PM2  
Worm and wheel set, Hardened steel

## Complementary products



BAB  
Hardened Stainless steel ball pin, Stainless steel hardened



BABFCFO  
Ball pin socket, Mounting collar with a oval flange



BABss  
303 Stainless steel ball pin, 303 Stainless steel



BABV  
Ball lock pins lockable, Stainless steel