

- Auto-blocking

- Material:

Pin: Hardened stainless steel (630)
with resistant finish
Spring: stainless steel

- Maximum working temperature: 250°C

Advantages


- Released by simple push action. For locking pieces in places easily and quickly
- Quick release mechanism for repeated operations
- Hard wearing treated pin resists wear (Stainless steel 1.4542)
- Works under heavy load conditions
- Corrosion resistant
- Compact size with ergonomically designed handle

Press to unlock



Accessory

- CDR/S retaining cable (tome 1 p.38)



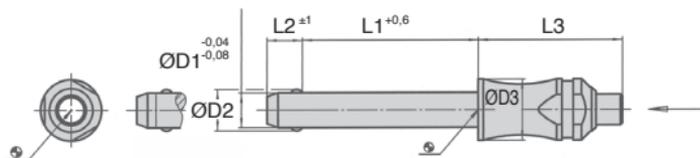


DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1	L1	ØD2	ØD3	L2	L3	For bore H11	Double shear strength (kN)	Weight (g)	Stock*	Price each 1 to 5
BAB5-10/S	5	10	5,5	10	6,0	26,2	5	24	15	✓	35,98 €
BAB5-15/S	5	15	5,5	10	6,0	26,2	5	24	16	-	35,98 €
BAB5-20/S	5	20	5,5	10	6,0	26,2	5	24	17	-	35,98 €
BAB5-25/S	5	25	5,5	10	6,0	26,2	5	24	18	-	35,98 €
BAB5-30/S	5	30	5,5	10	6,0	26,2	5	24	19	✓	38,07 €
BAB6-10/S	6	10	7,0	10	7,0	26,2	6	35	17	-	36,32 €
BAB6-15/S	6	15	7,0	10	7,0	26,2	6	35	18	-	36,32 €
BAB6-20/S	6	20	7,0	10	7,0	26,2	6	35	19	-	36,32 €
BAB6-25/S	6	25	7,0	10	7,0	26,2	6	35	20	✓	36,32 €
BAB6-30/S	6	30	7,0	10	7,0	26,2	6	35	21	-	40,33 €
BAB6-35/S	6	35	7,0	10	7,0	26,2	6	35	22	-	40,33 €
BAB6-40/S	6	40	7,0	10	7,0	26,2	6	35	23	-	40,33 €
BAB6-45/S	6	45	7,0	10	7,0	26,2	6	35	24	-	40,33 €
BAB6-50/S	6	50	7,0	10	7,0	26,2	6	35	25	-	40,33 €

 *Depending on availability - Dimensions in mm

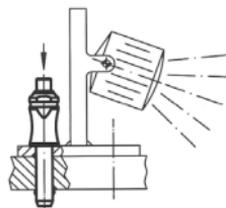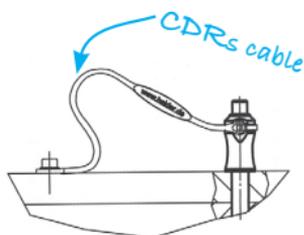

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1	L1	ØD2	ØD3	L2	L3	For bore H11	Double shear strength (kN)	Weight (g)	Price each	
										Stock*	1 to 5
BAB8-20/S	8	20	9,6	14	8,2	33,1	8	63	23	-	38,92 €
BAB8-25/S	8	25	9,6	14	8,2	33,1	8	63	25	-	38,92 €
BAB8-30/S	8	30	9,6	14	8,2	33,1	8	63	27	-	43,72 €
BAB8-35/S	8	35	9,6	14	8,2	33,1	8	63	29	-	43,72 €
BAB8-40/S	8	40	9,6	14	8,2	33,1	8	63	30	-	43,72 €
BAB8-45/S	8	45	9,6	14	8,2	33,1	8	63	32	-	43,72 €
BAB8-50/S	8	50	9,6	14	8,2	33,1	8	63	34	-	43,72 €
BAB10-20/S	10	20	12,0	14	9,6	33,1	10	100	35	-	59,71 €
BAB10-25/S	10	25	12,0	14	9,6	33,1	10	100	37	-	59,71 €
BAB10-30/S	10	30	12,0	14	9,6	33,1	10	100	40	-	62,49 €
BAB10-35/S	10	35	12,0	14	9,6	33,1	10	100	43	-	62,49 €
BAB10-40/S	10	40	12,0	14	9,6	33,1	10	100	46	-	62,49 €
BAB10-45/S	10	45	12,0	14	9,6	33,1	10	100	49	-	62,49 €
BAB10-50/S	10	50	12,0	14	9,6	33,1	10	100	52	-	62,49 €
BAB10-60/S	10	60	12,0	14	9,6	33,1	10	100	56	-	65,87 €
BAB12-25/S	12	25	14,5	20	10,6	39,5	12	144	51	-	60,77 €
BAB12-30/S	12	30	14,5	20	10,6	39,5	12	144	55	-	63,43 €
BAB12-35/S	12	35	14,5	20	10,6	39,5	12	144	59	-	63,43 €
BAB12-40/S	12	40	14,5	20	10,6	39,5	12	144	64	-	63,43 €
BAB12-45/S	12	45	14,5	20	10,6	39,5	12	144	68	-	63,43 €
BAB12-50/S	12	50	14,5	20	10,6	39,5	12	144	72	-	63,43 €
BAB12-60/S	12	60	14,5	20	10,6	39,5	12	144	80	-	66,69 €
BAB12-70/S	12	70	14,5	20	10,6	39,5	12	144	89	-	66,69 €
BAB12-80/S	12	80	14,5	20	10,6	39,5	12	144	98	-	69,73 €
BAB16-30/S	16	30	19,0	20	14,0	39,5	16	257	138	-	108,59 €
BAB16-35/S	16	35	19,0	20	14,0	39,5	16	257	147	-	108,59 €
BAB16-40/S	16	40	19,0	20	14,0	39,5	16	257	156	-	108,59 €
BAB16-45/S	16	45	19,0	20	14,0	39,5	16	257	165	-	108,59 €
BAB16-50/S	16	50	19,0	20	14,0	39,5	16	257	175	-	108,59 €
BAB16-60/S	16	60	19,0	20	14,0	39,5	16	257	193	-	117,01 €
BAB16-70/S	16	70	19,0	20	14,0	39,5	16	257	212	-	117,01 €
BAB16-80/S	16	80	19,0	20	14,0	39,5	16	257	233	-	124,05 €
BAB20-60/S	20	60	25,0	28	20,5	50,1	20	403	338	-	247,52 €
BAB20-80/S	20	80	25,0	28	20,5	50,1	20	403	388	-	254,54 €
BAB20-100/S	20	100	25,0	28	20,5	50,1	20	403	438	-	269,00 €
BAB20-120/S	20	120	25,0	28	20,5	50,1	20	403	488	-	279,69 €

*Depending on availability - Dimensions in mm