

Stainless steel clamping pin

BABs

Compact

- Auto-blocking

- Material:

Pin: Hardened stainless steel (630)
with resistant finish
Spring: stainless steel


- Maximum working temperature: 250°C

Advantages

- Released by simple push action. For locking pieces in places easily and quickly
- Quick release mechanism for repeated operations
- Hard wearing treated pin resists wear (Stainless steel 1.4542)
- Works under heavy load conditions
- Corrosion resistant
- Compact size with ergonomically designed handle



Press to unlock



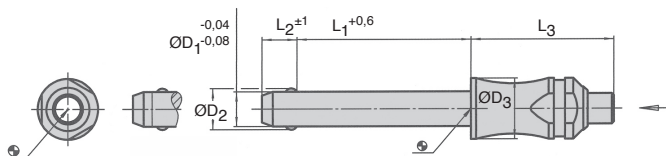


DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1	L1	ØD2	ØD3	L2	L3	Fir bore H11	Double shear strength (kN)	Weight (g)	Stock*	Price each 1 to 5
BAB5-10/S	5	10	5,5	10	6,0	26,2	5	24	15	✓	29,05 €
BAB5-15/S	5	15	5,5	10	6,0	26,2	5	24	16	✓	29,05 €
BAB5-20/S	5	20	5,5	10	6,0	26,2	5	24	17	-	29,05 €
BAB5-25/S	5	25	5,5	10	6,0	26,2	5	24	18	-	29,05 €
BAB5-30/S	5	30	5,5	10	6,0	26,2	5	24	19	-	30,75 €
BAB6-10/S	6	10	7,0	10	7,0	26,2	6	35	17	-	29,34 €
BAB6-15/S	6	15	7,0	10	7,0	26,2	6	35	18	✓	29,34 €
BAB6-20/S	6	20	7,0	10	7,0	26,2	6	35	19	-	29,34 €
BAB6-25/S	6	25	7,0	10	7,0	26,2	6	35	20	✓	29,34 €
BAB6-30/S	6	30	7,0	10	7,0	26,2	6	35	21	✓	32,57 €
BAB6-35/S	6	35	7,0	10	7,0	26,2	6	35	22	-	32,57 €
BAB6-40/S	6	40	7,0	10	7,0	26,2	6	35	23	-	32,57 €
BAB6-45/S	6	45	7,0	10	7,0	26,2	6	35	24	-	32,57 €
BAB6-50/S	6	50	7,0	10	7,0	26,2	6	35	25	-	32,57 €

 *Subject to availability - Dimensions in mm

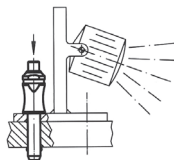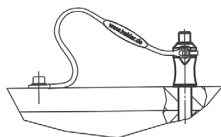

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1	L1	ØD2	ØD3	L2	L3	For bore H11	Double shear strength (kN)	Weight (g)	Prix Uni.	
										Stock*	1 à 5
BAB8-20/S	8	20	9,6	14	8,2	33,1	8	63	23	-	31,44 €
BAB8-25/S	8	25	9,6	14	8,2	33,1	8	63	25	-	31,44 €
BAB8-30/S	8	30	9,6	14	8,2	33,1	8	63	27	-	35,32 €
BAB8-35/S	8	35	9,6	14	8,2	33,1	8	63	29	-	35,32 €
BAB8-40/S	8	40	9,6	14	8,2	33,1	8	63	30	-	35,32 €
BAB8-45/S	8	45	9,6	14	8,2	33,1	8	63	32	-	35,32 €
BAB8-50/S	8	50	9,6	14	8,2	33,1	8	63	34	-	35,32 €
BAB10-20/S	10	20	12,0	14	9,6	33,1	10	100	35	-	48,23 €
BAB10-25/S	10	25	12,0	14	9,6	33,1	10	100	37	-	48,23 €
BAB10-30/S	10	30	12,0	14	9,6	33,1	10	100	40	-	50,48 €
BAB10-35/S	10	35	12,0	14	9,6	33,1	10	100	43	-	50,48 €
BAB10-40/S	10	40	12,0	14	9,6	33,1	10	100	46	-	50,48 €
BAB10-45/S	10	45	12,0	14	9,6	33,1	10	100	49	-	50,48 €
BAB10-50/S	10	50	12,0	14	9,6	33,1	10	100	52	-	50,48 €
BAB10-60/S	10	60	12,0	14	9,6	33,1	10	100	56	-	53,20 €
BAB12-25/S	12	25	14,5	20	10,6	39,5	12	144	51	-	49,08 €
BAB12-30/S	12	30	14,5	20	10,6	39,5	12	144	55	✓	51,23 €
BAB12-35/S	12	35	14,5	20	10,6	39,5	12	144	59	-	51,23 €
BAB12-40/S	12	40	14,5	20	10,6	39,5	12	144	64	✓	51,23 €
BAB12-45/S	12	45	14,5	20	10,6	39,5	12	144	68	-	51,23 €
BAB12-50/S	12	50	14,5	20	10,6	39,5	12	144	72	-	51,23 €
BAB12-60/S	12	60	14,5	20	10,6	39,5	12	144	80	-	53,87 €
BAB12-70/S	12	70	14,5	20	10,6	39,5	12	144	89	-	53,87 €
BAB12-80/S	12	80	14,5	20	10,6	39,5	12	144	98	-	56,32 €
BAB16-30/S	16	30	19,0	20	14,0	39,5	16	257	138	-	87,70 €
BAB16-35/S	16	35	19,0	20	14,0	39,5	16	257	147	✓	87,70 €
BAB16-40/S	16	40	19,0	20	14,0	39,5	16	257	156	-	87,70 €
BAB16-45/S	16	45	19,0	20	14,0	39,5	16	257	165	-	87,70 €
BAB16-50/S	16	50	19,0	20	14,0	39,5	16	257	175	✓	87,70 €
BAB16-60/S	16	60	19,0	20	14,0	39,5	16	257	193	✓	94,50 €
BAB16-70/S	16	70	19,0	20	14,0	39,5	16	257	212	-	94,50 €
BAB16-80/S	16	80	19,0	20	14,0	39,5	16	257	233	-	100,19 €
BAB20-60/S	20	60	25,0	28	20,5	50,1	20	403	338	-	199,91 €
BAB20-80/S	20	80	25,0	28	20,5	50,1	20	403	388	-	205,58 €
BAB20-100/S	20	100	25,0	28	20,5	50,1	20	403	438	-	217,27 €
BAB20-120/S	20	120	25,0	28	20,5	50,1	20	403	488	-	225,90 €

*Subject to availability - Dimensions in mm

Our other products



WJRM
Drylin® W hybrid bearing block, Hybrid bearings



T10_21_AL
T type timing pulley, Economy range - T10 aluminium



NK17
Drylin®N miniature guiding system, Width 17 mm



ZH66
Plastic spur gear, Machined plastic (delrin)



RJA10_03
Sealing strip, Clipping



EBC
Cap nut Hygienic Design®, Compact



CHMR50
Worm and wheel gear reducer, up to 107 Nm



RAS
90° ball and socket joints DIN71802, Stainless steel



PGM52-M4
Pull handle, Brass



PRF_JL5
Lip seal for panel, Door seal - Ø 5mm



RBGpl
Swivel castor with double brake, Steel - grey rubber



GE_ET_2RS
Spherical bushing, Hard chromium / Teflon contact with seals

Complementary products




BABreceptacle
Ball pin socket, Socket



BABS303
303 Stainless steel compact ball pin, Stainless steel 303



AFA
Locking pin, with ring

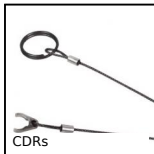

CDRs
Retaining cable for ball pin, Retaining cable