

Stainless steel clamping pin

BABs

Compact

- Auto-blocking

- Material:

Pin: Hardened stainless steel (630)
with resistant finish
Spring: stainless steel


- Maximum working temperature: 250°C

Advantages

- Released by simple push action. For locking pieces in places easily and quickly
- Quick release mechanism for repeated operations
- Hard wearing treated pin resists wear (Stainless steel 1.4542)
- Works under heavy load conditions
- Corrosion resistant
- Compact size with ergonomically designed handle



Press to unlock



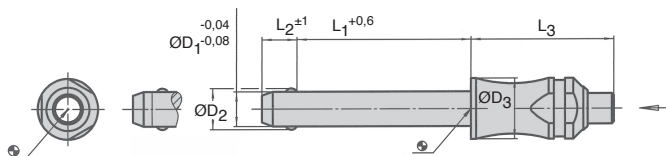


DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1	L1	ØD2	ØD3	L2	L3	Fir bore H11	Double shear strength (kN)	Weight (g)	Stock*	Price each 1 to 5
BAB5-10/S	5	10	5,5	10	6,0	26,2	5	24	15	✓	29,05 €
BAB5-15/S	5	15	5,5	10	6,0	26,2	5	24	16	✓	29,05 €
BAB5-20/S	5	20	5,5	10	6,0	26,2	5	24	17	-	29,05 €
BAB5-25/S	5	25	5,5	10	6,0	26,2	5	24	18	-	29,05 €
BAB5-30/S	5	30	5,5	10	6,0	26,2	5	24	19	-	30,75 €
BAB6-10/S	6	10	7,0	10	7,0	26,2	6	35	17	-	29,34 €
BAB6-15/S	6	15	7,0	10	7,0	26,2	6	35	18	✓	29,34 €
BAB6-20/S	6	20	7,0	10	7,0	26,2	6	35	19	-	29,34 €
BAB6-25/S	6	25	7,0	10	7,0	26,2	6	35	20	✓	29,34 €
BAB6-30/S	6	30	7,0	10	7,0	26,2	6	35	21	✓	32,57 €
BAB6-35/S	6	35	7,0	10	7,0	26,2	6	35	22	-	32,57 €
BAB6-40/S	6	40	7,0	10	7,0	26,2	6	35	23	-	32,57 €
BAB6-45/S	6	45	7,0	10	7,0	26,2	6	35	24	-	32,57 €
BAB6-50/S	6	50	7,0	10	7,0	26,2	6	35	25	-	32,57 €

 *Subject to availability - Dimensions in mm

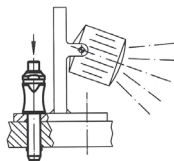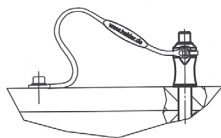

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1	L1	ØD2	ØD3	L2	L3	For bore H11	Double shear strength (kN)	Weight (g)	Prix Uni.	
										Stock*	1 à 5
BAB8-20/S	8	20	9,6	14	8,2	33,1	8	63	23	-	31,44 €
BAB8-25/S	8	25	9,6	14	8,2	33,1	8	63	25	-	31,44 €
BAB8-30/S	8	30	9,6	14	8,2	33,1	8	63	27	-	35,32 €
BAB8-35/S	8	35	9,6	14	8,2	33,1	8	63	29	-	35,32 €
BAB8-40/S	8	40	9,6	14	8,2	33,1	8	63	30	-	35,32 €
BAB8-45/S	8	45	9,6	14	8,2	33,1	8	63	32	-	35,32 €
BAB8-50/S	8	50	9,6	14	8,2	33,1	8	63	34	-	35,32 €
BAB10-20/S	10	20	12,0	14	9,6	33,1	10	100	35	-	48,23 €
BAB10-25/S	10	25	12,0	14	9,6	33,1	10	100	37	-	48,23 €
BAB10-30/S	10	30	12,0	14	9,6	33,1	10	100	40	-	50,48 €
BAB10-35/S	10	35	12,0	14	9,6	33,1	10	100	43	-	50,48 €
BAB10-40/S	10	40	12,0	14	9,6	33,1	10	100	46	-	50,48 €
BAB10-45/S	10	45	12,0	14	9,6	33,1	10	100	49	-	50,48 €
BAB10-50/S	10	50	12,0	14	9,6	33,1	10	100	52	-	50,48 €
BAB10-60/S	10	60	12,0	14	9,6	33,1	10	100	56	-	53,20 €
BAB12-25/S	12	25	14,5	20	10,6	39,5	12	144	51	-	49,08 €
BAB12-30/S	12	30	14,5	20	10,6	39,5	12	144	55	✓	51,23 €
BAB12-35/S	12	35	14,5	20	10,6	39,5	12	144	59	-	51,23 €
BAB12-40/S	12	40	14,5	20	10,6	39,5	12	144	64	✓	51,23 €
BAB12-45/S	12	45	14,5	20	10,6	39,5	12	144	68	-	51,23 €
BAB12-50/S	12	50	14,5	20	10,6	39,5	12	144	72	-	51,23 €
BAB12-60/S	12	60	14,5	20	10,6	39,5	12	144	80	-	53,87 €
BAB12-70/S	12	70	14,5	20	10,6	39,5	12	144	89	-	53,87 €
BAB12-80/S	12	80	14,5	20	10,6	39,5	12	144	98	-	56,32 €
BAB16-30/S	16	30	19,0	20	14,0	39,5	16	257	138	-	87,70 €
BAB16-35/S	16	35	19,0	20	14,0	39,5	16	257	147	✓	87,70 €
BAB16-40/S	16	40	19,0	20	14,0	39,5	16	257	156	-	87,70 €
BAB16-45/S	16	45	19,0	20	14,0	39,5	16	257	165	-	87,70 €
BAB16-50/S	16	50	19,0	20	14,0	39,5	16	257	175	✓	87,70 €
BAB16-60/S	16	60	19,0	20	14,0	39,5	16	257	193	✓	94,50 €
BAB16-70/S	16	70	19,0	20	14,0	39,5	16	257	212	-	94,50 €
BAB16-80/S	16	80	19,0	20	14,0	39,5	16	257	233	-	100,19 €
BAB20-60/S	20	60	25,0	28	20,5	50,1	20	403	338	-	199,91 €
BAB20-80/S	20	80	25,0	28	20,5	50,1	20	403	388	-	205,58 €
BAB20-100/S	20	100	25,0	28	20,5	50,1	20	403	438	-	217,27 €
BAB20-120/S	20	120	25,0	28	20,5	50,1	20	403	488	-	225,90 €

*Subject to availability - Dimensions in mm

Our other products



DIA
Ring operated locking bolt, with ring



ZBconique
Machined plastic bevel gear, 1:1



SEH
Horizontal stirrup toggle clamp,
Horizontal Latch clamp - stainless ...



METC
Flanged sintered bronze bush, Self-lubricating sintered bronze



CAP880
Side flexing slim slat top chain acetal,
Narrow range 880



 
PRT
Rotary table iglidur®, aluminium and stainless steel



CSS
Spherical bushing,
Steel / self lubricating steel



MBEX
Hexagonal ended handle, Hexagonal ended handle



CFC
Spring loaded position switch, Electric contact



PGM86-M5
Pull handle,
Thermoplastic



BOX-TOR-INCH
Box set of Nitrile O-rings in inch NBR90Sh A,
For fasteners and fitt...



VTLB
Three-lobed knob,
Thermoplastic / Brass or stainless steel insert

Complementary products




BABreceptacle
Ball pin socket, Socket



BABS303
303 Stainless steel compact ball pin,
Stainless steel 303



 AFA
Locking pin, with ring



CDRs
Retaining cable for ball pin, Retaining cable