

Clamping pin, 303 stainless steel



BABS303

Compact

- Self locking
- Materials:
 - Shaft: Stainless steel 303
 - Spring: Stainless steel
- Working temp: max 150°C

Advantages

- Press to unlock
- Quick and easy to assemble, block, adjust change and stop
- Simply and quickly to released when performing repetitive operations
- Corrosion resistant
- Handle designed to avoid accidental release
- Compact size with ergonomically designed handle


Press to unlock



Lower cost material

Options

- BABS Ball pin manufactured from hardened stainless steel (630) offers increased double shear strength



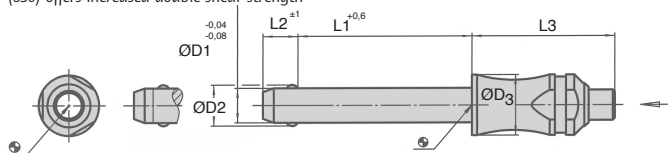


DISCOUNTS

| | | | |
|------------|-----|----|------------|
| Qty | 1+ | 6+ | 10+ |
| Disc. List | -5% | | On request |

| Part number | Ød1 | L1 | Ød2 | Ød3 | L2 | L3 | For bore H11 | Double shear strength (kN) | Weight (g) | Price each 1 to 5 |
|--------------|-----|----|-----|-----|-----|------|--------------|----------------------------|------------|-------------------|
| BAB5-10/S303 | 5 | 10 | 5,5 | 10 | 6,0 | 26,2 | 5 | 14 | 10 | 18,29 € |
| BAB5-15/S303 | 5 | 15 | 5,5 | 10 | 6,0 | 26,2 | 5 | 14 | 11 | 18,31 € |
| BAB5-20/S303 | 5 | 20 | 5,5 | 10 | 6,0 | 26,2 | 5 | 14 | 12 | 18,31 € |
| BAB5-25/S303 | 5 | 25 | 5,5 | 10 | 6,0 | 26,2 | 5 | 14 | 13 | 18,31 € |
| BAB5-30/S303 | 5 | 30 | 5,5 | 10 | 6,0 | 26,2 | 5 | 14 | 13 | 19,47 € |
| BAB6-10/S303 | 6 | 10 | 7,0 | 10 | 7,0 | 26,2 | 6 | 21 | 11 | 18,41 € |
| BAB6-15/S303 | 6 | 15 | 7,0 | 10 | 7,0 | 26,2 | 6 | 21 | 12 | 18,41 € |
| BAB6-20/S303 | 6 | 20 | 7,0 | 10 | 7,0 | 26,2 | 6 | 21 | 13 | 18,41 € |
| BAB6-25/S303 | 6 | 25 | 7,0 | 10 | 7,0 | 26,2 | 6 | 21 | 14 | 18,41 € |
| BAB6-30/S303 | 6 | 30 | 7,0 | 10 | 7,0 | 26,2 | 6 | 21 | 15 | 20,60 € |
| BAB6-35/S303 | 6 | 35 | 7,0 | 10 | 7,0 | 26,2 | 6 | 21 | 16 | 20,60 € |
| BAB6-40/S303 | 6 | 40 | 7,0 | 10 | 7,0 | 26,2 | 6 | 21 | 17 | 20,60 € |
| BAB6-45/S303 | 6 | 45 | 7,0 | 10 | 7,0 | 26,2 | 6 | 21 | 18 | 20,60 € |
| BAB6-50/S303 | 6 | 50 | 7,0 | 10 | 7,0 | 26,2 | 6 | 21 | 19 | 20,60 € |

 Dimensions in mm

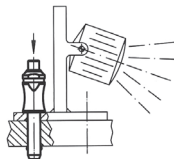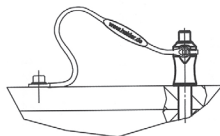

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 6+ | 10+ |
| Disc. | List | -5% | On request |

| Part number | Ød1 | L1 | Ød2 | Ød3 | L2 | L3 | For bore H11 | Double shear strength (kN) | Weight (g) | Price each 1 to 5 |
|----------------|-----|-----|------|-----|------|------|--------------|----------------------------|------------|-------------------|
| BAB8-20/S303 | 8 | 20 | 9,6 | 14 | 8,2 | 33,1 | 8 | 38 | 33 | 19,86 € |
| BAB8-25/S303 | 8 | 25 | 9,6 | 14 | 8,2 | 33,1 | 8 | 38 | 34 | 19,86 € |
| BAB8-30/S303 | 8 | 30 | 9,6 | 14 | 8,2 | 33,1 | 8 | 38 | 36 | 22,33 € |
| BAB8-35/S303 | 8 | 35 | 9,6 | 14 | 8,2 | 33,1 | 8 | 38 | 38 | 22,33 € |
| BAB8-40/S303 | 8 | 40 | 9,6 | 14 | 8,2 | 33,1 | 8 | 38 | 40 | 22,33 € |
| BAB8-45/S303 | 8 | 45 | 9,6 | 14 | 8,2 | 33,1 | 8 | 38 | 42 | 22,33 € |
| BAB8-50/S303 | 8 | 50 | 9,6 | 14 | 8,2 | 33,1 | 8 | 38 | 44 | 22,33 € |
| BAB10-20/S303 | 10 | 20 | 12,0 | 14 | 9,6 | 33,1 | 10 | 60 | 39 | 30,32 € |
| BAB10-25/S303 | 10 | 25 | 12,0 | 14 | 9,6 | 33,1 | 10 | 60 | 42 | 30,32 € |
| BAB10-30/S303 | 10 | 30 | 12,0 | 14 | 9,6 | 33,1 | 10 | 60 | 45 | 32,00 € |
| BAB10-35/S303 | 10 | 35 | 12,0 | 14 | 9,6 | 33,1 | 10 | 60 | 48 | 32,00 € |
| BAB10-40/S303 | 10 | 40 | 12,0 | 14 | 9,6 | 33,1 | 10 | 60 | 51 | 32,00 € |
| BAB10-45/S303 | 10 | 45 | 12,0 | 14 | 9,6 | 33,1 | 10 | 60 | 54 | 32,00 € |
| BAB10-50/S303 | 10 | 50 | 12,0 | 14 | 9,6 | 33,1 | 10 | 60 | 57 | 32,00 € |
| BAB10-60/S303 | 10 | 60 | 12,0 | 14 | 9,6 | 33,1 | 10 | 60 | 63 | 33,57 € |
| BAB12-25/S303 | 12 | 25 | 14,5 | 20 | 10,6 | 39,5 | 12 | 87 | 84 | 30,95 € |
| BAB12-30/S303 | 12 | 30 | 14,5 | 20 | 10,6 | 39,5 | 12 | 87 | 88 | 32,43 € |
| BAB12-35/S303 | 12 | 35 | 14,5 | 20 | 10,6 | 39,5 | 12 | 87 | 92 | 32,43 € |
| BAB12-40/S303 | 12 | 40 | 14,5 | 20 | 10,6 | 39,5 | 12 | 87 | 96 | 32,43 € |
| BAB12-45/S303 | 12 | 45 | 14,5 | 20 | 10,6 | 39,5 | 12 | 87 | 101 | 32,43 € |
| BAB12-50/S303 | 12 | 50 | 14,5 | 20 | 10,6 | 39,5 | 12 | 87 | 105 | 32,43 € |
| BAB12-60/S303 | 12 | 60 | 14,5 | 20 | 10,6 | 39,5 | 12 | 87 | 113 | 34,01 € |
| BAB12-70/S303 | 12 | 70 | 14,5 | 20 | 10,6 | 39,5 | 12 | 87 | 122 | 34,01 € |
| BAB12-80/S303 | 12 | 80 | 14,5 | 20 | 10,6 | 39,5 | 12 | 87 | 130 | 35,37 € |
| BAB16-30/S303 | 16 | 30 | 19,0 | 20 | 14,0 | 39,5 | 16 | 155 | 120 | 55,30 € |
| BAB16-35/S303 | 16 | 35 | 19,0 | 20 | 14,0 | 39,5 | 16 | 155 | 127 | 55,30 € |
| BAB16-40/S303 | 16 | 40 | 19,0 | 20 | 14,0 | 39,5 | 16 | 155 | 135 | 55,30 € |
| BAB16-45/S303 | 16 | 45 | 19,0 | 20 | 14,0 | 39,5 | 16 | 155 | 143 | 55,30 € |
| BAB16-50/S303 | 16 | 50 | 19,0 | 20 | 14,0 | 39,5 | 16 | 155 | 150 | 55,30 € |
| BAB16-60/S303 | 16 | 60 | 19,0 | 20 | 14,0 | 39,5 | 16 | 155 | 166 | 59,60 € |
| BAB16-70/S303 | 16 | 70 | 19,0 | 20 | 14,0 | 39,5 | 16 | 155 | 181 | 59,60 € |
| BAB16-80/S303 | 16 | 80 | 19,0 | 20 | 14,0 | 39,5 | 16 | 155 | 196 | 63,30 € |
| BAB20-60/S303 | 20 | 60 | 25,0 | 28 | 20,5 | 50,1 | 20 | 244 | 322 | 111,99 € |
| BAB20-80/S303 | 20 | 80 | 25,0 | 28 | 20,5 | 50,1 | 20 | 244 | 370 | 116,50 € |
| BAB20-100/S303 | 20 | 100 | 25,0 | 28 | 20,5 | 50,1 | 20 | 244 | 414 | 122,20 € |
| BAB20-120/S303 | 20 | 120 | 25,0 | 28 | 20,5 | 50,1 | 20 | 244 | 466 | 126,85 € |


Dimensions in mm

Our other products



BLHM50

 Right angled gearbox, double output shafts, up to 30 Nm



LAT1

1A motorised linear actuator, 1 ampere



DOMI120

Domino 120 adjustable slide, Slide DOMILINE 120



SVR30

Screwjack with travelling nut, with moving nut



E60

Right angle helical reducers, from 4.50 to 62 Nm



CHMR30

Worm and wheel gear reducer, up to 28 Nm



GE14

Toggle latches, With padlock-holder



CTss

Universal joint, telescopic, Inox, Light duty



HK

Manual locking clamp, Manual locking clamp



VTSM

Ball head screws Hygienic Design®,



SC2

2 part rigid shaft clamp, Clamping jaw



EBH

 
Cap nut Hygienic Design®, With collar

Complementary products



BABS

630 Stainless steel compact ball pin, Hardened stainless steel



CDRs

Retaining cable for ball pin, Retaining cable