

## BABs303

## Compact

- **Self locking**
- Materials:
  - Shaft: Stainless steel 303
  - Spring: Stainless steel
- Working temp: max 150°C

### Advantages

- Press to unlock
- Quick and easy to assemble, block, adjust change and stop
- Simply and quickly to released when performing repetitive operations
- Corrosion resistant
- Compact size with ergonomically designed handle

### Options


- BABs Ball pin manufactured from hardened stainless steel (630) offers increased double shear strength

### Accessory

- CDR/S retaining cable (tome 1 p.38)



Lower cost material



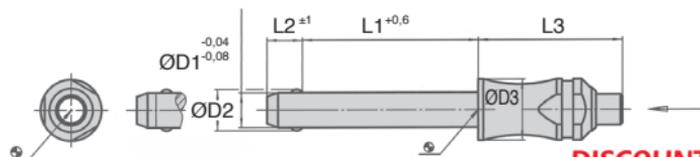


### DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1	L1	ØD2	ØD3	L2	L3	For bore H11	Double shear strength (kN)	Weight (g)	Price each 1 to 5
BAB5-10/S303	5	10	5,5	10	6,0	26,2	5	14	10	- 22,64 €
BAB5-15/S303	5	15	5,5	10	6,0	26,2	5	14	11	- 22,66 €
BAB5-20/S303	5	20	5,5	10	6,0	26,2	5	14	12	- 22,66 €
BAB5-25/S303	5	25	5,5	10	6,0	26,2	5	14	13	✓ 22,66 €
BAB5-30/S303	5	30	5,5	10	6,0	26,2	5	14	13	✓ 24,10 €
BAB6-10/S303	6	10	7,0	10	7,0	26,2	6	21	11	- 22,79 €
BAB6-15/S303	6	15	7,0	10	7,0	26,2	6	21	12	- 22,79 €
BAB6-20/S303	6	20	7,0	10	7,0	26,2	6	21	13	- 22,79 €
BAB6-25/S303	6	25	7,0	10	7,0	26,2	6	21	14	- 22,79 €
BAB6-30/S303	6	30	7,0	10	7,0	26,2	6	21	15	✓ 25,50 €
BAB6-35/S303	6	35	7,0	10	7,0	26,2	6	21	16	✓ 25,50 €
BAB6-40/S303	6	40	7,0	10	7,0	26,2	6	21	17	- 25,50 €
BAB6-45/S303	6	45	7,0	10	7,0	26,2	6	21	18	✓ 25,50 €
BAB6-50/S303	6	50	7,0	10	7,0	26,2	6	21	19	✓ 25,50 €

 \*Depending on availability - Dimensions in mm

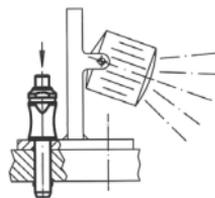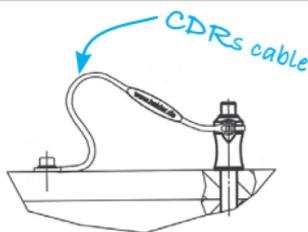

## DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1	L1	ØD2	ØD3	L2	L3	For bore H11	Double shear strenght (kN)	Weight (g)	Stock*	Price each 1 to 5
										✓	€
BAB8-20/S303	8	20	9,6	14	8,2	33,1	8	38	33	✓	24,58 €
BAB8-25/S303	8	25	9,6	14	8,2	33,1	8	38	34	-	24,58 €
BAB8-30/S303	8	30	9,6	14	8,2	33,1	8	38	36	✓	27,63 €
BAB8-35/S303	8	35	9,6	14	8,2	33,1	8	38	38	-	27,63 €
BAB8-40/S303	8	40	9,6	14	8,2	33,1	8	38	40	✓	27,63 €
BAB8-45/S303	8	45	9,6	14	8,2	33,1	8	38	42	-	27,63 €
BAB8-50/S303	8	50	9,6	14	8,2	33,1	8	38	44	✓	27,63 €
BAB10-20/S303	10	20	12,0	14	9,6	33,1	10	60	39	✓	37,53 €
BAB10-25/S303	10	25	12,0	14	9,6	33,1	10	60	42	-	37,53 €
BAB10-30/S303	10	30	12,0	14	9,6	33,1	10	60	45	-	39,61 €
BAB10-35/S303	10	35	12,0	14	9,6	33,1	10	60	48	-	39,61 €
BAB10-40/S303	10	40	12,0	14	9,6	33,1	10	60	51	-	39,61 €
BAB10-45/S303	10	45	12,0	14	9,6	33,1	10	60	54	-	39,61 €
BAB10-50/S303	10	50	12,0	14	9,6	33,1	10	60	57	-	39,61 €
BAB10-60/S303	10	60	12,0	14	9,6	33,1	10	60	63	✓	41,56 €
BAB12-25/S303	12	25	14,5	20	10,6	39,5	12	87	84	✓	38,31 €
BAB12-30/S303	12	30	14,5	20	10,6	39,5	12	87	88	-	40,15 €
BAB12-35/S303	12	35	14,5	20	10,6	39,5	12	87	92	-	40,15 €
BAB12-40/S303	12	40	14,5	20	10,6	39,5	12	87	96	-	40,15 €
BAB12-45/S303	12	45	14,5	20	10,6	39,5	12	87	101	-	40,15 €
BAB12-50/S303	12	50	14,5	20	10,6	39,5	12	87	105	-	40,15 €
BAB12-60/S303	12	60	14,5	20	10,6	39,5	12	87	113	-	42,11 €
BAB12-70/S303	12	70	14,5	20	10,6	39,5	12	87	122	-	42,11 €
BAB12-80/S303	12	80	14,5	20	10,6	39,5	12	87	130	-	43,78 €
BAB16-30/S303	16	30	19,0	20	14,0	39,5	16	155	120	-	68,47 €
BAB16-35/S303	16	35	19,0	20	14,0	39,5	16	155	127	-	68,47 €
BAB16-40/S303	16	40	19,0	20	14,0	39,5	16	155	135	-	68,47 €
BAB16-45/S303	16	45	19,0	20	14,0	39,5	16	155	143	-	68,47 €
BAB16-50/S303	16	50	19,0	20	14,0	39,5	16	155	150	-	68,47 €
BAB16-60/S303	16	60	19,0	20	14,0	39,5	16	155	166	-	73,80 €
BAB16-70/S303	16	70	19,0	20	14,0	39,5	16	155	181	-	73,80 €
BAB16-80/S303	16	80	19,0	20	14,0	39,5	16	155	196	-	78,37 €
BAB20-60/S303	20	60	25,0	28	20,5	50,1	20	244	322	-	138,65 €
BAB20-80/S303	20	80	25,0	28	20,5	50,1	20	244	370	-	144,25 €
BAB20-100/S303	20	100	25,0	28	20,5	50,1	20	244	414	-	151,30 €
BAB20-120/S303	20	120	25,0	28	20,5	50,1	20	244	466	-	157,04 €

\*Depending on availability - Dimensions in mm