

Clamping pin, 303 stainless steel



BABS303

Compact

- Self locking
- Materials:
 - Shaft: Stainless steel 303
 - Spring: Stainless steel
- Working temp: max 150°C

Advantages

- Press to unlock
- Quick and easy to assemble, block, adjust change and stop
- Simply and quickly to released when performing repetitive operations
- Corrosion resistant
- Handle designed to avoid accidental release
- Compact size with ergonomically designed handle




Press to unlock

Lower cost material

Options

- BABS Ball pin manufactured from hardened stainless steel (630) offers increased double shear strength



 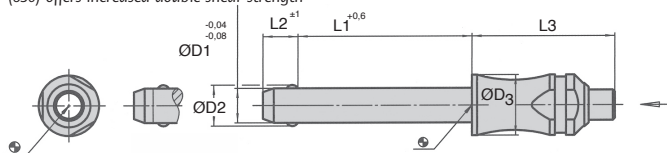


DISCOUNTS

Qty	1+	6+	10+
Disc. List		-5%	On request

Part number	Ød1	L1	Ød2	Ød3	L2	L3	For bore H11	Double shear strength (kN)	Weight (g)	Price each 1 to 5
BAB5-10/S303	5	10	5,5	10	6,0	26,2	5	14	10	18,29 €
BAB5-15/S303	5	15	5,5	10	6,0	26,2	5	14	11	18,31 €
BAB5-20/S303	5	20	5,5	10	6,0	26,2	5	14	12	18,31 €
BAB5-25/S303	5	25	5,5	10	6,0	26,2	5	14	13	18,31 €
BAB5-30/S303	5	30	5,5	10	6,0	26,2	5	14	13	19,47 €
BAB6-10/S303	6	10	7,0	10	7,0	26,2	6	21	11	18,41 €
BAB6-15/S303	6	15	7,0	10	7,0	26,2	6	21	12	18,41 €
BAB6-20/S303	6	20	7,0	10	7,0	26,2	6	21	13	18,41 €
BAB6-25/S303	6	25	7,0	10	7,0	26,2	6	21	14	18,41 €
BAB6-30/S303	6	30	7,0	10	7,0	26,2	6	21	15	20,60 €
BAB6-35/S303	6	35	7,0	10	7,0	26,2	6	21	16	20,60 €
BAB6-40/S303	6	40	7,0	10	7,0	26,2	6	21	17	20,60 €
BAB6-45/S303	6	45	7,0	10	7,0	26,2	6	21	18	20,60 €
BAB6-50/S303	6	50	7,0	10	7,0	26,2	6	21	19	20,60 €

Dimensions in mm

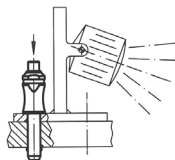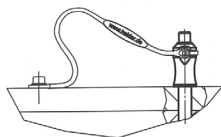

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Ød1	L1	Ød2	Ød3	L2	L3	For bore H11	Double shear strength (kN)	Weight (g)	Price each 1 to 5
BAB8-20/S303	8	20	9,6	14	8,2	33,1	8	38	33	19,86 €
BAB8-25/S303	8	25	9,6	14	8,2	33,1	8	38	34	19,86 €
BAB8-30/S303	8	30	9,6	14	8,2	33,1	8	38	36	22,33 €
BAB8-35/S303	8	35	9,6	14	8,2	33,1	8	38	38	22,33 €
BAB8-40/S303	8	40	9,6	14	8,2	33,1	8	38	40	22,33 €
BAB8-45/S303	8	45	9,6	14	8,2	33,1	8	38	42	22,33 €
BAB8-50/S303	8	50	9,6	14	8,2	33,1	8	38	44	22,33 €
BAB10-20/S303	10	20	12,0	14	9,6	33,1	10	60	39	30,32 €
BAB10-25/S303	10	25	12,0	14	9,6	33,1	10	60	42	30,32 €
BAB10-30/S303	10	30	12,0	14	9,6	33,1	10	60	45	32,00 €
BAB10-35/S303	10	35	12,0	14	9,6	33,1	10	60	48	32,00 €
BAB10-40/S303	10	40	12,0	14	9,6	33,1	10	60	51	32,00 €
BAB10-45/S303	10	45	12,0	14	9,6	33,1	10	60	54	32,00 €
BAB10-50/S303	10	50	12,0	14	9,6	33,1	10	60	57	32,00 €
BAB10-60/S303	10	60	12,0	14	9,6	33,1	10	60	63	33,57 €
BAB12-25/S303	12	25	14,5	20	10,6	39,5	12	87	84	30,95 €
BAB12-30/S303	12	30	14,5	20	10,6	39,5	12	87	88	32,43 €
BAB12-35/S303	12	35	14,5	20	10,6	39,5	12	87	92	32,43 €
BAB12-40/S303	12	40	14,5	20	10,6	39,5	12	87	96	32,43 €
BAB12-45/S303	12	45	14,5	20	10,6	39,5	12	87	101	32,43 €
BAB12-50/S303	12	50	14,5	20	10,6	39,5	12	87	105	32,43 €
BAB12-60/S303	12	60	14,5	20	10,6	39,5	12	87	113	34,01 €
BAB12-70/S303	12	70	14,5	20	10,6	39,5	12	87	122	34,01 €
BAB12-80/S303	12	80	14,5	20	10,6	39,5	12	87	130	35,37 €
BAB16-30/S303	16	30	19,0	20	14,0	39,5	16	155	120	55,30 €
BAB16-35/S303	16	35	19,0	20	14,0	39,5	16	155	127	55,30 €
BAB16-40/S303	16	40	19,0	20	14,0	39,5	16	155	135	55,30 €
BAB16-45/S303	16	45	19,0	20	14,0	39,5	16	155	143	55,30 €
BAB16-50/S303	16	50	19,0	20	14,0	39,5	16	155	150	55,30 €
BAB16-60/S303	16	60	19,0	20	14,0	39,5	16	155	166	59,60 €
BAB16-70/S303	16	70	19,0	20	14,0	39,5	16	155	181	59,60 €
BAB16-80/S303	16	80	19,0	20	14,0	39,5	16	155	196	63,30 €
BAB20-60/S303	20	60	25,0	28	20,5	50,1	20	244	322	111,99 €
BAB20-80/S303	20	80	25,0	28	20,5	50,1	20	244	370	116,50 €
BAB20-100/S303	20	100	25,0	28	20,5	50,1	20	244	414	122,20 €
BAB20-120/S303	20	120	25,0	28	20,5	50,1	20	244	466	126,85 €

Dimensions in mm

Our other products



RX-6
Spherical tilt washer -
DIN6319, concave



OP2
Mechanical digital
position indicator, 3
numbers



PO
Pull handle - Multi-
sector, Tapped
recessed insert



RJA10_03
Sealing strip, Clipping



BABV
Ball lock pins lockable
, Stainless steel



UTKpwr
V shaped channel
UtiliTrak®, V rail



MCLred
Reducing sleeve
female/female,
Cylindrical - steel



NSP
Right angled support
clamp, Right angled
support clamp



M1
Worm and wheel set,
Hardened steel



DOMI50
Accessories, Fixing kit



MCL
Cylindrical threaded
sleeve, Cylindrical -
steel

 


RPCplss
Swivel castor with
double brake,
Stainless steel -
Polyamide

Complementary products



BABS
630 Stainless steel
compact ball pin,
Hardened stainless
steel



CDRs
Retaining cable for
ball pin, Retaining
cable