

hardened stainless steel clamping pin

BABT

With T handle

- **Self locking**
- **Materials**
 Shaft: Stainless steel 1.4542, precipitation hardened with scratch resistant coating
 Spring: Stainless steel
 Handle: Black aluminium (RAL9005)
 Release button: Black stainless steel
- **Working temperature range:** -30°C to +150°C




Advantages

- Push to release
- Easy and quick method of attaching, blocking, adjusting etc...
 Quickly and easily unlocked for frequently repeated operations.
- Corrosion resistant
- Highly resistant, anti-wear, suitable for heavy duty applications
- Can be used with the **CDR** retaining cable

Info.

- Shear resistance conforms to DIN 50141

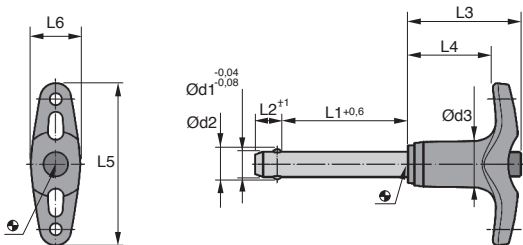


DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	On request	

Part number	Ød1	L1	Ød2	Ød3	L2	L3	L4	L5	L6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB5-10/T	5	10	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	19	34,93 €
BAB5-15/T	5	15	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	20	34,93 €
BAB5-20/T	5	20	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	20	34,93 €
BAB5-25/T	5	25	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	21	34,93 €
BAB5-30/T	5	30	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	22	37,10 €
BAB6-10/T	6	10	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	20	34,93 €
BAB6-15/T	6	15	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	21	34,93 €
BAB6-20/T	6	20	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	22	34,93 €
BAB6-25/T	6	25	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	23	34,93 €
BAB6-30/T	6	30	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	24	37,10 €

Dimensions in mm

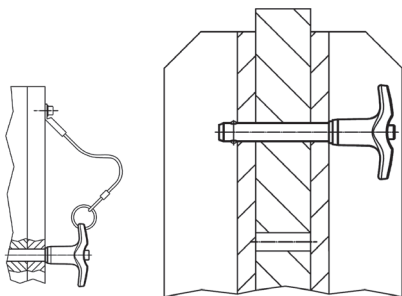

DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	On request	

Part number	Ød1	L1	Ød2	Ød3	L2	L3	L4	L5	L6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB6-35/T	6	35	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	25	37,10 €
BAB6-40/T	6	40	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	26	37,10 €
BAB6-45/T	6	45	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	27	37,10 €
BAB6-50/T	6	50	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	28	37,10 €
BAB8-20/T	8	20	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	37	38,57 €
BAB8-25/T	8	25	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	39	38,25 €
BAB8-30/T	8	30	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	41	40,66 €
BAB8-35/T	8	35	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	43	40,66 €
BAB8-40/T	8	40	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	44	40,66 €
BAB8-45/T	8	45	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	46	40,66 €
BAB8-50/T	8	50	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	48	40,66 €
BAB10-20/T	10	20	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	44	56,42 €
BAB10-25/T	10	25	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	47	56,42 €
BAB10-30/T	10	30	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	49	59,38 €
BAB10-35/T	10	35	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	52	59,38 €
BAB10-40/T	10	40	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	55	59,38 €
BAB10-45/T	10	45	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	58	59,38 €
BAB10-50/T	10	50	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	61	59,38 €
BAB10-60/T	10	60	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	67	62,28 €
BAB12-25/T	12	25	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	73	57,57 €
BAB12-30/T	12	30	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	77	60,51 €
BAB12-35/T	12	35	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	81	60,51 €
BAB12-40/T	12	40	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	86	60,51 €
BAB12-45/T	12	45	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	90	60,51 €
BAB12-50/T	12	50	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	94	60,51 €
BAB12-60/T	12	60	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	103	63,31 €
BAB12-70/T	12	70	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	111	63,31 €
BAB12-80/T	12	80	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	119	66,10 €

Dimensions in mm

Our other products



BIMSS
Indexing plunger mini,
miniature - Stainless
steel



TRM
Spur round rack, Steel
- module 1-6



SDCcs
Positioning sleeve for
indexing pin, For pin
Ø4 to Ø12



PARF110
Pressed steel base
rigid foot, Swivelling
Ø110



AC144
Strike for toggle latch,
22mm



NCT
Square tube
connector, Fixed
angle



CHAR7530
Spring hinge, welded



SRG
Adjustable latch
clamp with strike
plate, Stroke from
96mm to 121,7mm



 
T5P_T10P
Connecting plate for T
type timing belts, T10



Q6
Deep groove ball
bearing, Steel



HK
Manual locking clamp,
Manual locking clamp



LAT2
2A motorised linear
actuator, 2 amperes

Complementary products



BABreceptacle
Ball pin socket, Socket



CDR
Retaining cable for
ball pin, Retaining
cable



AFA
Locking pin, with ring



BABtss
303 Stainless steel
ball pin, 303 Stainless
steel