

hardened stainless steel clamping pin

BABT

With T handle

- **Self locking**
- **Materials**
 Shaft: Stainless steel 1.4542, precipitation hardened with scratch resistant coating
 Spring: Stainless steel
 Handle: Black aluminium (RAL9005)
 Release button: Black stainless steel
- **Working temperature range:** -30°C to +150°C




Advantages

- Push to release
- Easy and quick method of attaching, blocking, adjusting etc...
 Quickly and easily unlocked for frequently repeated operations.
- Corrosion resistant
- Highly resistant, anti-wear, suitable for heavy duty applications
- Can be used with the **CDR** retaining cable

Info.

- Shear resistance conforms to DIN 50141

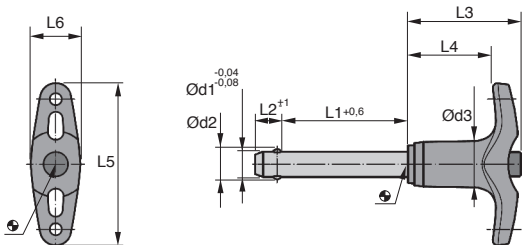


DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	On request	

Part number	Ød1	L1	Ød2	Ød3	L2	L3	L4	L5	L6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB5-10/T	5	10	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	19	34,93 €
BAB5-15/T	5	15	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	20	34,93 €
BAB5-20/T	5	20	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	20	34,93 €
BAB5-25/T	5	25	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	21	34,93 €
BAB5-30/T	5	30	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	22	37,10 €
BAB6-10/T	6	10	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	20	34,93 €
BAB6-15/T	6	15	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	21	34,93 €
BAB6-20/T	6	20	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	22	34,93 €
BAB6-25/T	6	25	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	23	34,93 €
BAB6-30/T	6	30	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	24	37,10 €

Dimensions in mm

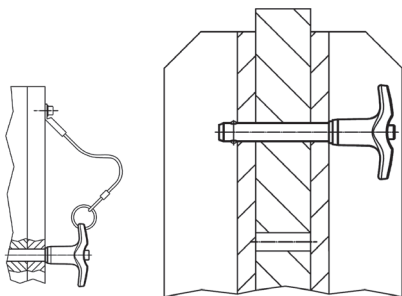

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Ød1	L1	Ød2	Ød3	L2	L3	L4	L5	L6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB6-35/T	6	35	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	25	37,10 €
BAB6-40/T	6	40	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	26	37,10 €
BAB6-45/T	6	45	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	27	37,10 €
BAB6-50/T	6	50	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	28	37,10 €
BAB8-20/T	8	20	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	37	38,57 €
BAB8-25/T	8	25	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	39	38,25 €
BAB8-30/T	8	30	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	41	40,66 €
BAB8-35/T	8	35	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	43	40,66 €
BAB8-40/T	8	40	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	44	40,66 €
BAB8-45/T	8	45	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	46	40,66 €
BAB8-50/T	8	50	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	48	40,66 €
BAB10-20/T	10	20	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	44	56,42 €
BAB10-25/T	10	25	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	47	56,42 €
BAB10-30/T	10	30	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	49	59,38 €
BAB10-35/T	10	35	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	52	59,38 €
BAB10-40/T	10	40	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	55	59,38 €
BAB10-45/T	10	45	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	58	59,38 €
BAB10-50/T	10	50	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	61	59,38 €
BAB10-60/T	10	60	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	67	62,28 €
BAB12-25/T	12	25	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	73	57,57 €
BAB12-30/T	12	30	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	77	60,51 €
BAB12-35/T	12	35	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	81	60,51 €
BAB12-40/T	12	40	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	86	60,51 €
BAB12-45/T	12	45	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	90	60,51 €
BAB12-50/T	12	50	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	94	60,51 €
BAB12-60/T	12	60	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	103	63,31 €
BAB12-70/T	12	70	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	111	63,31 €
BAB12-80/T	12	80	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	119	66,10 €

Dimensions in mm

Our other products



LRM
Trapezoidal bronze nut, Bronze - 1 thread



ZG125
Plastic spur gear, Machined plastic (delrin)



UGPC
Actuator guide kit, Short bearing



SLS
Bearing block for leadscrew, Floating Drylin® bearing block



PNA
PERIFLEX® elastic coupling, Complete coupling



CNA-CNG
Right angled mounting plate, Right angled mounting plate for clevis



NT92
Spur gear coaxial gearbox, from 15 to 40 Nm - In-line



PRF1945
Standard aluminium profile, 19 x 45 mm



MAX26
Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



H02
Single needle roller universal joint, Heavy duty



CFF_SS
Female rod ends DIN ISO12240-4, Stainless steel / bronze -



BUH77
Motor-gearbox 12V and 24V DC, from 0.1 to 2 Nm

Complementary products



BABreceptacle
Ball pin socket, Socket



CDR
Retaining cable for ball pin, Retaining cable



AFA
Locking pin, with ring



BABTss
303 Stainless steel ball pin, 303 Stainless steel