

# hardened stainless steel clamping pin Sta

## BABT

## With T handle

- **Self locking**
- **Materials**  
 Shaft: Stainless steel 1.4542, precipitation hardened with scratch resistant coating  
 Spring: Stainless steel  
 Handle: Black aluminium (RAL9005)  
 Release button: Black stainless steel
- **Working temperature range:** -30°C to +150°C




### Advantages

- Push to release
- Easy and quick method of attaching, blocking, adjusting etc...  
 Quickly and easily unlocked for frequently repeated operations.
- Corrosion resistant
- Highly resistant, anti-wear, suitable for heavy duty applications
- Can be used with the **CDR** retaining cable

### Info.

- Shear resistance conforms to DIN 50141

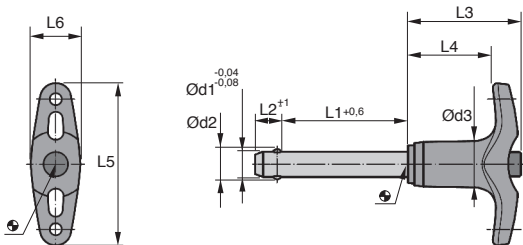


### DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	On request	

Part number	Ød1	L1	Ød2	Ød3	L2	L3	L4	L5	L6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB5-10/T	5	10	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	19	34,93 €
BAB5-15/T	5	15	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	20	34,93 €
BAB5-20/T	5	20	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	20	34,93 €
BAB5-25/T	5	25	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	21	34,93 €
BAB5-30/T	5	30	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	22	37,10 €
BAB6-10/T	6	10	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	20	34,93 €
BAB6-15/T	6	15	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	21	34,93 €
BAB6-20/T	6	20	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	22	34,93 €
BAB6-25/T	6	25	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	23	34,93 €
BAB6-30/T	6	30	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	24	37,10 €

Dimensions in mm

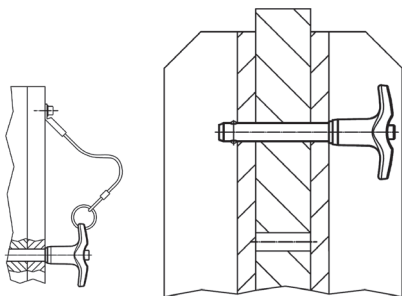

## DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	On request	

Part number	Ød1	L1	Ød2	Ød3	L2	L3	L4	L5	L6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB6-35/T	6	35	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	25	37,10 €
BAB6-40/T	6	40	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	26	37,10 €
BAB6-45/T	6	45	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	27	37,10 €
BAB6-50/T	6	50	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	28	37,10 €
BAB8-20/T	8	20	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	37	38,57 €
BAB8-25/T	8	25	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	39	38,25 €
BAB8-30/T	8	30	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	41	40,66 €
BAB8-35/T	8	35	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	43	40,66 €
BAB8-40/T	8	40	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	44	40,66 €
BAB8-45/T	8	45	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	46	40,66 €
BAB8-50/T	8	50	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	48	40,66 €
BAB10-20/T	10	20	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	44	56,42 €
BAB10-25/T	10	25	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	47	56,42 €
BAB10-30/T	10	30	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	49	59,38 €
BAB10-35/T	10	35	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	52	59,38 €
BAB10-40/T	10	40	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	55	59,38 €
BAB10-45/T	10	45	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	58	59,38 €
BAB10-50/T	10	50	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	61	59,38 €
BAB10-60/T	10	60	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	67	62,28 €
BAB12-25/T	12	25	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	73	57,57 €
BAB12-30/T	12	30	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	77	60,51 €
BAB12-35/T	12	35	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	81	60,51 €
BAB12-40/T	12	40	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	86	60,51 €
BAB12-45/T	12	45	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	90	60,51 €
BAB12-50/T	12	50	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	94	60,51 €
BAB12-60/T	12	60	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	103	63,31 €
BAB12-70/T	12	70	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	111	63,31 €
BAB12-80/T	12	80	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	119	66,10 €

Dimensions in mm

## Our other products



BLHM70

Right angled gearbox,  
up to 128 Nm



GPB

Threaded spherical  
knob, Moulded thread



BAB

Hardened Stainless  
steel ball pin,  
Stainless steel  
hardened



BPP

Pressed steel flanged  
bearing for light  
loads, Sheet steel  
hardened



 
BCM\_T

Driving collar, Driving  
collar



GMK17\_BR

Clamp for guiding  
profile, Rounded only  
- double



CT

Telescopic universal  
joint, Normal duty



RAGb

Cylindrical brush  
track, For gentle  
conveying and  
handling



PSG15

Spur gear - precision  
range, Case hardened



CLASS

Stainless steel  
indexing handle -



EFTC

Fixing support,  
Stainless steel



NSKB

Drynlin® Rail end cap,  
Rail end cap

## Complementary products



BABreceptacle

Ball pin socket, Socket



CDR

Retaining cable for  
ball pin, Retaining  
cable



AFA

Locking pin, with ring



BABTss

303 Stainless steel  
ball pin, 303 Stainless  
steel