

hardened stainless steel clamping pin Sta

BABT

With T handle

- **Self locking**
- **Materials**
 Shaft: Stainless steel 1.4542, precipitation hardened with scratch resistant coating
 Spring: Stainless steel
 Handle: Black aluminium (RAL9005)
 Release button: Black stainless steel
- **Working temperature range:** -30°C to +150°C




Advantages

- Push to release
- Easy and quick method of attaching, blocking, adjusting etc...
 Quickly and easily unlocked for frequently repeated operations.
- Corrosion resistant
- Highly resistant, anti-wear, suitable for heavy duty applications
- Can be used with the **CDR** retaining cable

Info.

- Shear resistance conforms to DIN 50141

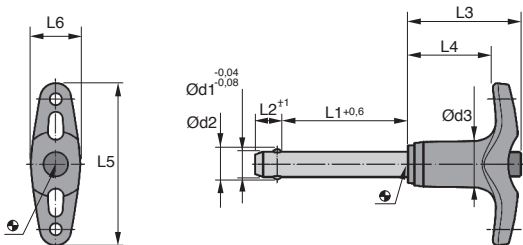


DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	On request	

Part number	Ød1	L1	Ød2	Ød3	L2	L3	L4	L5	L6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB5-10/T	5	10	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	19	34,93 €
BAB5-15/T	5	15	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	20	34,93 €
BAB5-20/T	5	20	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	20	34,93 €
BAB5-25/T	5	25	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	21	34,93 €
BAB5-30/T	5	30	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	24	22	37,10 €
BAB6-10/T	6	10	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	20	34,93 €
BAB6-15/T	6	15	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	21	34,93 €
BAB6-20/T	6	20	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	22	34,93 €
BAB6-25/T	6	25	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	23	34,93 €
BAB6-30/T	6	30	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	24	37,10 €

Dimensions in mm

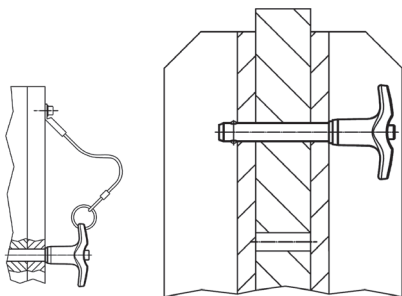

DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	On request	

Part number	Ød1	L1	Ød2	Ød3	L2	L3	L4	L5	L6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB6-35/T	6	35	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	25	37,10 €
BAB6-40/T	6	40	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	26	37,10 €
BAB6-45/T	6	45	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	27	37,10 €
BAB6-50/T	6	50	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	35	28	37,10 €
BAB8-20/T	8	20	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	37	38,57 €
BAB8-25/T	8	25	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	39	38,25 €
BAB8-30/T	8	30	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	41	40,66 €
BAB8-35/T	8	35	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	43	40,66 €
BAB8-40/T	8	40	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	44	40,66 €
BAB8-45/T	8	45	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	46	40,66 €
BAB8-50/T	8	50	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	63	48	40,66 €
BAB10-20/T	10	20	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	44	56,42 €
BAB10-25/T	10	25	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	47	56,42 €
BAB10-30/T	10	30	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	49	59,38 €
BAB10-35/T	10	35	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	52	59,38 €
BAB10-40/T	10	40	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	55	59,38 €
BAB10-45/T	10	45	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	58	59,38 €
BAB10-50/T	10	50	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	61	59,38 €
BAB10-60/T	10	60	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	100	67	62,28 €
BAB12-25/T	12	25	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	73	57,57 €
BAB12-30/T	12	30	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	77	60,51 €
BAB12-35/T	12	35	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	81	60,51 €
BAB12-40/T	12	40	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	86	60,51 €
BAB12-45/T	12	45	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	90	60,51 €
BAB12-50/T	12	50	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	94	60,51 €
BAB12-60/T	12	60	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	103	63,31 €
BAB12-70/T	12	70	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	111	63,31 €
BAB12-80/T	12	80	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	144	119	66,10 €

Dimensions in mm

Our other products



SF_ZZ
Deep groove ball bearing, Stainless steel



BKGS
Backlash free coupling Gerwah®, from 1.2 to 450Nm



GLP
Small 6 lobe threaded handle - male, Technopolymer - Steel



F7-P-AM
Multifunction display, Magnetic band



GPLbr
Brush, brass



BAG-MISS
Split shaft collar with clamp lever, Stainless steel



TOL
Swivel head, Long



NSKB
Drylin® Rail end cap, Rail end cap




DER90
Stainless steel AC asynchronous motor 1.1 - 1.5kW, 1.1 to



RHTtcss
High Temperature Castor, up to 200kg



 HLA19
Right angle spiro bevel gearbox, Up to 43Nm



JSM
Cylindrical polymer bush, Universal polymer

Complementary products



BABreceptacle
Ball pin socket, Socket



CDR
Retaining cable for ball pin, Retaining cable



AFA
Locking pin, with ring



BABtss
303 Stainless steel ball pin, 303 Stainless steel