



- Allows ball pins to be positioned quickly and more securely
- Material:
Stainless steel 1.4305 (303)

Advantages

- Precision collar means optimised centring
- Simple and safe assembly
- Suitable for use with different materials
- Suitable for use with thin walled materials
- Corrosion resistant
- Wear resistant
- Can be mounted from either side

Simple and safe assembly

stainless steel

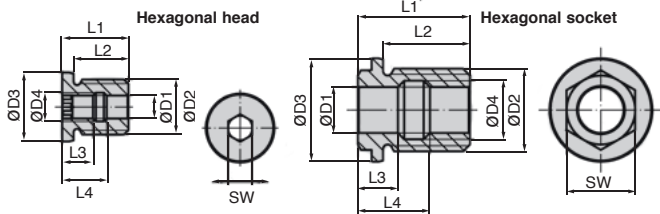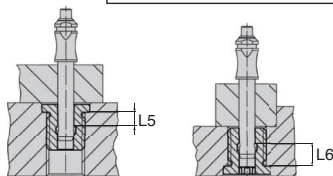

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1 H11	ØD2	ØD3	ØD4	L1	L2	L3	L4	L5	L6	SW	Weight (g)	Price each 1 to 5
Hexagonal head													
BAB5-M12	5	M12	18	6,0	19	15	9,0	13,0	5,1	9,0	5	15	16,57 €
BAB6-M12	6	M12	18	7,5	19	15	9,4	13,0	5,6	8,8	6	13	16,57 €
BAB8-M16	8	M16	22	10,0	25	20	12,0	17,0	7,3	11,7	8	29	24,43 €
BAB10-M24	10	M24	30	12,5	29	24	13,5	19,5	8,9	14,1	10	75	28,36 €
BAB12-M24	12	M24	30	15,0	29	24	14,0	20,0	9,6	14,4	12	66	29,31 €
Hexagonal socket													
BAB16-M30	16	M30	36	19,5	39	29	15,5	23,5	6,1	12,8	24	124	32,27 €
BAB20-M36	20	M36	45	25,5	49	38	17,5	31,5	7,7	19,3	30	208	53,75 €

Dimensions in mm

Our other products




PPG

Indexing plunger with flange, With horizontal mounting flange



CHC

Socket headed screw, Steel class 12.19

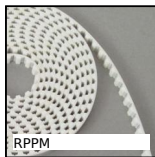

RPPM

RPP type belt per metre, RPP14 Steel cored polyurethane



SBF

Sealed flange bearing unit for Food Industry, cover



ZG1

Plastic spur gear, Machined plastic (delrin)



MRA_SS

Stainless steel Quick link, Stainless steel



INS_SS

Self tapping stainless steel insert, 316 stainless steel



PCF4

Conical flexible mount, Square base plate



SLHVlok

Horizontal toggle clamp, Horizontal toggle clamp / vertical



VHEH

Hexagonal headed screw with collar Hygienic Usit®,



E40

Right angle helical reducers, from 2.30 to 20 Nm



T5-10ECO

T type timing pulley, Economy range - T5 aluminium

Complementary products



BABV

Ball lock pins lockable, Stainless steel



BABTV

Ball lock pins lockable, Stainless steel