



- Allows ball pins to be positioned quickly and more securely
- Material:  
Stainless steel 1.4305 (303)

### Advantages

- Precision collar means optimised centring
- Simple and safe assembly
- Suitable for use with different materials
- Suitable for use with thin walled materials
- Corrosion resistant
- Wear resistant
- Can be mounted from either side

Simple and safe assembly

stainless steel

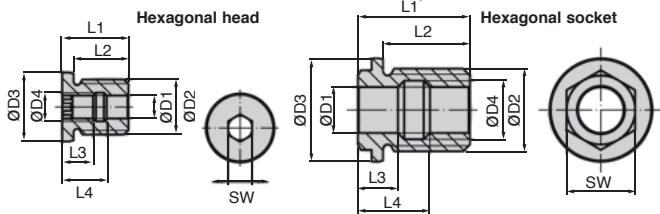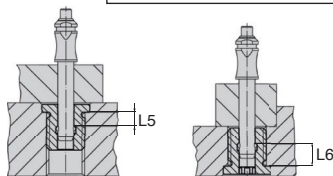

### DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1 H11	ØD2	ØD3	ØD4	L1	L2	L3	L4	L5	L6	SW	Weight (g)	Price each 1 to 5
<b>Hexagonal head</b>													
BAB5-M12	5	M12	18	6,0	19	15	9,0	13,0	5,1	9,0	5	15	16,57 €
BAB6-M12	6	M12	18	7,5	19	15	9,4	13,0	5,6	8,8	6	13	16,57 €
BAB8-M16	8	M16	22	10,0	25	20	12,0	17,0	7,3	11,7	8	29	24,43 €
BAB10-M24	10	M24	30	12,5	29	24	13,5	19,5	8,9	14,1	10	75	28,36 €
BAB12-M24	12	M24	30	15,0	29	24	14,0	20,0	9,6	14,4	12	66	29,31 €
<b>Hexagonal socket</b>													
BAB16-M30	16	M30	36	19,5	39	29	15,5	23,5	6,1	12,8	24	124	32,27 €
BAB20-M36	20	M36	45	25,5	49	38	17,5	31,5	7,7	19,3	30	208	53,75 €

Dimensions in mm

## Our other products



DGS1  
Female rod ends,  
Steel / steel -  
Economy range



 
PRF-SCREEN-5  
Screen support,  
Support with 5 axes of  
rotation



PRES4HR  
Manual workbench  
press, Force up to  
600kg



CHAE4080PA  
Symmetrical decorative  
screwed hinge,  
Polyamide



RPP5  
RPP heavy duty  
timing belt, RPP5



DBL805  
Idler for slat top  
chain, Range 805



TCLar  
Automatic chain  
tensioner, With wide  
guide



SER  
Magnetic doorstop for  
aluminium profile,  
Magnetic doorstop



TMR  
Rigid manual  
tensioner, Adjustable



RBGtc  
Swivel castor with  
central hole, Steel -



R204  
Die spring ISO10243,  
Average



DH  
Dowel pin, Solid DIN  
6325

## Complementary products



BABV  
Ball lock pins lockable  
, Stainless steel



BABTV  
Ball lock pins lockable  
, Stainless steel