



- Allows ball pins to be positioned quickly and more securely
- Material:
Stainless steel 1.4305 (303)

Advantages

- Precision collar means optimised centring
- Simple and safe assembly
- Suitable for use with different materials
- Suitable for use with thin walled materials
- Corrosion resistant
- Wear resistant
- Can be mounted from either side

Simple and safe assembly

stainless steel

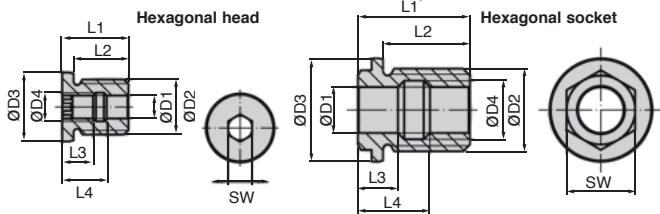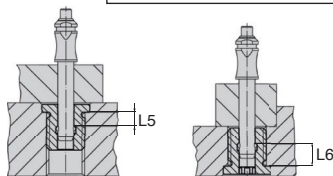

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1 H11	ØD2	ØD3	ØD4	L1	L2	L3	L4	L5	L6	SW	Weight (g)	Price each 1 to 5
Hexagonal head													
BAB5-M12	5	M12	18	6,0	19	15	9,0	13,0	5,1	9,0	5	15	16,57 €
BAB6-M12	6	M12	18	7,5	19	15	9,4	13,0	5,6	8,8	6	13	16,57 €
BAB8-M16	8	M16	22	10,0	25	20	12,0	17,0	7,3	11,7	8	29	24,43 €
BAB10-M24	10	M24	30	12,5	29	24	13,5	19,5	8,9	14,1	10	75	28,36 €
BAB12-M24	12	M24	30	15,0	29	24	14,0	20,0	9,6	14,4	12	66	29,31 €
Hexagonal socket													
BAB16-M30	16	M30	36	19,5	39	29	15,5	23,5	6,1	12,8	24	124	32,27 €
BAB20-M36	20	M36	45	25,5	49	38	17,5	31,5	7,7	19,3	30	208	53,75 €

Dimensions in mm

Our other products



 
ACLEPP

Right angled bracket for aluminium profile, 2 holes



BOXbeta

Box of assorted hitch pins, Boxed set - hitch



FRss

Stainless steel thread inserts, Stainless steel



BSB

Ball screw bearing unit, Support



SHTP

Dylin® Linear table, Economy range



INS_SS

Self tapping stainless steel insert, Stainless steel



BCFH

Mushroom headed button Hygienic Usit®, With male thread and high head



H02

Single needle roller universal joint, Heavy duty




PSG25

Spur gear - precision range, Case hardened steel 20NCD2



BLHM20

 Right angled gearbox, double output shafts, up to 1.77 Nm



CHB

Worm and wheel gear reducer, up to 22 Nm



INS100

Self tapping inserts-coarse thread, Coarse thread

Complementary products



BABV

Ball lock pins lockable, Stainless steel



BABTV

Ball lock pins lockable, Stainless steel