

Ball pin, 303 stainless steel



BABTSS

With T handle

- Self locking

- Materials:

Shaft: Stainless steel 303

Spring: Stainless steel

Handle: Black aluminium RAL9005

Button: Black stainless steel

- Working temp: -30°to 150°C

Advantages

- Press to unlock
- Quick and easy to assemble, block, adjust, change and stop
- Simply and quickly released when performing repetitive operations
- Corrosion resistant
- Resists high loads
- Ergonomic handle
- Handle designed to avoid accidental release




New lower cost material

Info

- Shear resistance acc DIN 50141

Options

- BABT Ball pin manufactured from hardened stainless steel (630) offers increased double shear strength

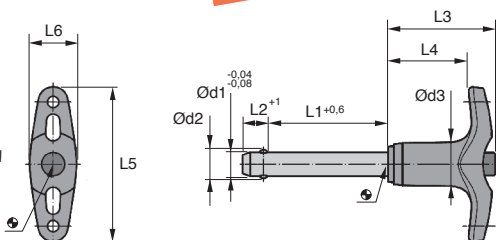

DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	On request	

Part number	Ød1	L1	Ød2	Ød3	L2	L3	L4	L5	L6	Corresponding		Price each	
										bore H11	Double shear resistance kN min.		
BAB5-10/T/SS	5	10	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	19	24,29 €
BAB5-15/T/SS	5	15	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	20	24,29 €
BAB5-20/T/SS	5	20	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	20	24,29 €
BAB5-25/T/SS	5	25	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	21	24,29 €
BAB5-30/T/SS	5	30	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	22	26,02 €
BAB6-10/T/SS	6	10	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	20	24,52 €
BAB6-15/T/SS	6	15	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	21	24,52 €
BAB6-20/T/SS	6	20	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	22	24,52 €
BAB6-25/T/SS	6	25	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	23	24,52 €
BAB6-30/T/SS	6	30	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	24	26,02 €


Dimensions in mm

HPC

WEB
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

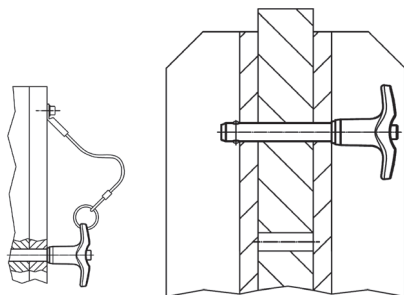


DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Ød1	l1	Ød2	Ød3	l2	l3	l4	l5	l6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB6-35/T/SS	6	35	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	25	26,02 €
BAB6-40/T/SS	6	40	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	26	26,02 €
BAB6-45/T/SS	6	45	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	27	26,02 €
BAB6-50/T/SS	6	50	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	28	26,02 €
BAB8-20/T/SS	8	20	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	37	26,75 €
BAB8-25/T/SS	8	25	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	39	26,75 €
BAB8-30/T/SS	8	30	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	41	28,53 €
BAB8-35/T/SS	8	35	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	43	28,53 €
BAB8-40/T/SS	8	40	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	44	28,53 €
BAB8-45/T/SS	8	45	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	46	28,53 €
BAB8-50/T/SS	8	50	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	48	28,53 €
BAB10-20/T/SS	10	20	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	44	39,59 €
BAB10-25/T/SS	10	25	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	47	39,59 €
BAB10-30/T/SS	10	30	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	49	41,60 €
BAB10-35/T/SS	10	35	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	52	41,60 €
BAB10-40/T/SS	10	40	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	55	41,60 €
BAB10-45/T/SS	10	45	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	58	41,60 €
BAB10-50/T/SS	10	50	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	61	41,60 €
BAB10-60/T/SS	10	60	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	67	43,69 €
BAB12-25/T/SS	12	25	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	73	40,20 €
BAB12-30/T/SS	12	30	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	77	42,33 €
BAB12-35/T/SS	12	35	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	81	42,33 €
BAB12-40/T/SS	12	40	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	86	42,33 €
BAB12-45/T/SS	12	45	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	90	42,33 €
BAB12-50/T/SS	12	50	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	94	42,33 €
BAB12-60/T/SS	12	60	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	103	44,24 €
BAB12-70/T/SS	12	70	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	111	44,24 €
BAB12-80/T/SS	12	80	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	119	46,13 €

Dimensions in mm

 Our other products



STL

Guidance brush -
Brush, Brush



RURt

Swivel castor with
central hole,
Polyurethane -
Aluminium rim (Free



GB-RA

Brass spur gear, Brass
CuZn39Pb3



PSG25

Spur gear - precision
range, Pre-hardened
Steel 35NCD6



HW_HT

Half-rail guide, Rail



CLG3

Moulded plastic spur
gear, Moulded plastic
(nylon)



PGMT

Pull handle, Stainless
steel



CHA35

Hinge for aluminium
profile, Hinge




MSP23

Masterplate®
glueable insert Ø23,
Cylindrical Ø23 with



ZB

 Shaft for linear
guides, Hardened
ground stainless steel



CDRs

Retaining cable for
ball pin, Retaining
cable



BLHB60

Right angled gearbox,
bored shafts, up to 70
Nm

Complementary products



CDR

Retaining cable for
ball pin, Retaining
cable



BABss

303 Stainless steel
ball pin, 303 Stainless
steel



BAPT

Hardened Stainless
steel ball pin,
Hardened stainless
steel