

Ball pin, 303 stainless steel



BABTSS

With T handle

- Self locking

- Materials:

Shaft: Stainless steel 303

Spring: Stainless steel

Handle: Black aluminium RAL9005

Button: Black stainless steel

- Working temp: -30°to 150°C

Advantages

- Press to unlock
- Quick and easy to assemble, block, adjust, change and stop
- Simply and quickly released when performing repetitive operations
- Corrosion resistant
- Resists high loads
- Ergonomic handle
- Handle designed to avoid accidental release




New lower cost material

Info

- Shear resistance acc DIN 50141

Options

- BABT Ball pin manufactured from hardened stainless steel (630) offers increased double shear strength

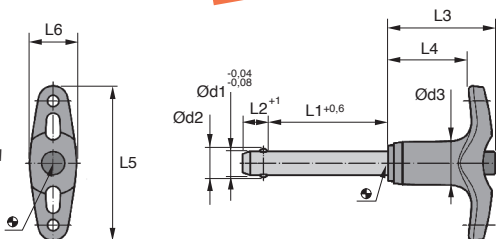


DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	On request	

Part number	Ød1	L1	Ød2	Ød3	L2	L3	L4	L5	L6	Corresponding		Price each	
										bore H11	Double shear resistance kN min.		
BAB5-10/T/SS	5	10	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	19	24,29 €
BAB5-15/T/SS	5	15	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	20	24,29 €
BAB5-20/T/SS	5	20	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	20	24,29 €
BAB5-25/T/SS	5	25	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	21	24,29 €
BAB5-30/T/SS	5	30	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	22	26,02 €
BAB6-10/T/SS	6	10	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	20	24,52 €
BAB6-15/T/SS	6	15	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	21	24,52 €
BAB6-20/T/SS	6	20	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	22	24,52 €
BAB6-25/T/SS	6	25	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	23	24,52 €
BAB6-30/T/SS	6	30	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	24	26,02 €

Dimensions in mm

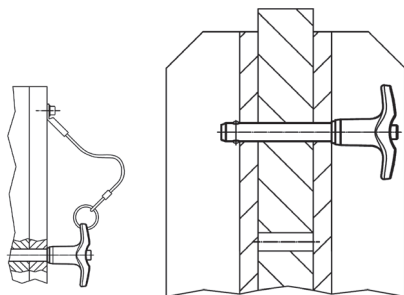

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Ød1	l1	Ød2	Ød3	l2	l3	l4	l5	l6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB6-35/T/SS	6	35	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	25	26,02 €
BAB6-40/T/SS	6	40	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	26	26,02 €
BAB6-45/T/SS	6	45	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	27	26,02 €
BAB6-50/T/SS	6	50	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	28	26,02 €
BAB8-20/T/SS	8	20	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	37	26,75 €
BAB8-25/T/SS	8	25	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	39	26,75 €
BAB8-30/T/SS	8	30	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	41	28,53 €
BAB8-35/T/SS	8	35	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	43	28,53 €
BAB8-40/T/SS	8	40	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	44	28,53 €
BAB8-45/T/SS	8	45	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	46	28,53 €
BAB8-50/T/SS	8	50	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	48	28,53 €
BAB10-20/T/SS	10	20	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	44	39,59 €
BAB10-25/T/SS	10	25	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	47	39,59 €
BAB10-30/T/SS	10	30	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	49	41,60 €
BAB10-35/T/SS	10	35	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	52	41,60 €
BAB10-40/T/SS	10	40	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	55	41,60 €
BAB10-45/T/SS	10	45	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	58	41,60 €
BAB10-50/T/SS	10	50	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	61	41,60 €
BAB10-60/T/SS	10	60	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	67	43,69 €
BAB12-25/T/SS	12	25	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	73	40,20 €
BAB12-30/T/SS	12	30	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	77	42,33 €
BAB12-35/T/SS	12	35	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	81	42,33 €
BAB12-40/T/SS	12	40	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	86	42,33 €
BAB12-45/T/SS	12	45	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	90	42,33 €
BAB12-50/T/SS	12	50	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	94	42,33 €
BAB12-60/T/SS	12	60	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	103	44,24 €
BAB12-70/T/SS	12	70	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	111	44,24 €
BAB12-80/T/SS	12	80	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	119	46,13 €

Dimensions in mm

Our other products



FF40

Offset spur gear reducer, from 59 to 210 Nm



T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane



RCC_RCX

Spherical tilt washer - DIN6319, concave



BIMSS

Indexing plunger mini, miniature - Stainless steel



HTD8M_50

HTD Heavy duty timing pulley, HTD8 Cast



CHT

Asynchronous AC motor 0.12 to 0.22kW, 0.12 to 0.22kW



HLA19

Right angle spiro bevel gearbox, Up to 43Nm



BLHM30

Right angled gearbox, double output shafts, up to 4.4 Nm



BH01

Single housed bearing, Bearing fitted



CHAL3

Piano hinge, Steel



PTCR

Adjustable furniture foot, square tube



HS

Hexagonal spacer, Stainless steel 303

Complementary products



CDR

Retaining cable for ball pin, Retaining cable



BABss

303 Stainless steel ball pin, 303 Stainless steel



BABT

Hardened Stainless steel ball pin, Hardened stainless steel