

# Clamping pin, 303 stainless steel



## BAB<sub>TSS</sub>

## With T handle

### - Self locking

### - Materials:

Shaft: Stainless steel 303

Spring: Stainless steel

Handle: Black aluminium RAL9005

Button: Black stainless steel

### - Working temp: -30° to 150°C

## Advantages

- Press to unlock
- Quick and easy to assemble, block, adjust, change and stop
- Simply and quickly released when performing repetitive operations
- Corrosion resistant
- Resists high loads
- Ergonomic handle
- Handle designed to avoid accidental release



Lower cost material

## Info


- Shear resistance acc DIN 50141

## Options

- BAB<sub>T</sub> Ball pin manufactured from hardened stainless steel (630) offers increased double shear strength

## Accessory

- CDR retaining cable (tome 1 p.39)

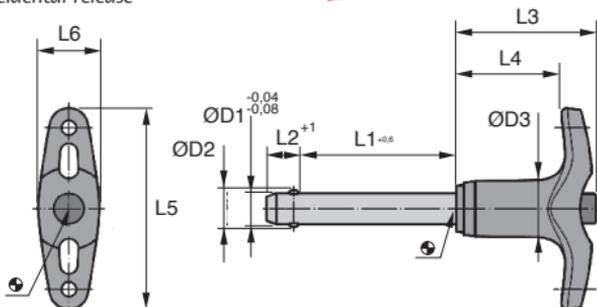


IN STOCK

## DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1	L1	ØD2	ØD3	L2	L3	L4	L5	L6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB5-10/T/SS	5	10	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	19	30,07 €
BAB5-15/T/SS	5	15	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	20	30,07 €
BAB5-20/T/SS	5	20	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	20	30,07 €
BAB5-25/T/SS	5	25	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	21	30,07 €
BAB5-30/T/SS	5	30	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	22	32,22 €
BAB6-10/T/SS	6	10	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	20	30,36 €
BAB6-15/T/SS	6	15	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	21	30,36 €
BAB6-20/T/SS	6	20	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	22	30,36 €
BAB6-25/T/SS	6	25	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	23	30,36 €
BAB6-30/T/SS	6	30	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	24	32,22 €

Dimensions in mm

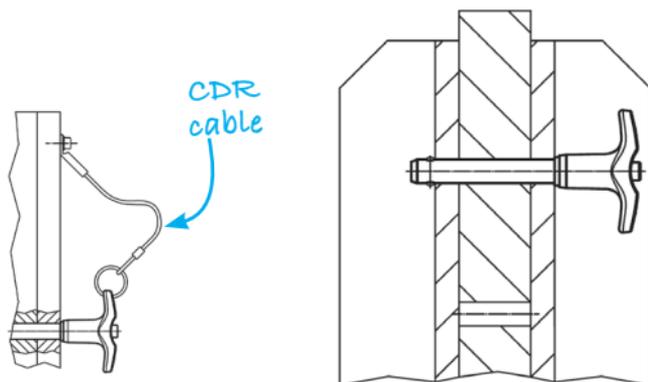

**✓ IN STOCK**

## DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1	L1	ØD2	ØD3	L2	L3	L4	L5	L6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB6-35/T/SS	6	35	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	25	32,22 €
BAB6-40/T/SS	6	40	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	26	32,22 €
BAB6-45/T/SS	6	45	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	27	32,22 €
BAB6-50/T/SS	6	50	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	28	32,22 €
BAB8-20/T/SS	8	20	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	37	33,12 €
BAB8-25/T/SS	8	25	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	39	33,12 €
BAB8-30/T/SS	8	30	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	41	35,32 €
BAB8-35/T/SS	8	35	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	43	35,32 €
BAB8-40/T/SS	8	40	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	44	35,32 €
BAB8-45/T/SS	8	45	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	46	35,32 €
BAB8-50/T/SS	8	50	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	48	35,32 €
BAB10-20/T/SS	10	20	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	44	49,02 €
BAB10-25/T/SS	10	25	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	47	49,02 €
BAB10-30/T/SS	10	30	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	49	51,50 €
BAB10-35/T/SS	10	35	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	52	51,50 €
BAB10-40/T/SS	10	40	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	55	51,50 €
BAB10-45/T/SS	10	45	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	58	51,50 €
BAB10-50/T/SS	10	50	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	61	51,50 €
BAB10-60/T/SS	10	60	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	67	54,09 €
BAB12-25/T/SS	12	25	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	73	49,77 €
BAB12-30/T/SS	12	30	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	77	52,41 €
BAB12-35/T/SS	12	35	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	81	52,41 €
BAB12-40/T/SS	12	40	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	86	52,41 €
BAB12-45/T/SS	12	45	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	90	52,41 €
BAB12-50/T/SS	12	50	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	94	52,41 €
BAB12-60/T/SS	12	60	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	103	54,77 €
BAB12-70/T/SS	12	70	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	111	54,77 €
BAB12-80/T/SS	12	80	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	119	57,11 €

Dimensions in mm