

# Ball pin, 303 stainless steel



## BABTSS

## With T handle

### - Self locking

### - Materials:

Shaft: Stainless steel 303

Spring: Stainless steel

Handle: Black aluminium RAL9005

Button: Black stainless steel

### - Working temp: -30°to 150°C

## Advantages

- Press to unlock
- Quick and easy to assemble, block, adjust, change and stop
- Simply and quickly released when performing repetitive operations
- Corrosion resistant
- Resists high loads
- Ergonomic handle
- Handle designed to avoid accidental release




**New lower cost material**

## Info

- Shear resistance acc DIN 50141

## Options

- BABT Ball pin manufactured from hardened stainless steel (630) offers increased double shear strength

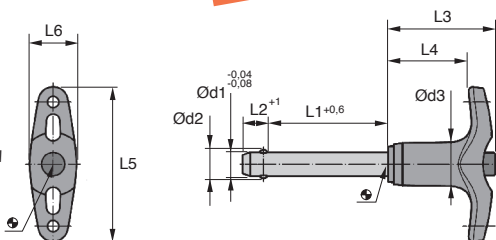

## DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	On request	

Part number	Ød1	L1	Ød2	Ød3	L2	L3	L4	L5	L6	Corresponding bore H11		Double shear resistance kN min.	Weight (g)	Price each
										1 to 5	6 to 10			
BAB5-10/T/SS	5	10	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	19	24,29 €	
BAB5-15/T/SS	5	15	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	20	24,29 €	
BAB5-20/T/SS	5	20	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	20	24,29 €	
BAB5-25/T/SS	5	25	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	21	24,29 €	
BAB5-30/T/SS	5	30	5,5	11,8	6,0	31,6	24,1	45,2	12,7	5	14	22	26,02 €	
BAB6-10/T/SS	6	10	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	20	24,52 €	
BAB6-15/T/SS	6	15	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	21	24,52 €	
BAB6-20/T/SS	6	20	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	22	24,52 €	
BAB6-25/T/SS	6	25	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	23	24,52 €	
BAB6-30/T/SS	6	30	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	24	26,02 €	


Dimensions in mm

**HPC**

WEB  
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

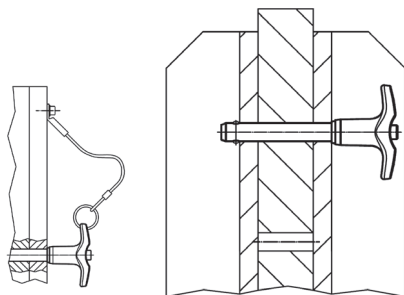

## DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Ød1	l1	Ød2	Ød3	l2	l3	l4	l5	l6	Corresponding bore H11	Double shear resistance kN min.	Weight (g)	Price each 1 to 5
BAB6-35/T/SS	6	35	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	25	26,02 €
BAB6-40/T/SS	6	40	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	26	26,02 €
BAB6-45/T/SS	6	45	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	27	26,02 €
BAB6-50/T/SS	6	50	7,0	11,8	7,0	31,6	24,1	45,2	12,7	6	21	28	26,02 €
BAB8-20/T/SS	8	20	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	37	26,75 €
BAB8-25/T/SS	8	25	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	39	26,75 €
BAB8-30/T/SS	8	30	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	41	28,53 €
BAB8-35/T/SS	8	35	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	43	28,53 €
BAB8-40/T/SS	8	40	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	44	28,53 €
BAB8-45/T/SS	8	45	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	46	28,53 €
BAB8-50/T/SS	8	50	9,5	14,7	8,2	35,8	26,9	51,5	15,8	8	38	48	28,53 €
BAB10-20/T/SS	10	20	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	44	39,59 €
BAB10-25/T/SS	10	25	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	47	39,59 €
BAB10-30/T/SS	10	30	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	49	41,60 €
BAB10-35/T/SS	10	35	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	52	41,60 €
BAB10-40/T/SS	10	40	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	55	41,60 €
BAB10-45/T/SS	10	45	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	58	41,60 €
BAB10-50/T/SS	10	50	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	61	41,60 €
BAB10-60/T/SS	10	60	12,0	14,7	9,6	35,8	26,9	51,5	15,8	10	60	67	43,69 €
BAB12-25/T/SS	12	25	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	73	40,20 €
BAB12-30/T/SS	12	30	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	77	42,33 €
BAB12-35/T/SS	12	35	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	81	42,33 €
BAB12-40/T/SS	12	40	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	86	42,33 €
BAB12-45/T/SS	12	45	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	90	42,33 €
BAB12-50/T/SS	12	50	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	94	42,33 €
BAB12-60/T/SS	12	60	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	103	44,24 €
BAB12-70/T/SS	12	70	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	111	44,24 €
BAB12-80/T/SS	12	80	14,5	18,2	10,6	35,1	25,3	59,1	20,2	12	87	119	46,13 €

Dimensions in mm

 
## Our other products



Self-centering  
clamping hub  
stainless steel,  
Without locknut



Tools Hygienic Usit®  
and Hygienic  
Design®, Protective  
inserts for ...



Retaining cable for  
ball pin, Retaining  
cable



Parallel axis helical  
gear, Machined plastic  
(delrin)



 
Brush, silk



Spherical tilt washer -  
DIN6319, convex



Accessory-holder for  
aluminium profile,  
Tool holder



RPP type belt per  
metre, RPP8 Steel  
cored polyurethane



Die spring ISO10243,  
Light



Worm and wheel set,  
Machined plastic



Diabolo shaped elasto  
mount, Steel



Idler sprocket for slot  
top chain, Range 880

## Complementary products



Retaining cable for  
ball pin, Retaining  
cable



303 Stainless steel  
ball pin, 303 Stainless  
steel



Hardened Stainless  
steel ball pin,  
Hardened stainless  
steel