

Storage bin for aluminium profile **New**

BAC105

For 8mm slots

- **Sorting or storage bin for 40/45mm wide profiles (Type PRF4545)**

- **Can easily be inserted into the slot of an aluminium profile by turning slightly**

- **Materials:**


 

Tray: Glass fibre reinforced PA plastic

Cardboard label 250g/m²

PC plastic window

Polyurethane shock absorbers 65/70

Shore A (4-off)

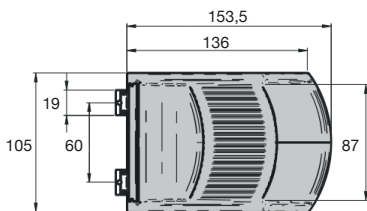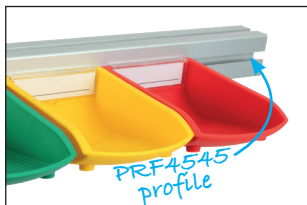

DISCOUNTS

Qty	1+	50+	100+
Disc.	Net	-5%	On request

Part N°	Colour	RAL	Weight (g)	Price each
BAC105-130N	Black	-	137,4	4,24 €
BAC105-130J	Yellow	RAL1003	137,4	4,34 €
BAC105-130R	Red	RAL3020	137,4	4,34 €
BAC105-130V	Green	RAL6032	137,4	4,34 €
BAC105-130G	Grey	RAL7042	137,4	4,34 €

Our other products



NKXR
Combined bearing without inner ring, Needle and cylindrical rollers



PCF2
Conical flexible mount, Oval base plate



CHAFR-MINI
Miniature friction hinge, Friction



PR125
Articulated foot Ø123, Ø 123



COA-COG
Surface mounting plate, Surface mounting plate for ball joint



DB_ECO
Eco. range steel bevel gear, 2:1



RBNpl
Swivel castor with double brake, Steel - rubber



MEP
Revolving handle for handwheel, Fixed



LVT
Miniature motorised actuator 2A, 2 amperes



BPM-Z
Plastic slotted spring plunger with ball tip, Plastic body + plastic...



WFRM
Flanged polymer nut, Polymer (Iglidur®) - 1 thread



COA-COG
Surface mounting plate, Surface mounting plate for clevis

Complementary products



PRF1932
Standard aluminium profile, 19 x 32 mm



PRF4545
Standard aluminium profile, 45 x 45 mm



PRF4590
Standard aluminium profile, 45 x 90 mm