




Storage bin for aluminium profile **New**

BAC105

For 8mm slots

- Sorting or storage bin for 40/45mm wide profiles (Type PRF4545)
- Can easily be inserted into the slot of an aluminium profile by turning slightly
- Materials:

 Tray: Glass fibre reinforced PA plastic
 Cardboard label 250g/m²
 PC plastic window
 Polyurethane shock absorbers 65/70 Shore A (4-off)

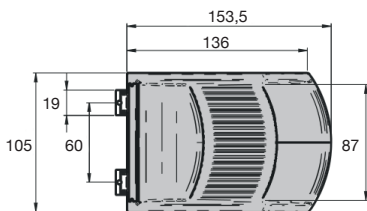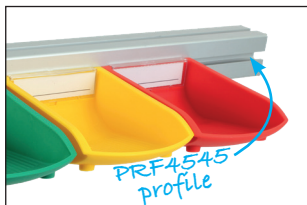

DISCOUNTS

Qty	1+	50+	100+
Disc.	Net	-5%	On request

Part N°	Colour	RAL	Weight (g)	Price each
BAC105-130N	Black	-	137,4	4,24 €
BAC105-130J	Yellow	RAL1003	137,4	4,34 €
BAC105-130R	Red	RAL3020	137,4	4,34 €
BAC105-130V	Green	RAL6032	137,4	4,34 €
BAC105-130G	Grey	RAL7042	137,4	4,34 €

Our other products



M1

Worm and wheel set,
Hardened steel



BOX-CSss

Hose clamp, Box set
of stainless steel hose
clamps



BLHB20

Right angled gearbox,
bored shafts, up to
1.77 Nm



KB_UU

Closed linear
precision bearing,
Precision - steel



H3

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



PML

Solid foot mount for
heavy loads, Ø 100,
120 or 150



MSP19

Masterplate®
glueable insert Ø19,
Cylindrical with
tapped insert



GG3

Ground spur gear,
Heat treated steel



 
PCLA_M

Technopolymer
clamping lever -
female, Plastic



BPHT

Ball transfer unit bolt
fitting, Heavy



BLHM50

Right angled gearbox,
double output shafts,
up to 30 Nm



BPPL

Mini plain bearing ball
transfer unit, For
countersinking

Complementary products



PRF1932

Standard aluminium
profile, 19 x 32 mm



PRF4545

Standard aluminium
profile, 45 x 45 mm



PRF4590

Standard aluminium
profile, 45 x 90 mm