



Storage bin for aluminium profile

For 8 and 10mm slots

BAC110

- Sorting or storage bin for 40/45mm wide profiles (Type PRF4545)

- The adjustable support can swivel +/- 45°
- With locking screw to prevent pivoting

- Materials:

Tray: Glass fibre reinforced PA plastic

Cardboard label 250g/m²

PC plastic window


Swivel hook:

Glass fibre reinforced PA plastic

Steel and Zamak fittings

Info.

- The adjustable support must be used to attach the bin in the profile slot

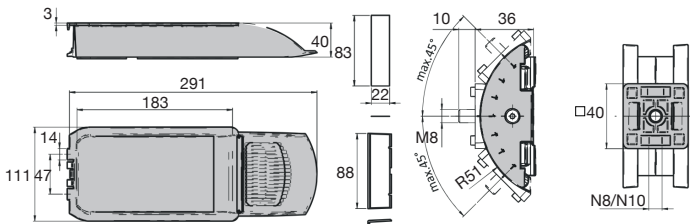

DISCOUNTS

Qty	1+	50+	100+
Disc. Net		-5%	On request

Part N°	Colour	Weight (g)	Price each
Bin			
BAC110-270N	Black	219,3	11,48 €
Adjustable support			
BAC110-ACC	Black	90,8	8,93 €

Our other products



BOX-TOR-G

Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x 3.00



T5P_T10P

Connecting plate for T type timing belts, T5



ZDB

Machined plastic bevel gear, 2:1



NK17

Drylin®N miniature guiding system, Width 17 mm



PRF4545r90

Standard aluminium profile, 45 x 45 mm - R90°



Q4

Double row radial contact ball bearing, Radial contact - Steel



SF_ZZ

Deep groove ball bearing, Stainless steel



PRFRTR

Cross connector for aluminium profile, Cross connector



PDD

Spring plunger, With sensor adaptor



BPHR

Ball transfer unit housed spring loaded, High



PCS62

Chain sprocket - steel, 15.875 (DIN 10B-1)



GCB880

Curved track for slat top chain, Ranges 880 and 881

Complementary products



BAC110

Swivel storage bin, Adjustable support



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF4590

Standard aluminium profile, 45 x 90 mm



PRF1932

Standard aluminium profile, 19 x 32 mm