

Split shaft collar with clamp lever

BAG-MI

Steel

- Ensures a uniform distribution of the clamping force
- Clamps securely to any type of shaft
- Material:

Burnished steel (S250Pb)

Repeated operations

 



Advantages

- Fits perfectly on to the shaft with a high clamping force but without risk of damage

Info.

- Recommended shaft tolerance: h11

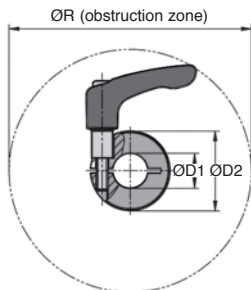

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	ØD1	ØD2	B	ØR	Stock*	Price each 1 to 5
BAG1-010-MI	10	24	9	44,1	-	14,83 €
BAG1-012-MI	12	28	11	90,4	✓	15,16 €
BAG1-015-MI	15	34	13	105,0	-	16,38 €
BAG1-016-MI	16	34	13	105,0	✓	16,73 €
BAG1-018-MI	18	36	13	105,7	-	17,46 €
BAG1-020-MI	20	40	15	103,8	✓	18,26 €
BAG1-022-MI	22	42	15	104,2	-	18,26 €
BAG1-025-MI	25	45	15	104,8	✓	19,34 €
BAG1-028-MI	28	48	15	106,8	-	19,34 €
BAG1-030-MI	30	54	15	112,6	✓	22,20 €
BAG1-040-MI	40	60	15	113,2	-	25,18 €
BAG1-050-MI	50	78	19	150,2	-	46,79 €

Dimensions in mm

Our other products



PCM

Fixed cylindrical handle, Fixed non-turning handle



CHAsb63

Hinge without pin, Polymer pin hinge



AC

Strike for toggle latch, 15mm



BLH30

Right angled gearbox, from 1.32 to 4.40 Nm



CLB_T

Die cast zinc clamping lever - male, Zamak



PHT

Pull handle, Up to 250 °C



CHTRP

Single and dual output gearboxes, Up to 28,8 Nm



UTKpwr

Utilitak® V rail, V rail



CAP821

Slat top chain acetal, Large range 821



YG1

HEAVY DUTY spur gear, Steel 35NCD6



PTA50ssEB

Articulated foot with sheet metal base



VTHA

Magnetic screw with hexagonal head, Steel

Complementary products



BAG-MISS

Split shaft collar with clamp lever, Stainless steel



BAG

Steel Clamping collar, Steel